

Specifications规格

Rated额定参数:300V , 25A

Dielectric strength抗电强度:AC2000V/1 Minute

Screw Torque螺丝扭矩:1.3Nm(10.53LB. in)

Wire Range线径:22~12AWG



Temp. range操作温度:-40°C~+105°C

Max soldering瞬时温度:+250°C. 5s

Housing Material塑胶材料:PA66

Contact端子:Brass, Tin plating黄铜, 镀锡

Screw螺丝:M4.0 Steel, Ni plating M3.0, 钢, 镀镍

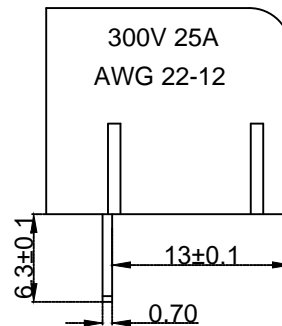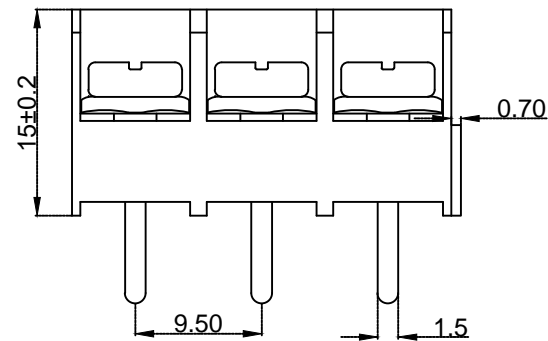

		PLPK9500-*P-14	上海洲日电子有限公司		
			Shanghai Zhouri Electronics CO.,LTD		
			上海康司玛电子设备进出口有限公司		
			Shanghai KangSiMa Eletronic Equipment import and export Co.,LTD		
X.	±0.3	±5°	20171018 A/0	TEL:86-21-34975176/51571121	
X.X	±0.2	±3°	ZR20171018-344		
X.XX	±0.15				
		物料编号	1:1	mm 图幅	A4
			: 1	1	