

FEATURES

- ※ Compact-sized 1.9x4.5mm
- ※ Side actuated
- ※ Sealed with dust proof structure

APPLICATION


- ※ Smart phone
- ※ Digital camera, Medical
- ※ Portable electronic device

SPECIFICATION


Contact Rating	50mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	180±50gf
Travel	0.20mm
Operating Life	100,000 cycles
Operating Temp.	-30°C ~ +80°C
Storage Temp.	-40°C ~ +90°C

HOW TO ORDER

MTA2 - WNCQR □

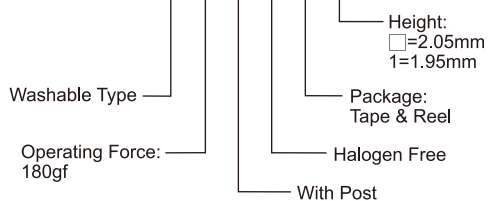

CIRCUIT



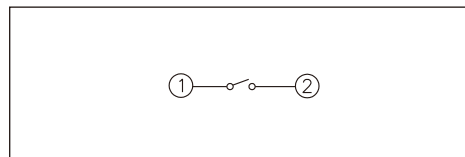


PACKAGE

<Tape & Reel>
3000 pcs




TACT SWITCH

MTA2-WNCQR

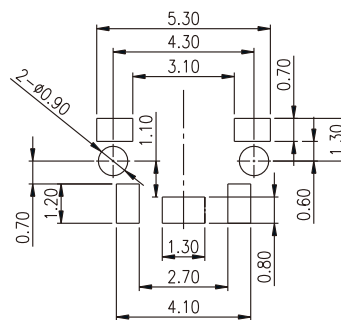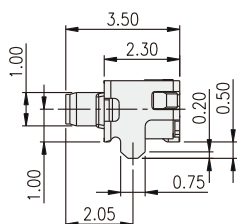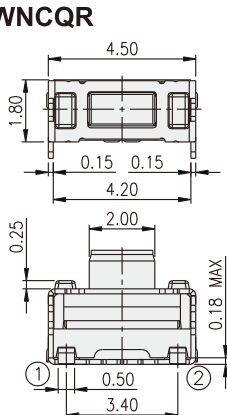

P.C.B. LAYOUT

MTA2-WNCQR1

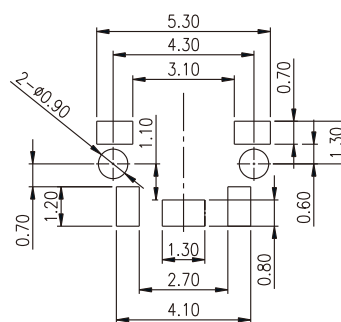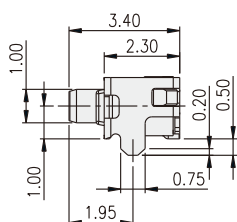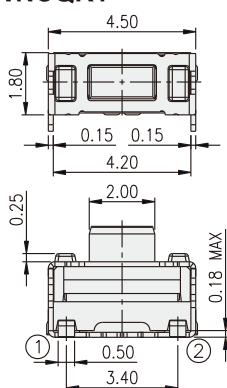

P.C.B. LAYOUT