




Φ5.2x20mm IEC STANDARD FUSE RoHS Compliant & Pb-Free  
LOW-BREAKING CAPACITY GLASS  
TUBE FUSE (TIME-LAG)  
低分断能力玻璃保险丝管 (慢断型)

**BREAKING CAPACITY/ 分断能力:**  
35A OR 10In 250V AC WHICHEVER IS GREATER


**Dimensions/ 尺寸:**

Unit 单位: mm

50T

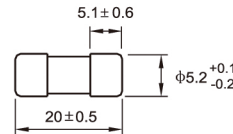

50T(P)

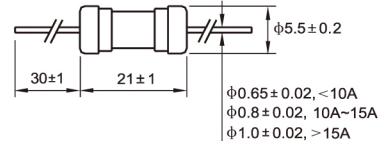

**Standards/ 标准:** IEC 60127 GB 9364

**Operating Temperature/ 工作温度:** -55°C ~125°C


**Storing Temperature/ 储存温度:** -55°C ~85°C

**Resistance to soldering heat/ 耐焊接热性:** 260°C, 10s Max

**Solderability/ 可焊性:** 245°C ±5°C, 5s ±0.5s

**50T AVERAGE I-T CHARACTERISTICS CURVE**  
(FOR REFERENCE ONLY)

**50T 平均 I-T 曲线图 (仅供参考)**

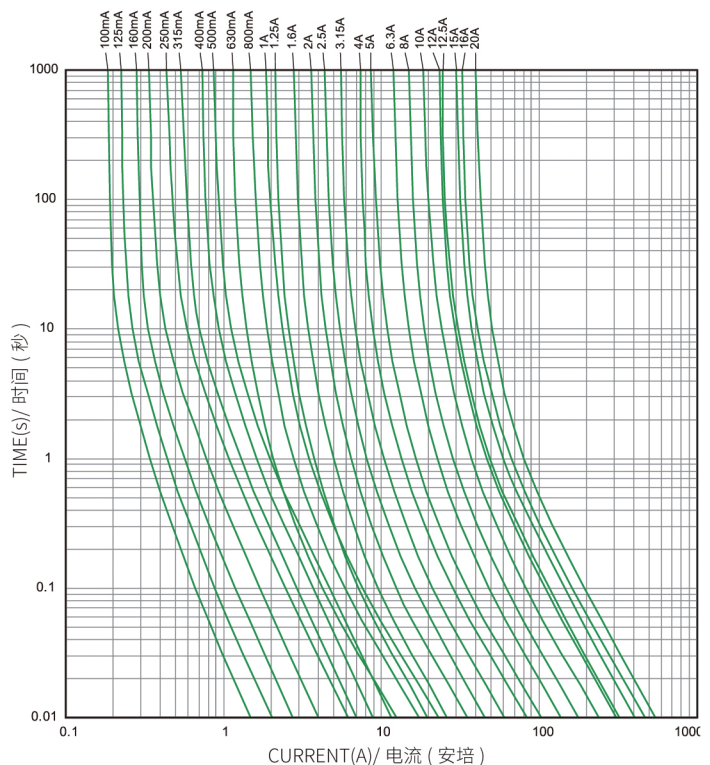

**TECHNICAL PARAMETERS/ 技术参数:**

CATALOG NO. 目录编号	CURRENT RATING 额定电流	MAX. VOLTAGE DROP 最大电压降 (mv)	SAFETY APPROVALS 安全认证									REFERENCE (A <sup>2</sup> .Sec.) (RoHS) I <sup>2</sup> T 参考值	
			CCC	CQC	SEMKO	VDE	BSI	IMQ	UR (CUR)	CSA	PSE		KC
50T-0100H	100mA	2500	●										0.0223
50T-0125H	125mA	2000	●										0.0417
50T-0160H	160mA	1900	●	●	●	●	●	●	●	●	●	●	0.0767
50T-0200H	200mA	1500	●	●	●	●	●	●	●	●	●	●	0.1628
50T-0250H	250mA	1300	●	●	●	●	●	●	●	●	●	●	0.3808
50T-0315H	315mA	1100	●	●	●	●	●	●	●	●	●	●	0.4833
50T-0400H	400mA	1000	●	●	●	●	●	●	●	●	●	●	0.7968
50T-0500H	500mA	900	●	●	●	●	●	●	●	●	●	●	1.362
50T-0630H	630mA	300	●	●	●	●	●	●	●	●	●	●	1.583
50T-0800H	800mA	250	●	●	●	●	●	●	●	●	●	●	3.004
50T-010H	1A	150	●	●	●	●	●	●	●	●	●	●	5.309
50T-013H	1.25A	150	●	●	●	●	●	●	●	●	●	●	3.879
50T-016H	1.6A	150	●	●	●	●	●	●	●	●	●	●	6.890
50T-020H	2A	150	●	●	●	●	●	●	●	●	●	●	12.33
50T-025H	2.5A	120	●	●	●	●	●	●	●	●	●	●	20.63
50T-032H	3.15A	100	●	●	●	●	●	●	●	●	●	●	36.91
50T-040H	4A	100	●	●	●	●	●	●	●	●	●	●	70.56
50T-050H	5A	100	●	●	●	●	●	●	●	●	●	●	108.7
50T-063H	6.3A	100	●	●	●	●	●	●	●	●	●	●	187.8
50T-080H	8A	100	●	●	●	●	●	●	●	●	●	●	314.9
50T-100H	10A	100	●	●	●	●	●	●	●	●	●	●	583.4
50T-120H	12A	80	●	●	●	●	●	●	●	●	●	●	958.9
50T-125H	12.5A	80	●	●	●	●	●	●	●	●	●	●	1045
50T-150H	15A	80	●	●	●	●	●	●	●	●	●	●	1668
50T-160H	16A	80	●	●	●	●	●	●	●	●	●	●	2231
50T-200H	20A	80	●	●	●	●	●	●	●	●	●	●	3010

H DENOTES FOR 250V

H 表示 250V

● DENOTES FOR APPROVED

● 表示已取得安全认证

REMARK 备注:

50T(P)-160H WITHOUT VDE AND SEMKO APPROVAL

50T(P)-160H 产品无 VDE 和 SEMKO 认证

**ELECTRICAL CHARACTERISTICS/ 电气特性:**

RATING 额定		BLOWING TIME 熔断时间		
		100mA	125mA-10A	>10A
2.1In	Max. 最慢	2 minutes	2 minutes	5 minutes
	Min. 最快	200 ms	600 ms	600 ms
2.75In	Max. 最慢	10 seconds	10 seconds	15 seconds
	Min. 最快	40 ms	150 ms	150 ms
4In	Max. 最慢	3 seconds	3 seconds	5 seconds
	Min. 最快	10 ms	20 ms	20 ms
10In	Max. 最慢	300 ms	300 ms	400 ms