 



端子 TERMINAL (PHD)

型号 Type	适用线规 Applicable wires		电线外径 O.D of wire ins mm	数量 Quantity
	mm ²	AWG#		
HX20016-PT	0.08~0.33	28~22	1.0~1.5	10000PCS/包


HX20016-PT (PHD)



 
HX20018-Y (PA)



HX20018-A (PA)

 


HX20018-WA (PA)

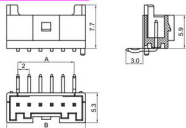


技术参数 SPECIFICATIONS

- ❑ 线数 (Poles) : 2~15(30)
- ❑ 适用线规 (Applicable wires) : AWG28#~22#
- ❑ 适应基板厚度 (Applicable PC board thickness) : 1.6mm
- ❑ 温度范围 (Temperature range) : -25℃~85℃
- ❑ 额定电压 (Voltage rating) : 250V.Ac/Dc
- ❑ 额定电流 (Current rating) : 3A
- ❑ 接触电阻 (Contact resistance) : ≤0.02Ω
- ❑ 绝缘电阻 (Insulation resistance) : ≥1000MΩ
- ❑ 耐压 (Withstand voltage) : 1000V.Ac/1min
- ❑ 材料 (Material) :
 孔座 (Housing) : 尼龙 (PA66) UL94V-2(O)
 针座 (Wafer) : 尼龙 (PA66) UL94V-2(O)
 端子 (Terminal) : 磷青铜 (Phos.bronze Tin/plated)

HX20018-BH (PA)

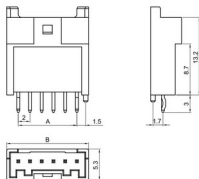

安装尺寸 MOUNTING MEASUREMENT

 

(HX20018-A/BH)

(HX20018-WA)

孔座 HOUSING (PA)

线数 Poles	型号 Type	尺寸Dimensions(mm)		
		A	B	C
2	HX20018-2Y	2.0	4.4	6.0
3	HX20018-3Y	4.0	6.4	8.0
4	HX20018-4Y	6.0	8.4	10.0
5	HX20018-5Y	8.0	10.4	12.0
6	HX20018-6Y	10.0	12.4	14.0
7	HX20018-7Y	12.0	14.4	16.0
8	HX20018-8Y	14.0	16.4	18.0
9	HX20018-9Y	16.0	18.4	20.0
10	HX20018-10Y	18.0	20.4	22.0
11	HX20018-11Y	20.0	22.4	24.0
12	HX20018-12Y	22.0	24.4	26.0
13	HX20018-13Y	24.0	26.4	28.0
14	HX20018-14Y	26.0	28.4	30.0
15	HX20018-15Y	28.0	30.4	32.0
...
30	HX20018-30Y	58.0	60.4	62.0

针座 WAFER (PA)

线数 Poles	型号 Type	尺寸Dimensions(mm)	
		A	B
2	HX20018-2A/WA/BH	2.0	6.0
3	HX20018-3A/WA/BH	4.0	8.0
4	HX20018-4A/WA/BH	6.0	10.0
5	HX20018-5A/WA/BH	8.0	12.0
6	HX20018-6A/WA/BH	10.0	14.0
7	HX20018-7A/WA/BH	12.0	16.0
8	HX20018-8A/WA/BH	14.0	18.0
9	HX20018-9A/WA/BH	16.0	20.0
10	HX20018-10A/WA/BH	18.0	22.0
11	HX20018-11A/WA/BH	20.0	24.0
12	HX20018-12A/WA/BH	22.0	26.0
13	HX20018-13A/WA/BH	24.0	28.0
14	HX20018-14A/WA/BH	26.0	30.0
15	HX20018-15A/WA/BH	28.0	32.0
...
30	HX20018-30A/WA/BH	58.0	62.0