


### 技术参数 SPECIFICATIONS

 
- 线数 (Poles) : 2~15
- 适用线规 (Applicable wires) : AWG28#~24#
- 温度范围 (Temperature range) : -25℃~85℃
- 额定电压 (Voltage rating) : 250V.Ac/Dc
- 额定电流 (Current rating) : 2A
- 接触电阻 (Contact resistance) :  $\leq 0.02\Omega$
- 绝缘电阻 (Insulation resistance) :  $\geq 1000M\Omega$
- 耐压 (Withstand voltage) : 800V.Ac/1min
- 材料 (Material) :
  - 插头 (Plug housing) : 尼龙 (PA66) UL94V-2(0)
  - 插座 (Receptacle housing) : 尼龙 (PA66) UL94V-2(0)
  - 端子 (Terminal) : 磷青铜 (Phos.bronze Tin/plated)

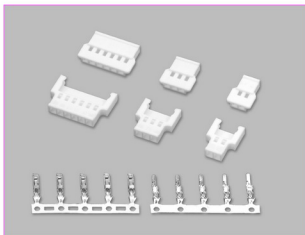


### 端子 TERMINAL (20032)

型号 Type	适用线规 Applicable wires mm <sup>2</sup> AWG#	电线外径 O.D of wire ins mm	数量 Quantity
HX20032-PT	0.08~0.22 28~24	0.9~1.5	
HX20032-RT	0.08~0.22 28~24	0.9~1.5	

### HX20032-PT




### HX20032-P

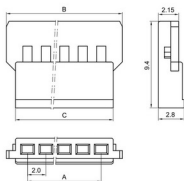


### 安装尺寸 MOUNTING MEASUREMENT


 
### HX20032-RT



### HX20032-R

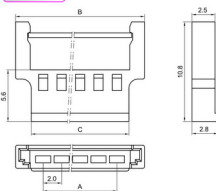

### 插头 PLUG HOUSING (20032)

线数 Poles	型号 Type	尺寸 Dimensions(mm)		
		A	B	C
2	HX20032-2P	2.0	6.6	4.6
3	HX20032-3P	4.0	8.6	6.6
4	HX20032-4P	6.0	10.6	8.6
5	HX20032-5P	8.0	12.6	10.6
6	HX20032-6P	10.0	14.6	12.6
7	HX20032-7P	12.0	16.6	14.6
8	HX20032-8P	14.0	18.6	16.6
9	HX20032-9P	16.0	20.6	18.6
10	HX20032-10P	18.0	22.6	20.6
11	HX20032-11P	20.0	24.6	22.6
12	HX20032-12P	22.0	26.6	24.6
13	HX20032-13P	24.0	28.6	26.6
14	HX20032-14P	26.0	30.6	28.6
15	HX20032-15P	28.0	32.6	30.6

### 插座 RECEPTACLE HOUSING (20032)

线数 Poles	型号 Type	尺寸 Dimensions(mm)		
		A	B	C
2	HX20032-2R	2.0	8.0	4.6
3	HX20032-3R	4.0	10.0	6.6
4	HX20032-4R	6.0	12.0	8.6
5	HX20032-5R	8.0	14.0	10.6
6	HX20032-6R	10.0	16.0	12.6
7	HX20032-7R	12.0	18.0	14.6
8	HX20032-8R	14.0	20.0	16.6
9	HX20032-9R	16.0	22.0	18.6
10	HX20032-10R	18.0	24.0	20.6
11	HX20032-11R	20.0	26.0	22.6
12	HX20032-12R	22.0	28.0	24.6
13	HX20032-13R	24.0	30.0	26.6
14	HX20032-14R	26.0	32.0	28.6
15	HX20032-15R	28.0	34.0	30.6