


■ 技术参数 SPECIFICATIONS

- 适用线规 (Applicable wires) : AWG24#~16#
- 温度范围 (Temperature range) : -25℃~85℃
- 额定电压 (Voltage rating) : 300V.Ac/Dc
- 额定电流 (Current rating) : 15A max
- 接触电阻 (Contact resistance) : ≤0.01Ω
- 绝缘电阻 (Insulation resistance) : ≥1000MΩ
- 耐压 (Withstand voltage) : 2000V.Ac/1min
- 材料 (Material) :
 - 壳体 (Housing) : 尼龙 (PA66) UL94V-2 (0)
 - 端子 (Terminal) : 黄铜 (Brass Tin/plated)
 - 磷青铜 (phos.bronze Tin/plated)

.187" /250# 端子 TERMINAL

型号 Type	适用线规 Applicable wires	尺寸 Dimensions (mm)				示意图 Sample	数量 Quantity			
		mm ²	AWG#	材料 Material	W			L	E	材料厚度 Thickness
HX480N-01T	STO-01T-187N	0.2~0.5	24~20		5.7	15.0	6.5	0.35		10000PCS/卷
HX480N-41T	STO-41T-187N	0.5~1.25	20~16	黄铜 Brass	5.7	15.0	6.5	0.35	A	10000PCS/卷
HX480N-61T	STO-61T-187N		(UL1015) 20+18		5.7	15.0	6.5	0.35		10000PCS/卷
HX4.8Z-21T	730494-3	0.5~1.25	20~16	磷青铜 Phos.bronze	5.6	18.0	6.0	0.3	B	2500PCS/盒

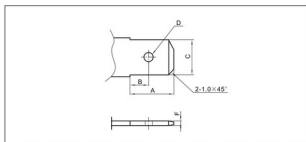

型号 Type	尺寸 Dimensions (mm)				
	A	B	C	D	F
.187"	7.0	3.6	4.8	φ1.5	0.5

