


技术参数 SPECIFICATIONS

- 适用线规 (Applicable wires) : AWG24#~12#
- 温度范围 (Temperature range) : -20℃~85℃
- 额定电压 (Voltage rating) : 300V.Ac/Dc
- 额定电流 (Current rating) : 18A max
- 接触电阻 (Contact resistance) : $\leq 0.01\Omega$
- 绝缘电阻 (Insulation resistance) : $\geq 1000M\Omega$
- 耐压 (Withstand voltage) : 1500V.Ac/1min
- 材料 (Material) :
 壳体 (Housing) : 尼龙 (PA66) UL94V-0
 端子 (Terminal) : 磷青铜 (Phos.bronze Tin/plated)
 黄铜 (Brass Tin/plated)

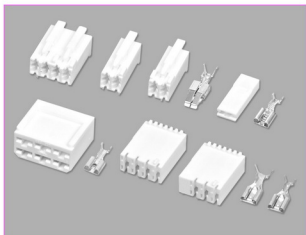


端子 TERMINAL


型号 Type	适用线规 Applicable wires mm ² AWG#	材料 Material	材料厚度 Thickness mm	数量 Quantity
HX50008-01PT	0.22~0.5 24~20	黄铜 Brass	0.3	2000PCS/包
HX50008-21PT	0.75~2.0 18~14		0.3	1500PCS/包
HX630N-21T	0.3~0.75 22~18		0.4	7000PCS/包
HX630N-41T	0.75~2.0 18~14		0.4	6000PCS/包

型号 Type	适用线规 Applicable wires mm ² AWG#	材料 Material	材料厚度 Thickness mm	数量 Quantity
HXA3BS-21PT	1217378-2 0.3~0.75 22~18	黄铜 Brass	0.3	4000PCS/包
HXA3BS-41PT	1217095-2 1.25~3.5 16~12		0.3	
HX63092-PT	0.52~2.1 20~14		0.35	

 
HX50008-PT




HX50007-2P (5-928247-2)

 

HX50007-2R (8-928247-2)

 


HX50007-4P (4-928247-4)

 


HX630N-T



 
HX630S-250ZK (6-735075-1)




HX6.3BS-T (1217378-2, 1217095-2)

 


HX50006-4Y (521206-1)

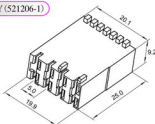

HX50006-4Y3 (521206)

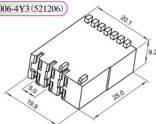

HX63092-PT (160928-2) DJ623-E6.3A-B

 

HX63091-6P (925276-0, 880297-1) DJ7065-6.3-21

