

SPECIFICATIONS


Rated Current: 3.0AMP
 Contact Resistance: 30mΩ Max
 Withstand Voltage: 1000V AC/DC
 Insulation Resistance: 1000MΩ Min
 Operation Temperature: -40°C to +105°C

Contact Material: Brass
 Contact Plating: Au or Sn Over Ni
 Insulator Material: Polyester (UL94V-0)
 Standard: PBT
 Max. Processing Temp: 180°C for 30-60 seconds
 (200°C for 10 seconds)

Ordering Information

35112 XX B F S XX BNA1

No. of Pins	Contact Type	Contact Plating
210	F=Femle	60:Gold Flash
216		S0:Gold Flash/Tin
220		S1:2U" Gold/Tin
232		S2:5U" Gold/Tin
244		S3:10U" Gold/Tin
248		S4:15U" Gold/Tin
250		S5:30U" Gold/Tin
264		SN:Tin

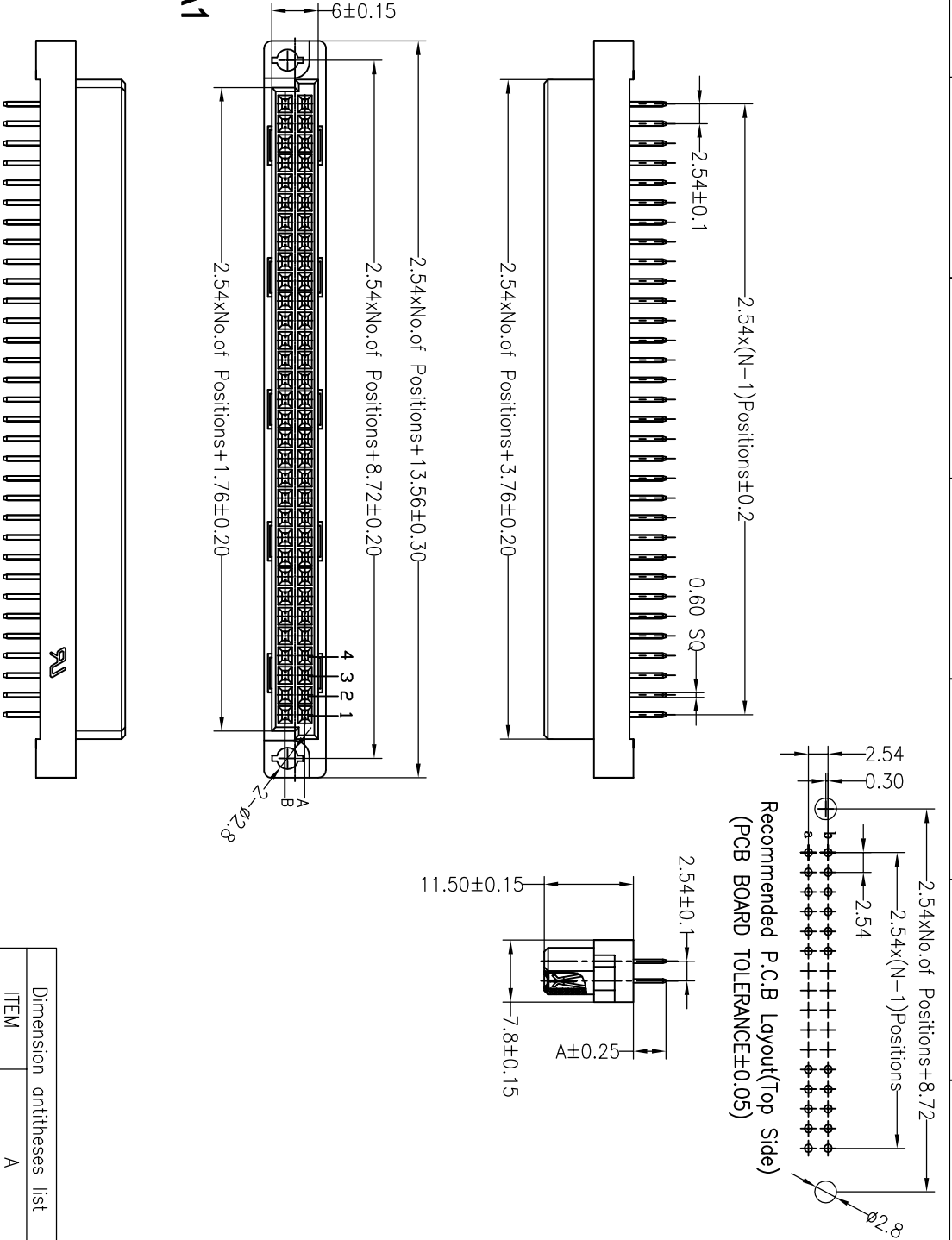

Dimension antitheses list	
ITEM	A
Standard	4.00
Alternate	

REV	DATE	MODIFICATION DESCRIPTION	CHANGE	DIM	TOL	APPROVE	SCALE	FIT	SHEET	PROJ.	TITLE:
A0	2015.04.06	NEW DRAWING		X:XXX	±0.10	CHECK	A4	1/1			PART NO. 35112XXBFSXXBNA1
1											DIN 41612 180° 2xNPIN Femle

JIN 深圳市锦凌电子有限公司
 SHENZHEN JINLING ELECTRONIC CO.,LTD
 Tel: 86-755-2997-5806/5802 Fax: 86-755-2997-5892