
 




1111 KSS 六角隔离柱

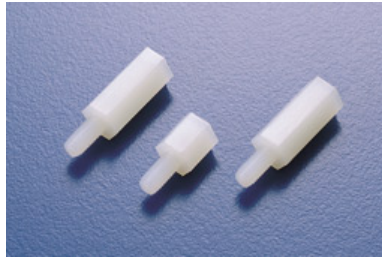

材质： UL合格之NYLON 66（本色），防火等级 94V-2。
用法： 使用螺丝及螺帽即可将基板与机板隔离。
特点： 长度不够时可再延伸。



							单位：mm
型号 Item No.	A	B	C/D	L	L1	包装 Packing	
<input type="checkbox"/> HTS-205	4.0	5.0	M2 x 0.4	5.0	4.0	100 pcs / 包	
<input type="checkbox"/> HTS-208	4.0	5.0		8.0	6.0		
<input type="checkbox"/> HTS-210	4.0	5.0		10.0	6.0		
<input type="checkbox"/> HTS-215	4.0	5.0		15.0	6.0		
<input type="checkbox"/> HTS-306	5.6	6.0	M3 x 0.5	6.0	5.3		
<input type="checkbox"/> HTS-308	5.6	6.0		8.0	7.5		
<input type="checkbox"/> HTS-310	5.6	6.0		10.0	6.5		
<input type="checkbox"/> HTS-312	5.6	6.0		12.7	10.0		
<input type="checkbox"/> HTS-315	5.6	6.0		15.0	10.0		
<input type="checkbox"/> HTS-317	5.5	6.0		17.0	10.0		
<input type="checkbox"/> HTS-318	5.6	6.0		18.0	10.0		
<input type="checkbox"/> HTS-320	5.6	6.0		20.0	10.0		
<input type="checkbox"/> HTS-322	5.6	6.0		22.0	10.0		
<input type="checkbox"/> HTS-325	5.6	6.0		25.0	10.0		
<input type="checkbox"/> HTS-330	5.6	6.0	30.0	10.0			
<input type="checkbox"/> HTS-410	7.0	6.0	M4 x 0.7	10.1	10.0		
<input type="checkbox"/> HTS-413	7.0	6.0		13.0	7.0		
<input type="checkbox"/> HTS-415	7.0	6.0		15.0	10.0		
<input type="checkbox"/> HTS-419	7.0	6.0		19.0	10.0		
<input type="checkbox"/> HTS-425	7.0	6.0		25.0	10.0		
<input type="checkbox"/> HTS-430	7.0	6.0		30.0	10.0		

放入选样单

查看选样单

退回所有选样