
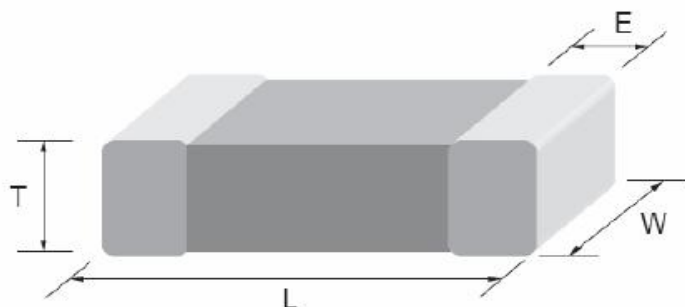


PRODUCT: High Current Chip Ferrite Bead

SERIES: PBBHAQ1005(0402大电流)

PACKAGING DIMENSION: [Unit: mm] (10K/Reel)

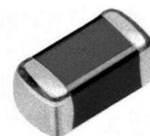

L	1.00±0.10
W	0.50±0.10
T	0.50±0.10
E	0.25±0.10

GENERAL SPECIFICATIONS:



P/N	Impedance (Ω)	Tolerance (±%)	Test Frequency (MHz)	DC Resitance (Rdc)Max. (Ω)	Rated Current (Idc)Max. (mA)
PBBHAQ1005S-100T20	10.0	25	100	0.050	2000
PBBHAQ1005S-300T20	30.0	25	100	0.060	2000
PBBHAQ1005S-600T20	60.0	25	100	0.070	2000
PBBHAQ1005S-900T20	90.0	25	100	0.090	2000
PBBHAQ1005S-121T20	120.0	25	100	0.095	2000
PBBHAQ1005S-221T10	220.0	25	100	0.130	1000
PBBHAQ1005S-601T08	600.0	25	100	0.340	800
PBBHAQ1005S-102T05	1000.0	25	100	0.830	500

备注:

© 储存条件: Less than 40°C and 70% RH

© 电感工作环境温度: -55°C~125°C, 产品最终承受温度不得高于125°C

© 系列规格书只用于电感一般特性的参考, 产品适用场景及更详细的参数, 请向我司索取单颗产品的规格书



PROD TECHNOLOGY CO., LTD.

TEL :0755-86667379

<http://www.prodtech.cn>



E-LIVEN TECHNOLOGY CO., LTD.

NO.28 ho-cheng RD, bade city, taoyuan, taiwan