


金屬化聚丙烯膜電容器 (盒裝型) SMPC series

■ 外觀圖 Outline Drawing

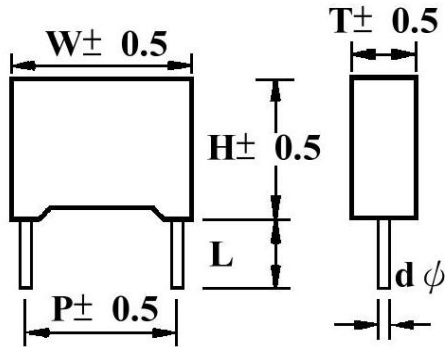

■ 主要用途:

廣泛用於高頻·直流·交流和脈衝電路中
適用於各種高頻·大電流場合

■ 特點:

金屬化聚丙烯膜, 無感捲繞結構

高頻損耗小

內部溫升小

塑膠外殼, 阻燃環氧樹脂填充

■ Typical Applications

Widely used in high frequency, DC, AC and pulse circuits
Suitable for the situation where applies high frequency and high current pulse.

■ Features

Metalized polypropylene film,
non-inductive wound construction
Low loss at high frequency
Small inherent temperature rise
Plastic case (UL94v-0), Epoxy resin sealing.

■ 技術要求 Specifications

引用標準 Reference Standard	GB/T 10190 (IEC 60384-16)	
氣候類別 Climatic Category	55/105/56	
工作溫度範圍 Operating Temperature Range	-40°C~+105°C (+85°C to +105°C: decreasing factor 1.25% per °C for UR)	
電容量範圍 Capacitance Range	0.00056uF ~ 15μF	
額定電壓 Rated (DC) Voltage	160V , 250V , 400V , 630V , 1000V , 1600V , 2000Vdc	
額定電壓 Rated (AC) Voltage	90V , 160V , 220V , 250V , 400V , 600Vac	
電容偏差 Capacitance Tolerance	±5%(J) 、 ±10%(K)	
承受電壓 Voltage Proof	1.5UR (5s)	
損耗角 Dissipation Factor	≤ 0.1% (20°C, 1kHz)	
絕緣電阻 Insulation Resistance	UR ≤	C _R ≤ 0.33uF IR ≥ 15,000MΩ
	100V	C _R > 0.33uF IR ≥ 5,000MΩ/Cap(μF)

Metallized Polypropylene Film Capacitor
 金屬化聚丙烯膜電容器 (盒裝型) SMPC series



■ 外型尺寸表 Dimensions (mm)

160Vdc (90Vac)						
容量 μF	W	H	T	P	d	產品代碼 Part number
0.027	7.2	7.5	3.5	5	0.5	SMPC_273*0160D*05**
0.033	7.2	7.5	3.5	5	0.5	SMPC_333*0160D*05**
0.039	7.2	7.5	3.5	5	0.5	SMPC_393*0160D*05**
0.047	7.2	9.5	4.5	5	0.5	SMPC_473*0160D*05**
0.056	7.2	9.5	4.5	5	0.5	SMPC_563*0160D*05**
0.068	7.2	9.5	4.5	5	0.5	SMPC_683*0160D*05**
0.082	7.2	10	5	5	0.5	SMPC_823*0160D*05**
0.1	7.2	10	5	5	0.5	SMPC_104*0160D*05**
0.12	7.2	11	6	5	0.5	SMPC_124*0160D*05**
0.15	7.2	11	6	5	0.5	SMPC_154*0160D*05**
0.068	10.5	9	4	7.5	0.6	SMPC_683*0160D*08**
0.082	10.5	9	4	7.5	0.6	SMPC_823*0160D*08**
0.1	10.5	11	5	7.5	0.6	SMPC_104*0160D*08**
0.12	10.5	11	5	7.5	0.6	SMPC_124*0160D*08**
0.15	10.5	12	6	7.5	0.6	SMPC_154*0160D*08**
0.18	10.5	12	6	7.5	0.6	SMPC_184*0160D*08**
0.082	13	9	4	10	0.6	SMPC_823*0160D*10**
0.1	13	9	4	10	0.6	SMPC_104*0160D*10**
0.12	13	11	5	10	0.6	SMPC_124*0160D*10**
0.15	13	11	5	10	0.6	SMPC_154*0160D*10**
0.18	13	11	5	10	0.6	SMPC_184*0160D*10**
0.22	13	12	6	10	0.6	SMPC_224*0160D*10**
0.27	13	12	6	10	0.6	SMPC_274*0160D*10**
0.18	18	11	5	15	0.8	SMPC_184*0160D*15**
0.22	18	11	5	15	0.8	SMPC_224*0160D*15**
0.27	18	11	5	15	0.8	SMPC_274*0160D*15**
0.33	18	11	5	15	0.8	SMPC_334*0160D*15**
0.39	18	12	6	15	0.8	SMPC_394*0160D*15**
0.47	18	12	6	15	0.8	SMPC_474*0160D*15**
0.56	18	13.5	7.5	15	0.8	SMPC_564*0160D*15**
0.68	18	13.5	7.5	15	0.8	SMPC_684*0160D*15**

160Vdc (90Vac)						
容量 μF	W	H	T	P	d	產品代碼 Part number
0.82	18	14.5	8.5	15	0.8	SMPC_824*0160D*15**
1.0	18	15.5	9.5	15	0.8	SMPC_105*0160D*15**
1.2	18	15.5	9.5	15	0.8	SMPC_125*0160D*15**
1.5	18	19	11	15	0.8	SMPC_155*0160D*15**
1.8	18	19	11	15	0.8	SMPC_185*0160D*15**
0.47	25.5	15	6	22.5	0.8	SMPC_474*0160D*23**
0.56	25.5	15	6	22.5	0.8	SMPC_564*0160D*23**
0.68	25.5	15	6	22.5	0.8	SMPC_684*0160D*23**
0.82	25.5	16	7	22.5	0.8	SMPC_824*0160D*23**
1.0	25.5	16	7	22.5	0.8	SMPC_105*0160D*23**
1.2	25.5	17	8.5	22.5	0.8	SMPC_125*0160D*23**
1.5	25.5	17	8.5	22.5	0.8	SMPC_155*0160D*23**
1.8	25.5	18.5	10	22.5	0.8	SMPC_185*0160D*23**
2.2	25.5	20	11	22.5	0.8	SMPC_225*0160D*23**
2.7	25.5	22	12	22.5	0.8	SMPC_275*0160D*23**
3.3	25.5	22	12	22.5	0.8	SMPC_335*0160D*23**
1.0	25.5	18	9	22.5	0.8	SMPC_105*0160D*23**
1.2	25.5	18	9	22.5	0.8	SMPC_125*0160D*23**
1.5	25.5	18	9	22.5	0.8	SMPC_155*0160D*23**
1.8	25.5	18	9	22.5	0.8	SMPC_185*0160D*23**
2.2	25.5	18	9	22.5	0.8	SMPC_225*0160D*23**
2.7	25.5	20	11	22.5	0.8	SMPC_275*0160D*23**
3.3	25.5	20	11	22.5	0.8	SMPC_335*0160D*23**
3.9	32	22	13	27.5	0.8	SMPC_395*0160D*28**
4.7	32	28	14	27.5	0.8	SMPC_475*0160D*28**
5.6	32	24.5	15	27.5	0.8	SMPC_565*0160D*28**
6.8	32	33	18	27.5	0.8	SMPC_685*0160D*28**
8.2	32	33	18	27.5	0.8	SMPC_825*0160D*28**
10	32	33	18	27.5	0.8	SMPC_106*0160D*28**
12	32	37	22	27.5	0.8	SMPC_126*0160D*28**
15	32	37	22	27.5	0.8	SMPC_156*0160D*28**

Metallized Polypropylene Film Capacitor
 金屬化聚丙烯膜電容器 (盒裝型) SMPC series



■ 外型尺寸表 Dimensions (mm)

250Vdc (160Vac)						
容量 μF	W	H	T	P	d	產品代碼 Part number
0.012	7.2	7.5	3.5	5	0.5	SMPC_123*0250D*05**
0.015	7.2	7.5	3.5	5	0.5	SMPC_153*0250D*05**
0.022	7.2	7.5	3.5	5	0.5	SMPC_223*0250D*05**
0.027	7.2	7.5	3.5	5	0.5	SMPC_273*0250D*05**
0.033	7.2	7.5	3.5	5	0.5	SMPC_333*0250D*05**
0.047	7.2	9.5	4.5	5	0.5	SMPC_473*0250D*05**
0.068	7.2	10	5	5	0.5	SMPC_683*0250D*05**
0.082	7.2	10	5	5	0.5	SMPC_823*0250D*05**
0.1	7.2	11	6	5	0.5	SMPC_104*0250D*05**
0.12	7.2	11	6	5	0.5	SMPC_124*0250D*05**
0.027	10.5	9	4	7.5	0.6	SMPC_123*0250D*08**
0.033	10.5	9	4	7.5	0.6	SMPC_333*0250D*08**
0.047	10.5	9	4	7.5	0.6	SMPC_473*0250D*08**
0.068	10.5	9	4	7.5	0.6	SMPC_683*0250D*08**
0.082	10.5	11	5	7.5	0.6	SMPC_823*0250D*08**
0.1	10.5	11	5	7.5	0.6	SMPC_104*0250D*08**
0.12	10.5	11	5	7.5	0.6	SMPC_124*0250D*08**
0.15	10.5	12	6	7.5	0.6	SMPC_154*0250D*08**
0.18	10.5	12	6	7.5	0.6	SMPC_184*0250D*08**
0.033	13	9	4	10	0.6	SMPC_333*0250D*10**
0.047	13	9	4	10	0.6	SMPC_473*0250D*10**
0.068	13	9	4	10	0.6	SMPC_683*0250D*10**
0.082	13	9	4	10	0.6	SMPC_823*0250D*10**
0.1	13	11	5	10	0.6	SMPC_104*0250D*10**
0.12	13	11	5	10	0.6	SMPC_124*0250D*10**
0.15	13	11	5	10	0.6	SMPC_154*0250D*10**
0.18	13	12	6	10	0.6	SMPC_184*0250D*10**
0.22	13	12	6	10	0.6	SMPC_224*0250D*10**
0.1	18	11	5	15	0.8	SMPC_104*0250D*15**
0.12	18	11	5	15	0.8	SMPC_124*0250D*15**
0.15	18	11	5	15	0.8	SMPC_154*0250D*15**

250Vdc (160Vac)						
容量 μF	W	H	T	P	d	產品代碼 Part number
0.18	18	11	5	15	0.8	SMPC_184*0250D*15**
0.22	18	11	5	15	0.8	SMPC_224*0250D*15**
0.27	18	12	6	15	0.8	SMPC_274*0250D*15**
0.33	18	12	6	15	0.8	SMPC_334*0250D*15**
0.47	18	13.5	7.5	15	0.8	SMPC_474*0250D*15**
0.68	18	14.5	8.5	15	0.8	SMPC_684*0250D*15**
0.82	18	15.5	9.5	15	0.8	SMPC_824*0250D*15**
1.0	18	15.5	9.5	15	0.8	SMPC_105*0250D*15**
1.2	18	19	11	15	0.8	SMPC_125*0250D*15**
0.47	26.5	15	6	22.5	0.8	SMPC_474*0250D*23**
0.68	26.5	15	6	22.5	0.8	SMPC_684*0250D*23**
0.82	26.5	15	6	22.5	0.8	SMPC_824*0250D*23**
1.0	26.5	16	7	22.5	0.8	SMPC_105*0250D*23**
1.2	26.5	17	8.5	22.5	0.8	SMPC_125*0250D*23**
1.5	26.5	17	8.5	22.5	0.8	SMPC_155*0250D*23**
1.8	26.5	18.5	10	22.5	0.8	SMPC_185*0250D*23**
2.2	26.5	20	11	22.5	0.8	SMPC_225*0250D*23**
2.7	26.5	22	12	22.5	0.8	SMPC_275*0250D*23**
0.82	32	18	9	27.5	0.8	SMPC_824*0250D*28**
1.0	32	18	9	27.5	0.8	SMPC_105*0250D*28**
1.5	32	18	9	27.5	0.8	SMPC_155*0250D*28**
2.2	32	18	9	27.5	0.8	SMPC_225*0250D*28**
2.7	32	20	11	27.5	0.8	SMPC_275*0250D*28**
3.3	32	20	11	27.5	0.8	SMPC_335*0250D*28**
3.9	32	22	13	27.5	0.8	SMPC_395*0250D*28**
4.7	32	28	14	27.5	0.8	SMPC_475*0250D*28**
5.6	32	24.5	15	27.5	0.8	SMPC_565*0250D*28**
6.8	32	33	18	27.5	0.8	SMPC_685*0250D*28**
8.2	32	33	18	27.5	0.8	SMPC_825*0250D*28**
10	32	33	18	27.5	0.8	SMPC_106*0250D*28**
15	32	37	22	27.5	0.8	SMPC_156*0250D*28**

Metallized Polypropylene Film Capacitor
 金屬化聚丙烯膜電容器 (盒裝型) SMPC series



■ 外型尺寸表 Dimensions (mm)

400Vdc (220Vac)						
容量 μF	W	H	T	P	d	產品代碼 Part number
0.0039	7.2	7.5	3.5	5	0.5	SMPC_392_0400D*05**
0.0047	7.2	7.5	3.5	5	0.5	SMPC_472_0400D*05**
0.0068	7.2	7.5	3.5	5	0.5	SMPC_682_0400D*05**
0.01	7.2	7.5	3.5	5	0.5	SMPC_103_0400D*05**
0.012	7.2	7.5	3.5	5	0.5	SMPC_123_0400D*05**
0.015	7.2	9.5	4.5	5	0.5	SMPC_153_0400D*05**
0.022	7.2	9.5	4.5	5	0.5	SMPC_223_0400D*05**
0.027	7.2	10	5	5	0.5	SMPC_273_0400D*05**
0.033	7.2	11	6	5	0.5	SMPC_333_0400D*05**
0.039	7.2	11	6	5	0.5	SMPC_393_0400D*05**
0.047	7.2	11	6	5	0.5	SMPC_473_0400D*05**
0.01	10.5	9	4	7.5	0.6	SMPC_103_0400D*08**
0.012	10.5	9	4	7.5	0.6	SMPC_123_0400D*08**
0.015	10.5	9	4	7.5	0.6	SMPC_153_0400D*08**
0.022	10.5	9	4	7.5	0.6	SMPC_223_0400D*08**
0.027	10.5	9	4	7.5	0.6	SMPC_273_0400D*08**
0.033	10.5	11	5	7.5	0.6	SMPC_333_0400D*08**
0.047	10.5	11	5	7.5	0.6	SMPC_473_0400D*08**
0.068	10.5	12	6	7.5	0.6	SMPC_683_0400D*08**
0.015	13	9	4	10	0.6	SMPC_153_0400D*10**
0.018	13	9	4	10	0.6	SMPC_183_0400D*10**
0.022	13	9	4	10	0.6	SMPC_223_0400D*10**
0.027	13	9	4	10	0.6	SMPC_273_0400D*10**
0.033	13	9	4	10	0.6	SMPC_333_0400D*10**
0.039	13	9	4	10	0.6	SMPC_393_0400D*10**
0.047	13	11	5	10	0.6	SMPC_473_0400D*10**
0.056	13	11	5	10	0.6	SMPC_563_0400D*10**
0.068	13	11	5	10	0.6	SMPC_683_0400D*10**
0.082	13	12	6	10	0.6	SMPC_823_0400D*10**
0.1	13	12	6	10	0.6	SMPC_104_0400D*10**

400Vdc (220Vac)						
容量 μF	W	H	T	P	d	產品代碼 Part number
0.1	18	11	5	15	0.8	SMPC_104_0400D*15**
0.12	18	11	5	15	0.8	SMPC_124_0400D*15**
0.15	18	12	6	15	0.8	SMPC_154_0400D*15**
0.18	18	12	6	15	0.8	SMPC_184_0400D*15**
0.22	18	13.5	7.5	15	0.8	SMPC_224_0400D*15**
0.33	18	14.5	8.5	15	0.8	SMPC_334_0400D*15**
0.39	18	15.5	9.5	15	0.8	SMPC_394_0400D*15**
0.47	18	15.5	9.5	15	0.8	SMPC_474_0400D*15**
0.68	18	19	11	15	0.8	SMPC_684_0400D*15**
0.18	26.5	15	6	22.5	0.8	SMPC_184_0400D*23**
0.22	26.5	15	6	22.5	0.8	SMPC_224_0400D*23**
0.33	26.5	15	6	22.5	0.8	SMPC_334_0400D*23**
0.39	26.5	16	7	22.5	0.8	SMPC_394_0400D*23**
0.47	26.5	16	7	22.5	0.8	SMPC_474_0400D*23**
0.68	26.5	17	8.5	22.5	0.8	SMPC_684_0400D*23**
0.82	26.5	18.5	10	22.5	0.8	SMPC_824_0400D*23**
1.0	26.5	20	11	22.5	0.8	SMPC_105_0400D*23**
1.2	26.5	22	12	22.5	0.8	SMPC_125_0400D*23**
1.5	26.5	22	12	22.5	0.8	SMPC_155_0400D*23**
0.68	32	18	9	27.5	0.8	SMPC_684_0400D*28**
1.0	32	18	9	27.5	0.8	SMPC_105_0400D*28**
1.2	32	20	11	27.5	0.8	SMPC_125_0400D*28**
1.5	32	20	11	27.5	0.8	SMPC_155_0400D*28**
1.8	32	22	13	27.5	0.8	SMPC_185_0400D*28**
2.2	32	24.5	15	27.5	0.8	SMPC_225_0400D*28**
2.7	32	28	14	27.5	0.8	SMPC_275_0400D*28**
3.3	32	33	18	27.5	0.8	SMPC_335_0400D*28**
3.9	32	33	18	27.5	0.8	SMPC_395_0400D*28**
4.7	32	37	22	27.5	0.8	SMPC_475_0400D*28**
5.6	32	37	22	27.5	0.8	SMPC_565_0400D*28**

Metallized Polypropylene Film Capacitor
 金屬化聚丙烯膜電容器 (盒裝型) SMPC series



■ 外型尺寸表 Dimensions (mm)

630Vdc (250Vac)						
容量 μF	W	H	T	P	d	產品代碼 Part number
0.001	7.2	7.5	3.5	5	0.5	SMPC_102*0630D*05**
0.0033	7.2	7.5	3.5	5	0.5	SMPC_332*0630D*05**
0.0039	7.2	9.5	4.5	5	0.5	SMPC_392*0630D*05**
0.0047	7.2	9.5	4.5	5	0.5	SMPC_472*0630D*05**
0.0056	7.2	10	5	5	0.5	SMPC_562*0630D*05**
0.0068	7.2	10	5	5	0.5	SMPC_682*0630D*05**
0.0082	7.2	11	6	5	0.5	SMPC_822*0630D*05**
0.01	7.2	11	6	5	0.5	SMPC_103*0630D*05**
0.012	7.2	11	6	5	0.5	SMPC_123*0630D*05**
0.001	10.5	9	4	7.5	0.6	CMPC_102*0630D*08**
0.0033	10.5	9	4	7.5	0.6	CMPC_332*0630D*08**
0.0068	10.5	9	4	7.5	0.6	CMPC_682*0630D*08**
0.01	10.5	9	4	7.5	0.6	CMPC_103*0630D*08**
0.012	10.5	9	4	7.5	0.6	CMPC_123*0630D*08**
0.015	10.5	11	5	7.5	0.6	CMPC_153*0630D*08**
0.018	10.5	11	5	7.5	0.6	CMPC_183*0630D*08**
0.022	10.5	11	5	7.5	0.6	CMPC_223*0630D*08**
0.027	10.5	12	6	7.5	0.6	SMPC_273*0630D*08**
0.033	10.5	12	6	7.5	0.6	SMPC_333*0630D*08**
0.001	13	9	4	10	0.6	SMPC_102*0630D*10**
0.0012	13	9	4	10	0.6	SMPC_122*0630D*10**
0.0015	13	9	4	10	0.6	SMPC_152*0630D*10**
0.0022	13	9	4	10	0.6	SMPC_222*0630D*10**
0.0033	13	9	4	10	0.6	SMPC_332*0630D*10**
0.0047	13	9	4	10	0.6	SMPC_472*0630D*10**
0.0068	13	9	4	10	0.6	SMPC_682*0630D*10**
0.01	13	9	4	10	0.6	SMPC_103*0630D*10**
0.018	13	9	4	10	0.6	SMPC_183*0630D*10**
0.022	13	11	5	10	0.6	SMPC_223*0630D*10**
0.033	13	11	5	10	0.6	SMPC_333*0630D*10**
0.047	13	12	6	10	0.6	SMPC_473*0630D*10**

630Vdc (250Vac)						
容量 μF	W	H	T	P	d	產品代碼 Part number
0.033	18	11	5	15	0.8	SMPC_333*0630D*15**
0.047	18	11	5	15	0.8	SMPC_473*0630D*15**
0.068	18	12	6	15	0.8	SMPC_683*0630D*15**
0.082	18	12	6	15	0.8	SMPC_823*0630D*15**
0.1	18	13.5	7.5	15	0.8	SMPC_104*0630D*15**
0.15	18	13.5	7.5	15	0.8	SMPC_154*0630D*15**
0.18	18	14.5	8.5	15	0.8	SMPC_184*0630D*15**
0.22	18	15.5	9.5	15	0.8	SMPC_224*0630D*15**
0.27	18	19	11	15	0.8	SMPC_274*0630D*15**
0.33	18	19	11	15	0.8	SMPC_334*0630D*15**
0.1	26.5	15	6	22.5	0.8	SMPC_104*0630D*23**
0.15	26.5	15	6	22.5	0.8	SMPC_154*0630D*23**
0.22	26.5	16	7	22.5	0.8	SMPC_224*0630D*23**
0.27	26.5	17	8.5	22.5	0.8	SMPC_274*0630D*23**
0.33	26.5	17	8.5	22.5	0.8	SMPC_334*0630D*23**
0.39	26.5	19	10	22.5	0.8	SMPC_394*0630D*23**
0.47	26.5	19	10	22.5	0.8	SMPC_474*0630D*23**
0.56	26.5	20	11	22.5	0.8	SMPC_564*0630D*23**
0.68	26.5	22	12	22.5	0.8	SMPC_684*0630D*23**
0.33	32	18	9	27.5	0.8	SMPC_334*0630D*28**
0.47	32	18	9	27.5	0.8	SMPC_474*0630D*28**
0.56	32	20	11	27.5	0.8	SMPC_564*0630D*28**
0.82	32	20	11	27.5	0.8	SMPC_824*0630D*28**
1.0	32	22	13	27.5	0.8	SMPC_105*0630D*28**
1.2	32	24.5	15	27.5	0.8	SMPC_125*0630D*28**
1.5	32	28	14	27.5	0.8	SMPC_155*0630D*28**
1.8	32	33	18	27.5	0.8	SMPC_185*0630D*28**
2.2	32	33	18	27.5	0.8	SMPC_225*0630D*28**
2.7	32	37	22	27.5	0.8	SMPC_275*0630D*28**
3.3	32	37	22	27.5	0.8	SMPC_335*0630D*28**

Metallized Polypropylene Film Capacitor
 金屬化聚丙烯膜電容器 (盒裝型) SMPC series



■ 外型尺寸表 Dimensions (mm)

1000Vdc (400Vac)						
容量 μF	W	H	T	P	d	產品代碼 Part number
0.001	13	9	4	10	0.6	SMPC_102*1000D*10**
0.0022	13	9	4	10	0.6	SMPC_222*1000D*10**
0.0033	13	9	4	10	0.6	SMPC_332*1000D*10**
0.0039	13	9	4	10	0.6	SMPC_392*1000D*10**
0.0047	13	11	5	10	0.6	SMPC_472*1000D*10**
0.0068	13	11	5	10	0.6	SMPC_682*1000D*10**
0.0082	13	12	6	10	0.6	SMPC_822*1000D*10**
0.01	13	12	6	10	0.6	SMPC_103*1000D*10**
0.0022	18	11	5	15	0.8	SMPC_222*1000D*15**
0.0033	18	11	5	15	0.8	SMPC_332*1000D*15**
0.0047	18	11	5	15	0.8	SMPC_472*1000D*15**
0.0068	18	11	5	15	0.8	SMPC_682*1000D*15**
0.01	18	11	5	15	0.8	SMPC_103*1000D*15**
0.015	18	12	6	15	0.8	SMPC_153*1000D*15**
0.022	18	13.5	7.5	15	0.8	SMPC_223*1000D*15**
0.027	18	13.5	7.5	15	0.8	SMPC_273*1000D*15**
0.033	18	14.5	8.5	15	0.8	SMPC_333*1000D*15**
0.039	18	15.5	9.5	15	0.8	SMPC_393*1000D*15**
0.047	18	15.5	9.5	15	0.8	SMPC_473*1000D*15**
0.056	18	19	11	15	0.8	SMPC_563*1000D*15**
0.068	18	19	11	15	0.8	SMPC_683*1000D*15**
0.022	26.5	15	6	22.5	0.8	SMPC_223_1000D*23**
0.033	26.5	15	6	22.5	0.8	SMPC_333_1000D*23**
0.047	26.5	16	7	22.5	0.8	SMPC_473_1000D*23**
0.056	26.5	16	7	22.5	0.8	SMPC_563_1000D*23**
0.068	26.5	17	8.5	22.5	0.8	SMPC_683_1000D*23**
0.082	26.5	17	8.5	22.5	0.8	SMPC_823_1000D*23**
0.1	26.5	19	10	22.5	0.8	SMPC_104_1000D*23**
0.12	26.5	22	12	22.5	0.8	SMPC_124_1000D*23**
0.15	26.5	22	12	22.5	0.8	SMPC_154_1000D*23**

1600Vdc (600Vac)						
容量 μF	W	H	T	P	d	產品代碼 Part number
0.00056	18	11	5	15	0.8	SMPC_561*1600D*15**
0.00068	18	11	5	15	0.8	SMPC_681*1600D*15**
0.001	18	11	5	15	0.8	SMPC_102*1600D*15**
0.0015	18	11	5	15	0.8	SMPC_152*1600D*15**
0.0022	18	11	5	15	0.8	SMPC_222*1600D*15**
0.0033	18	11	5	15	0.8	SMPC_332*1600D*15**
0.0039	18	11	5	15	0.8	SMPC_392*1600D*15**
0.0047	18	11	5	15	0.8	SMPC_472*1600D*15**
0.0056	18	11	5	15	0.8	SMPC_562*1600D*15**
0.0068	18	11	5	15	0.8	SMPC_682*1600D*15**
0.0082	18	12	6	15	0.8	SMPC_822*1600D*15**
0.01	18	12	6	15	0.8	SMPC_103*1600D*15**
0.015	18	13.5	7.5	15	0.8	SMPC_153*1600D*15**
0.018	18	13.5	7.5	15	0.8	SMPC_183*1600D*15**
0.022	18	14.5	8.5	15	0.8	SMPC_223*1600D*15**
0.027	18	15.5	9.5	15	0.8	SMPC_273*1600D*15**
0.033	18	15.5	9.5	15	0.8	SMPC_333*1600D*15**
0.039	18	19	10	15	0.8	SMPC_393*1600D*15**
0.047	18	19	10	15	0.8	SMPC_473*1600D*15**
0.015	26.5	15	6	22.5	0.8	SMPC_153*1600D*23**
0.018	26.5	15	6	22.5	0.8	SMPC_183*1600D*23**
0.022	26.5	15	6	22.5	0.8	SMPC_223*1600D*23**
0.027	26.5	16	7	22.5	0.8	SMPC_273*1600D*23**
0.033	26.5	16	7	22.5	0.8	SMPC_333*1600D*23**
0.039	26.5	17	8.5	22.5	0.8	SMPC_393*1600D*23**
0.047	26.5	19	10	22.5	0.8	SMPC_473*1600D*23**
0.056	26.5	19	10	22.5	0.8	SMPC_563*1600D*23**
0.068	26.5	22	12	22.5	0.8	SMPC_683*1600D*23**
0.082	26.5	22	12	22.5	0.8	SMPC_823*1600D*23**
0.1	26.5	22	12	22.5	0.8	SMPC_104*1600D*23**

Metallized Polypropylene Film Capacitor
 金屬化聚丙烯膜電容器 (盒裝型) SMPC series



■ 外型尺寸表 Dimensions (mm)

2000Vdc (600Vac)						
容量 μF	W	H	T	P	d	產品代碼 Part number
0.00056	18	11	5	15	0.8	SMPC_561*2000D*15**
0.00068	18	11	5	15	0.8	SMPC_681*2000D*15**
0.00082	18	11	5	15	0.8	SMPC_821*2000D*15**
0.001	18	11	5	15	0.8	SMPC_102*2000D*15**
0.0015	18	11	5	15	0.8	SMPC_152*2000D*15**
0.0018	18	11	5	15	0.8	SMPC_182*2000D*15**
0.0022	18	11	5	15	0.8	SMPC_222*2000D*15**
0.0027	18	11	5	15	0.8	SMPC_272*2000D*15**
0.0033	18	11	5	15	0.8	SMPC_332*2000D*15**
0.0039	18	11	5	15	0.8	SMPC_392*2000D*15**
0.0047	18	11	5	15	0.8	SMPC_472*2000D*15**
0.0056	18	12	6	15	0.8	SMPC_562*2000D*15**
0.0068	18	12	6	15	0.8	SMPC_682*2000D*15**
0.0082	18	13.5	7.5	15	0.8	SMPC_822*2000D*15**
0.01	18	13.5	7.5	15	0.8	SMPC_103*2000D*15**
0.015	18	14.5	8.5	15	0.8	SMPC_153*2000D*15**
0.018	18	15.5	9.5	15	0.8	SMPC_183*2000D*15**
0.022	18	19	11	15	0.8	SMPC_223*2000D*15**
0.0068	26.5	15	6	22.5	0.8	SMPC_682*2000D*23**
0.0082	26.5	15	6	22.5	0.8	SMPC_822*2000D*23**
0.01	26.5	15	6	22.5	0.8	SMPC_103*2000D*23**
0.012	26.5	15	6	22.5	0.8	SMPC_123*2000D*23**
0.015	26.5	15	6	22.5	0.8	SMPC_153*2000D*23**
0.018	26.5	16.5	7	22.5	0.8	SMPC_183*2000D*23**
0.022	26.5	17	8.5	22.5	0.8	SMPC_223*2000D*23**
0.027	26.5	17	8.5	22.5	0.8	SMPC_273*2000D*23**
0.033	26.5	19	10	22.5	0.8	SMPC_333*2000D*23**
0.039	26.5	19	10	22.5	0.8	SMPC_393*2000D*23**
0.047	26.5	22	12	22.5	0.8	SMPC_473*2000D*23**
0.056	26.5	22	12	22.5	0.8	SMPC_563*2000D*23**

_ = Internal use

* = Lead Forming (Refer to Product code system)

** = Lead length