
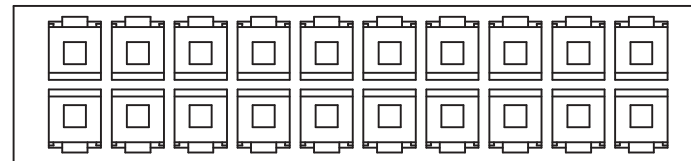
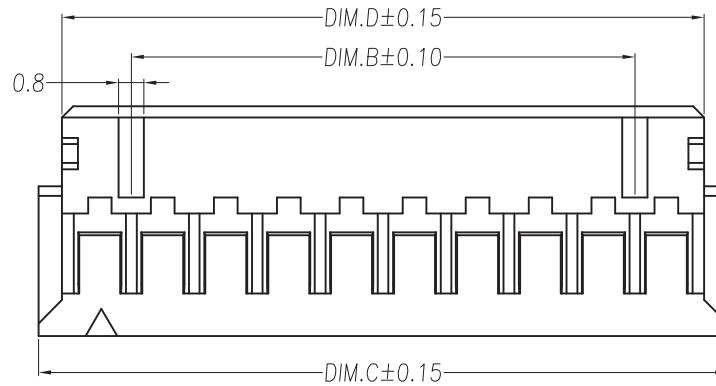
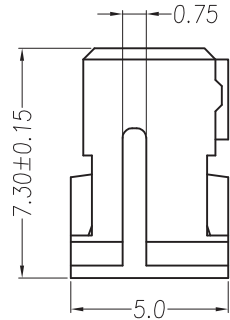


环保物料

TEL: 0769-82001899

**SPECIFICATIONS**

Voltage rating: 250V AC, DC  
 Current rating: 3A, AC, DC  
 Withstanding Voltage: 1000V AC/minute  
 Insulation resistance: 1000M min  
 Temperature range: -25 °C ~ +85 °C  
 Contact resistance: 20m max  
 Poles : 04-40P  
 Housing Material: Nylon66 UL94V-0  
 Part No.: P2020-XX-N0

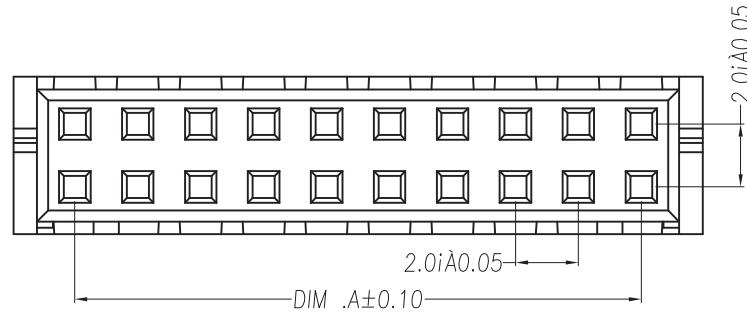

No. of Contacts	DIMENSIONS			
	DIM A	DIM B	DIM C	DIM D
2	2.00	0.00	5.90	4.40
3	4.00	2.00	7.90	6.40
4	6.00	4.00	9.90	8.40
5	8.00	6.00	11.90	10.40
6	10.00	8.00	13.90	12.40
7	12.00	10.00	15.90	14.40
8	14.00	12.00	17.90	16.40
9	16.00	14.00	19.90	18.40
10	18.00	16.00	21.90	20.40
11	20.00	18.00	23.90	22.40
12	22.00	20.00	25.90	24.40
13	24.00	22.00	27.90	26.40
14	26.00	24.00	29.90	28.40
15	28.00	26.00	31.90	30.40
16	30.00	28.00	33.90	32.40

				TOLERANCE UNLESS OTHERWISE		DRAWN	CK tan	<b>XFCN兴飞连接器有限公司</b> CONNECTORS XFCN CONNECTORS CO., LTD.		SHEET	1/1
				X.	±0.30	X°	±5°			CHKD	DATE
				.X	±0.20	.X°	±2°	APPD	PRODUCT NAME	2.00mm Crimp Style Connectors	
				.XX	±0.08	.XX°	±1°	VIEW	PART. NO.	P2020-XX-N0	
				.XXX	±0.03	.XXX°	±0.5°			DWG NO.	009
AO	MODIFICATION		DRAW	DATE							
VER											