



# specification

## SHEET FOR APPROVAL

Part Name: \_\_\_\_\_ electro-magnetic buzzer \_\_\_\_\_  
 Type: \_\_\_\_\_ YX-KC9055 \_\_\_\_\_  
 Customer Name: \_\_\_\_\_  
 Number of the Edition: \_\_\_\_\_



	Approved by	Checked by	Issued by
Signature			
Date			

**Yue Xin Electronics Co., Ltd.**  
 Add: People Industrial Park Chen Bao Town Xinghua City Jiangsu province China  
 Tel: +86 0523 83722059 Fax: +86 0523 83722259  
 Mob/whatsapp: +8615952695023 Mail: [anna@xhyxdz.com](mailto:anna@xhyxdz.com)  
 Web: [www.xhyxdz.com](http://www.xhyxdz.com)



# Electro-magnetic Buzzer

## YX-KC9055




### Electrical Characteristics

Model No.	YX-KC9055		
Rated Voltage(Vo-p)	1.5	3	5
Operating Voltage ( Vo-p )	1-3	2~4	4~6
*Rated Current (mA)			
*Sound Output at 10cm (dB)	80	80	80
Resonant Frequency (Hz)	2731		
Coil Resistance(Ω)	$5.5 \pm 1$	$16 \pm 3$	$40 \pm 4$
Operating Temperature (°C)	-20~+70		
Storage Temperature (°C)	-30~+80		
Weight (g)	1		
Housing Material	PPO		

### Appearance Drawing

( UNT : mm ) Tolerance :  $\pm 0.5$ mm Except Specified

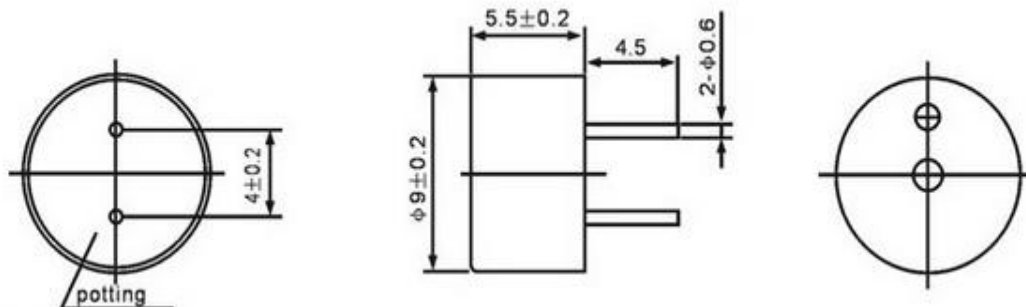

#### Yue Xin Electronics Co., Ltd.

Add: People Industrial Park Chen Bao Town Xinghua City Jiangsu province China

Tel: +86 0523 83722059 Fax: +86 0523 83722259

Mob/whatsup: +8615952695023 Mail: [anna@xhyxdz.com](mailto:anna@xhyxdz.com)

Web: [www.xhyxdz.com](http://www.xhyxdz.com)




# Electro-magnetic Buzzer


## YX-KC9055



### Testing Method:

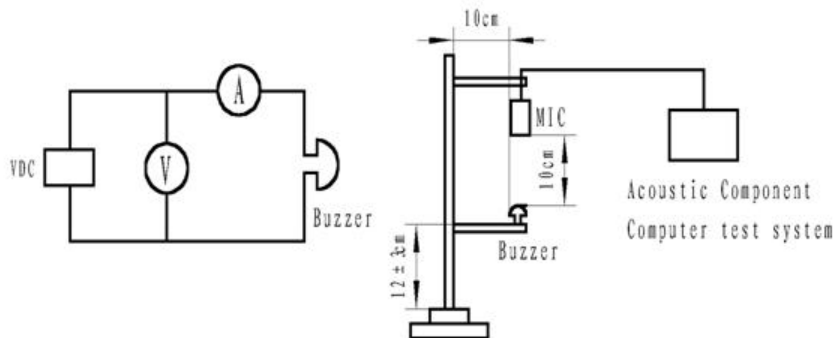

### Frequency Response:

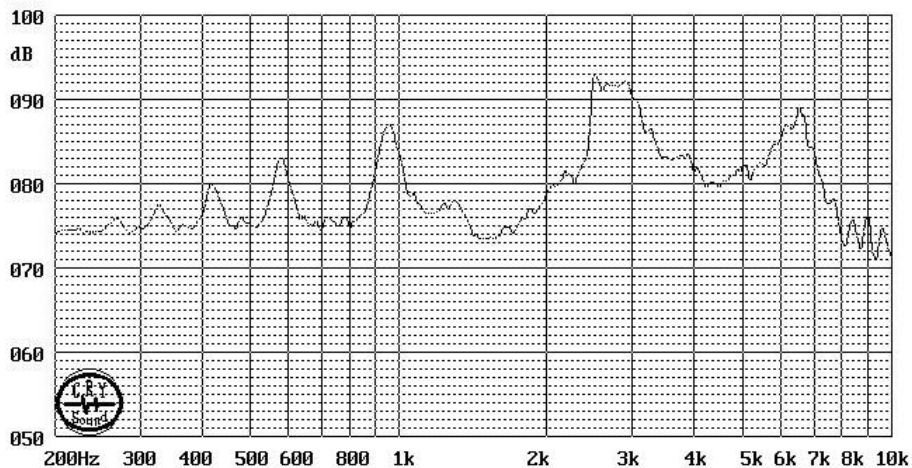

### Yue Xin Electronics Co., Ltd.

Add: People Industrial Park Chen Bao Town Xinghua City Jiangsu province China

Tel: +86 0523 83722059 Fax: +86 0523 83722259

Mob/whatsapp: +8615952695023 Mail: [anna@xhyxdz.com](mailto:anna@xhyxdz.com)

Web: [www.xhyxdz.com](http://www.xhyxdz.com)