



# piezoelectric buzzer


## YX-YD3015



### Electrical Characteristics

Type	Unit	YX-YD3015
Rated Voltage	V	12
Operating Voltage	V	3-24
Rated Current	m A	20Max. at 12VDC
Min Sound Output at 10cm	dB	≥90
Resonant Frequency	Hz	3000±500
Operating Temperature	°C	-20~+60
Storage Temperature	°C	-30~+70
Housing Material		ABS

### Appearance Drawing (UNT: mm) Tolerance: ±0.5mm Except Specified

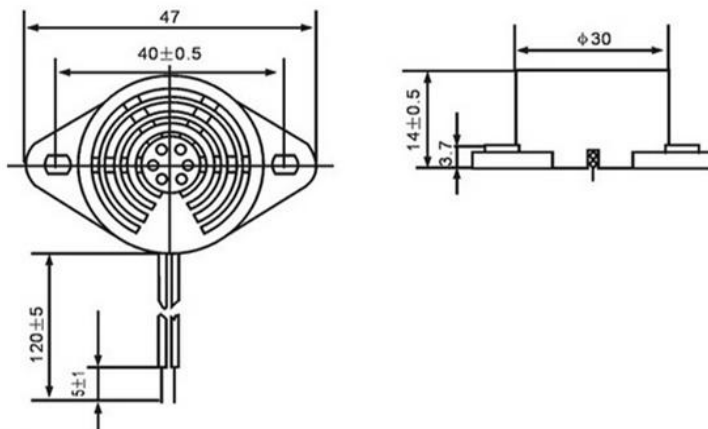

#### Yue Xin Electronics Co., Ltd.

Add: People Industrial Park Chen Bao Town Xinghua City Jiangsu province China

Tel: +86 0523 83722059 Fax: +86 0523 83722259

Web: [www.xhyxdz.com](http://www.xhyxdz.com)




# piezoelectric buzzer



## YX-YD3015



### Testing Method:

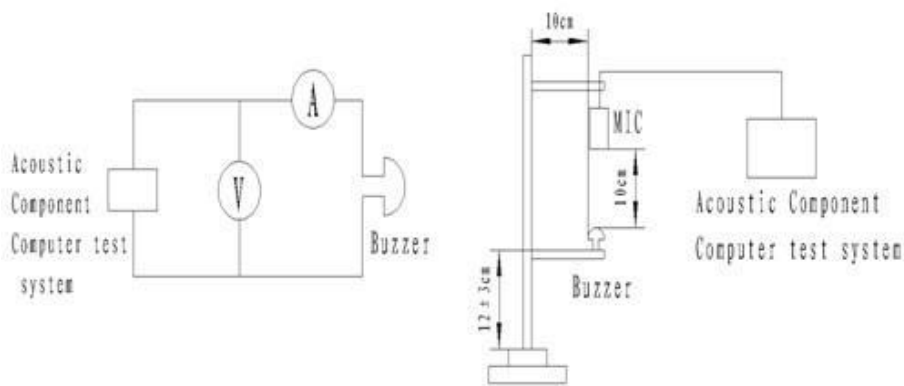

### Frequency Response:

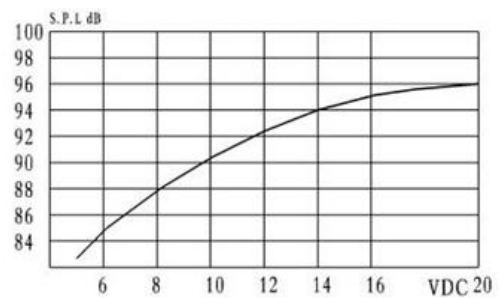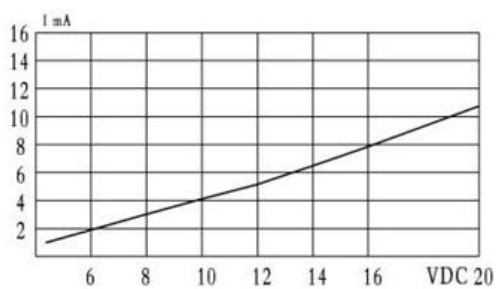

### Yue Xin Electronics Co., Ltd.

Add: People Industrial Park Chen Bao Town Xinghua City Jiangsu province China

Tel: +86 0523 83722059 Fax: +86 0523 83722259

Web: [www.xhyxdz.com](http://www.xhyxdz.com)