

- RF Transformers
- Impedance=50Ω
- Operating temperature range: -20°C to 85°C
- Storage temperature range: -55°C to +100°C
- RoHS compliant





Electrical Specifications @25° C



Part Number	Ω Ratio	Insertion Loss			DC Current	RF Power	Frequency
	Sec:Pri(1-3:6-4)	3-800MHz	5-400MHz	10-100MHz			
RFT-017SG	4:1	3.0dB	2.0dB	1.0dB	30mA	0.25W	3-800MHz

Note: Insertion Loss is referenced to mid-band loss, 0.8dB typ.

MECHANICAL

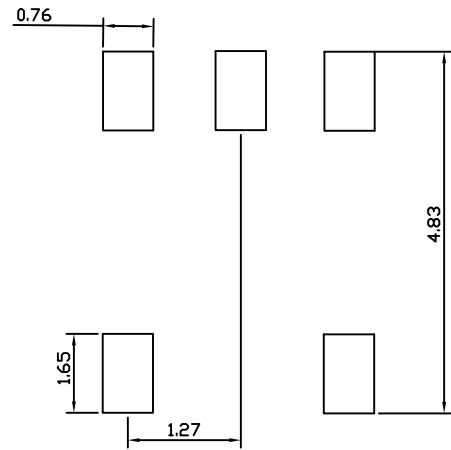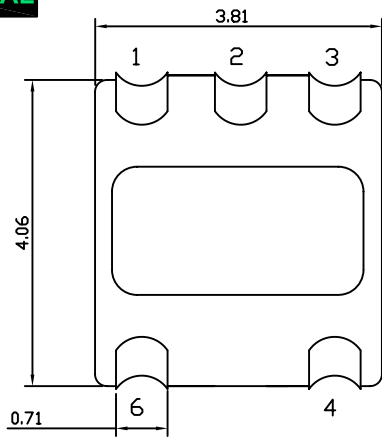

Recommend PAD layout

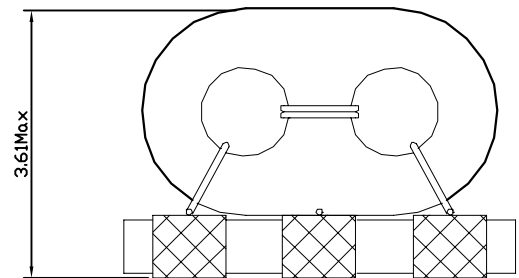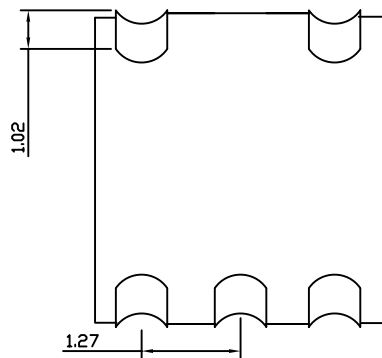

Unless otherwise specified all tolerances are: ± 0.25 in mm

SCHEMATICS

