

产品名称 Product name

▶ 2.0PH H2.0 2*Pin 180
度 PC2.8 PA3.9 PB2.0
L8.7

产品应用场景 Product application scenario

▶ 电子通讯/数码产品/家用电器
▶ 外围设备/汽车/医疗设备等.
▶ Electronic communication/
▶ digital products/household
▶ appliance peripherals/
▶ Automobile/medical equipment,
▶ etc

排针系列™
Needle arrangement series™

产品参数/Product parameters

额定电流 (Rated current): 1.5A AC/DC

盐雾实验 (Life Test): 24 hours

接触电阻 (Contact Resistance): 20mΩ

绝缘电阻 (Insulation Resistance): 1000MΩ min.

耐电压 (Withstand voltage): AC 500V

工作温度 (Operating Temperature): -40° C to 105°

防火等级 (Fire rating): Polyester (UL94V-0)

触点电镀 (Dielectric Strength): Gold Flash

耐高温范围/时长 (High temperature resistance range/duration): 260° C for 5seconds

包装方式 (Packaging method): 袋装

材质/MATERIALS:

No.	名称/NAME	材料/MATERIAL	表面处理/颜色 Surfacetreatment/color
①	端子/Terminal	Brass/C2680	镀金 gold-plating
②	塑胶/plastic cement	PBT/PA6T	黑色 Black

产品PIN位示意图/Schematic diagram of product PIN

No. of	DIM. A	DIM. B	No. of	DIM. A	DIM. B	No. of	DIM. A	DIM. B	No. of	DIM. A	DIM. B
2*1P	0.00	2.00	2*11P	20.00	22.00	2*21P	40.00	42.00	2*31P	60.00	62.00
2*2P	2.00	4.00	2*12P	22.00	24.00	2*22P	42.00	44.00	2*32P	62.00	64.00
2*3P	4.00	6.00	2*13P	24.00	26.00	2*23P	44.00	46.00	2*33P	64.00	66.00
2*4P	6.00	8.00	2*14P	26.00	28.00	2*24P	46.00	48.00	2*34P	66.00	68.00
2*5P	8.00	10.00	2*15P	28.00	30.00	2*25P	48.00	50.00	2*35P	68.00	70.00
2*6P	10.00	12.00	2*16P	30.00	32.00	2*26P	50.00	52.00	2*36P	70.00	72.00
2*7P	12.00	14.00	2*17P	32.00	34.00	2*27P	52.00	54.00	2*37P	72.00	74.00
2*8P	14.00	16.00	2*18P	34.00	36.00	2*28P	54.00	56.00	2*38P	74.00	76.00
2*9P	16.00	18.00	2*19P	36.00	38.00	2*29P	56.00	58.00	2*39P	76.00	78.00
2*10P	18.00	20.00	2*20P	38.00	40.00	2*30P	58.00	60.00	2*40P	78.00	80.00

产品编号/Product No



1: Series No:
PH-Pin Header
2: 焊接板类型/Welding Board Type:
8-180度双排DIP/Straight
DIP Type
3: 产品间距/Product spacing
127-1.27mm
200-2.00mm
254-2.54mm
4: PIN位/PIN bit
2*1P-21P



5: 颜色/Color:
B-Black
6: 材料/Material
1-PBT 2-PA6T
7: 触点电镀/Contact Plating
GO-Gold Flash
8: 包装方式/Packgin Method
P-袋装/PE B-盒装/BOX
T-管装/Tubing W-卷带/winding
9: Serial Code

连接器领域专家
让世界连接更清晰

产品订购号示意图/Schematic diagram of product order number

Schematic diagram of product order number: HB-PH8-20021PB2G0P

产品外形尺寸图/Outline dimension drawing of product

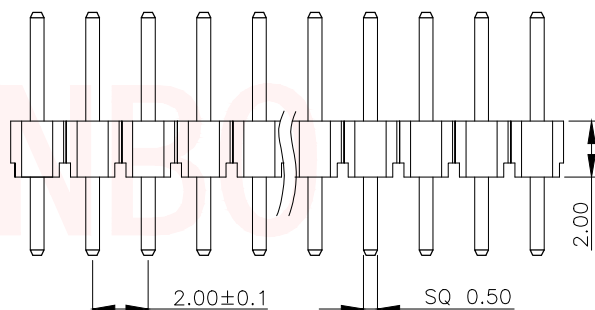
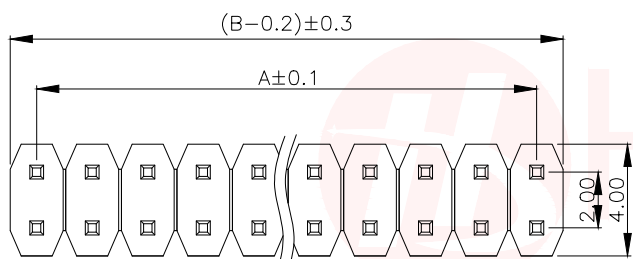


Series
Needle
Series

连接器领域专家

让世界连接更清晰



线路图/Circuit diagram

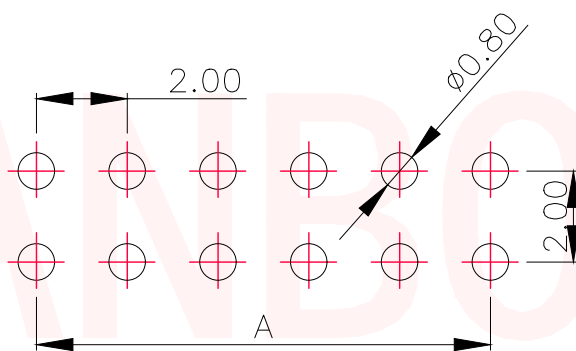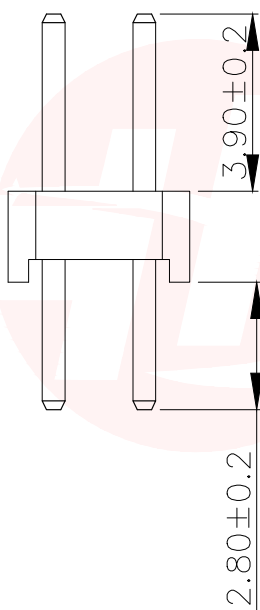


RECOMMEND P. C. B LAYOUT
PCB TOLERANCE: ± 0.05 (TOP VIEW)



产品

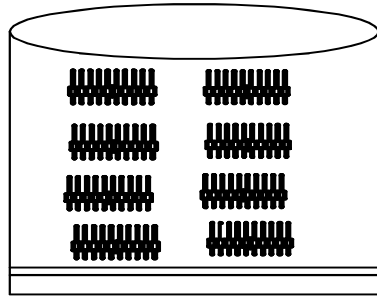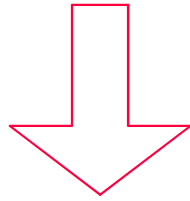

3#胶袋: 16*18cm

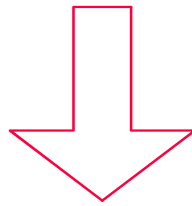

纸箱