


注：“*”表示关键尺寸(3个).

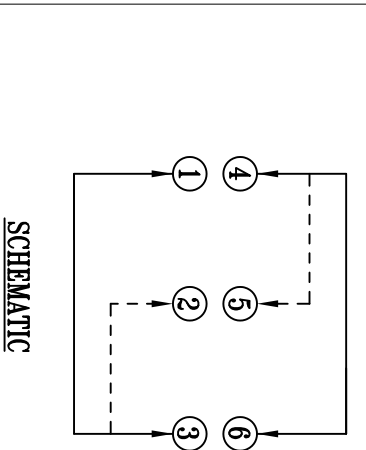

PB-22E18-6PX

X=NO LOCK
L=LOCK

G-Switch Specification:
 Electrical Specifications: 0.5A 30VDC
 Contact Resistance : ≤100mΩ
 Insulation Resistance: ≥100MΩ DC125V
 Withstand Voltage: AC125V 1 minute
 Operating Temperature: -25°C~+65°C
 Storage Humidity: ≤85%RH
 Electrical Life: 10,000
 Mechanical Life: 100,000



G-Switch 品尊科技

Unless otherwise specified, Tolerance:
 X ±0.30
 X.X ±0.20
 X.XX ±0.15
 X.XXX ±0.10
 Angles ±3°

G-Switch Electronic (HongKong) CO.,Ltd.	
DESIGN Bright Lee	DATE 2016.05.29
CHECKED	DATE
APPROVED	DATE
Mold code: PB-22E18-6PX	
REV: X1	SCALE: 4:1
http://www.dg-switch.com	UNIT: mm
TEL:0769-82388879	SIZE: A4 SHEET: 1/1