



## SMD PULSE TRANSFORMER

MNC  
Confidential  
HXH Corporation



深圳华芯鸿电子有限公司

**Shenzhen Hua Xin Hong Electronics Co.,Ltd**

公司地址: 深圳市南山区西丽镇街道百旺社区牛城村牛城路221号505

TEL: 86-755-29016433 FAX:86- 755-27652977

Email: hxhsales01@163.com


Http: //www.szhxhtech.com.cn

- High Common Mode Impedance at High Frequency.
- Excellent Noise Suppression Performance.
- Small Size and Low Profile, Surface Mount Type.
- Operating Temperature Range: -40 °C to +85 °C.
- RoHS Compliant.




Electrical Specifications @25°C					
Part Number	Common Mode Impedance	DC Resistance	Rated Current	Rated Volt	Insulation Resistance
	$\Omega$ , @100MHz	$\Omega$ Max	mA Max	Vdc Max	M $\Omega$ Min
CC2012E-601	800±25%	0.88	300	50	10


## MECHANICAL DIMENSIONS (unit:mm)

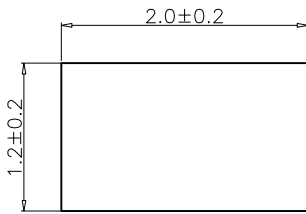


TOP VIEW

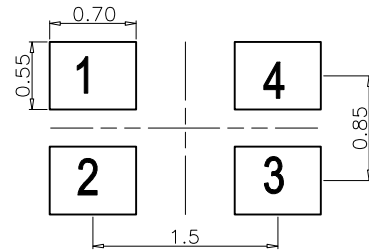

SUGGEST LAYOUT

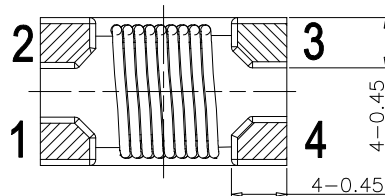


BOTTOM VIEW

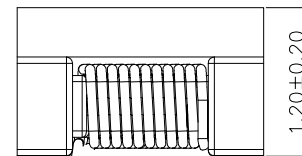

SIDE VIEW

Unless otherwise specified all tolerances are:±0.25mm

## SCHEMATIC

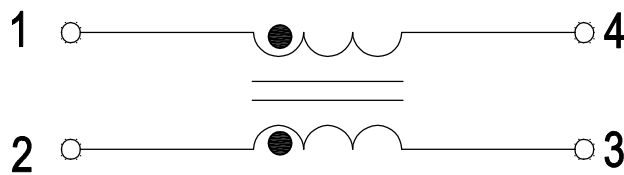

## Impedance Frequency

