

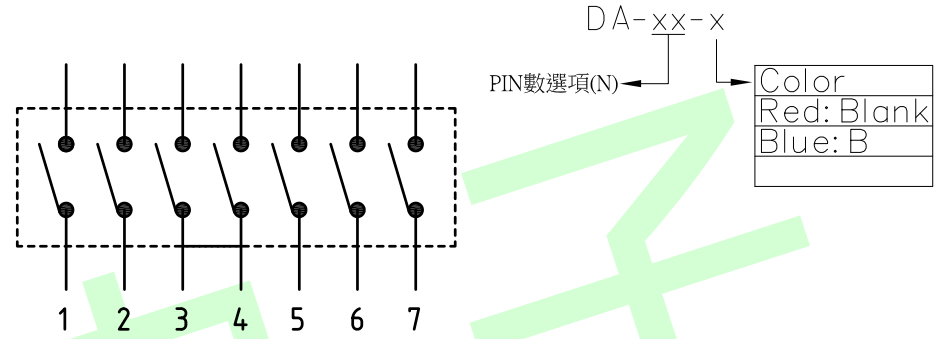




高推柄 High handle

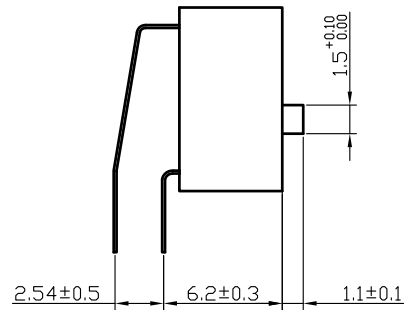

电路图

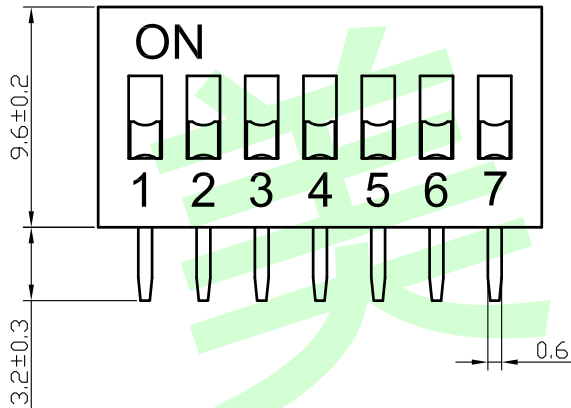

平推柄 short handle

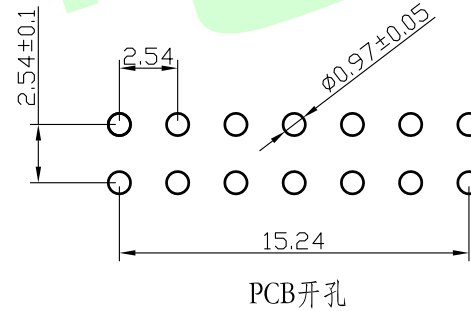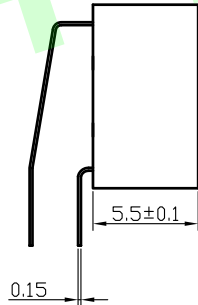

PCB开孔


PART NO.	A	B
DA-01-x	3.54	
DA-02-x	6.64	2.54
DA-03-x	9.18	5.08
DA-04-x	11.72	7.62
DA-05-x	14.26	10.16
DA-06-x	16.80	12.70
DA-07-x	19.34	15.24
DA-08-x	21.88	17.78
DA-09-x	24.42	20.32
DA-10-x	26.96	22.86
DA-11-x	29.50	25.40
DA-12-x	32.04	27.94

开关特性:

- 1、电流规格: 切换时: 25mA@24VDC
- 2、接触电阻: 50M Max
- 3、绝缘电阻: 100M @250VDC
- 4、绝缘强度: 500VAC/1min
- 5、操作力度: 1000gf Max
- 6、电气寿命: 2000次
- 7、适用温度: -20 to 80 (无结冰)
- 8、焊接要求:
手工焊接: 320 不超过2秒 (30瓦烙铁max.)
波峰焊: 260 不超过5秒
在焊接和清洁过程中开关处于断开状态
- 9、开关出厂处于断开状态

材料:

- 盖子: PBT塑料 (红色或蓝色)
- 底座: PBT塑料 (黑色)
- 操作杆: PBT塑料 (白色)
- 灌密封胶: 环氧树脂
- 端子: 镀锡磷青铜, 触点镀金 3μ (或整体镀金 1μ)
- 电镀: (全金/半锡金)

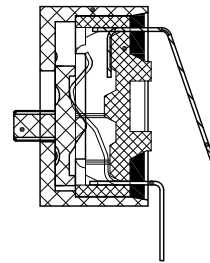

Dongguan Usakro Electronic Technology Co., Ltd.

design	date	name	DA-07-R
Review	date	name	
Approved	date	name	
Drawing number:			
modify	Review	Approved	Tolerance not specified
Proportion	1:1	unit	mm
gape number			
			A4