


| PART NO. | A     | B     |
|----------|-------|-------|
| DS-01-x  | 3.54  |       |
| DS-02-x  | 6.64  | 2.54  |
| DS-03-x  | 9.18  | 5.08  |
| DS-04-x  | 11.72 | 7.62  |
| DS-05-x  | 14.26 | 10.16 |
| DS-06-x  | 16.80 | 12.70 |
| DS-07-x  | 19.34 | 15.24 |
| DS-08-x  | 21.88 | 17.78 |
| DS-09-x  | 24.42 | 20.32 |
| DS-10-x  | 26.96 | 22.86 |
| DS-11-x  | 29.50 | 25.40 |
| DS-12-x  | 32.04 | 27.94 |

开关特性：

- 1、开关容量：切换时：25mA@24VDC  
非切换时：100mA@50VDC
- 2、接触电阻：初始值50M max寿命终值100M max
- 3、绝缘电阻：100M @500VDC
- 4、绝缘强度：500VAC 50Hz /1min
- 5、极间电容：<5pf, 1MHz /1min
- 6、操作力度：1000gf Max
- 7、电气寿命：2000次 <100M 20次/min, 25mA 24VDC
- 8、适用温度：-20 to 85 (无结冰)
- 9、焊接要求：  
手工焊接：320 不超过2秒(30瓦烙铁max.)  
波峰焊：260 不超过5秒, 在焊接和清洁过程中开关处于断开状态
- 10、开关出厂处于断开状态

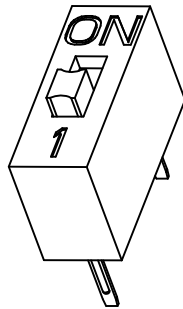

| 序号 | 名称  | 材质          | 数量 | 备注       |
|----|-----|-------------|----|----------|
| 7  |     |             |    |          |
| 6  | 灌封胶 | 环氧树脂        | 1  |          |
| 5  | 开关座 | PBT UL94-V0 | 1  | 黑色       |
| 4  | 动簧片 | 磷铜镀金或半锡金    | 4  |          |
| 3  | 静簧片 | 磷铜镀金或半锡金    | 4  |          |
| 2  | 开关盖 | PBT UL94-V0 | 1  | 红色或蓝色或黑色 |
| 1  | 拨动柄 | PBT UL94-V0 | 4  | 白色       |

Dongguan Usakro Electronic Technology Co., Ltd.

| design                  | date       | name        |
|-------------------------|------------|-------------|
| Review                  | date       | DS-01-R     |
| Approved                | date       | name        |
| Drawing number:         |            |             |
| modify                  | Review     | Approved    |
| Tolerance not specified | Proportion | 1:1         |
| unit                    | mm         | gape number |
| A4                      |            |             |