

## CD TYPE


### FEATURES 特性

Various high power inductors are superior be high saturation for surface mounting.  
具有高功率、高饱和电流、低阻抗、小型化之特点。

### APPLICATIONS 用途

Power supply for VTR,OA equipment Digital camera,LCD television set notebook PC,  
portable communication equipments,DC/DC converters,etc.  
录影机, OA仪器, 数码相机, 液晶电视, 笔记型电脑, 小型通信机器, DC/DC变压器  
之电源供应器等。

### DIMENSIONS 尺寸

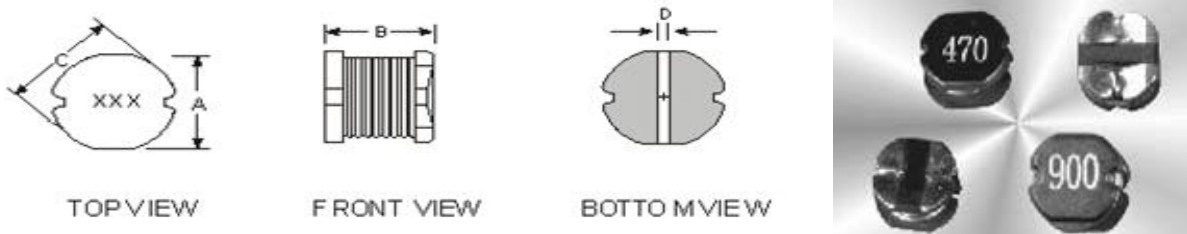

PART NO.	A	B	C	D(Ref)
XRCD105	9.0±0.3	5.4±0.5	10.0±0.3	3.1

### IDENTIFICATION 产品标记说明


XRCD 105 470 K I  
1 2 3 4 5

1. product ID 产品代号
2. Dimensions 尺寸
3. Inductance 电感量 (470:47uH,471:470uH)
4. Tolerance 精度 (J:±5%,K:±10%,L:±15% M:±20%,P:±25%,N:±30%)
5. Packaging Style 包装 (T:Tape and reel;B:Bulk)

**XRCD105 TYPE**

PART NUMBER 品名	INDUCTANCE E (μH) 电感值	DCR (max) (Ω) 直流电阻	IDC (A)(max) ΔL/L=-10%;Δt=40℃ 定格电流	TEST FREQ. 测试频率
XRCD105-100M	10	0.06	2.60	2.52MHz
XRCD105-120M	12	0.07	2.45	2.52MHz
XRCD105-150M	15	0.08	2.27	2.52MHz
XRCD105-180M	18	0.09	2.15	2.52MHz
XRCD105-220M	22	0.10	1.95	2.52MHz
XRCD105-270M	27	0.11	1.76	2.52MHz
XRCD105-330L	33	0.12	1.50	2.52MHz
XRCD105-390L	39	0.14	1.37	2.52MHz
XRCD105-470L	47	0.17	1.28	2.52MHz
XRCD105-560K	56	0.19	1.17	2.52MHz
XRCD105-680K	68	0.22	1.11	2.52MHz
XRCD105-820K	82	0.25	1.00	2.52MHz
XRCD105-101K	100	0.35	0.97	1KHz
XRCD105-121K	120	0.40	0.89	1KHz
XRCD105-151K	150	0.47	0.78	1KHz
XRCD105-181K	180	0.63	0.72	1KHz
XRCD105-221K	220	0.73	0.66	1KHz
XRCD105-271K	270	0.97	0.57	1KHz
XRCD105-331K	330	1.15	0.52	1KHz
XRCD105-391K	390	1.30	0.48	1KHz
XRCD105-471K	470	1.48	0.42	1KHz
XRCD105-561K	560	1.90	0.33	1KHz
XRCD105-681K	680	2.25	0.28	1KHz
XRCD105-821K	820	2.55	0.24	1KHz
XRCD105-102K	1000	3.80	0.23	1KHz
XRCD105-152K	1500	6.10	0.21	1KHz
XRCD105-222K	2200	7.40	0.17	1KHz
XRCD105-332K	3300	7.90	0.15	1KHz

## 包装

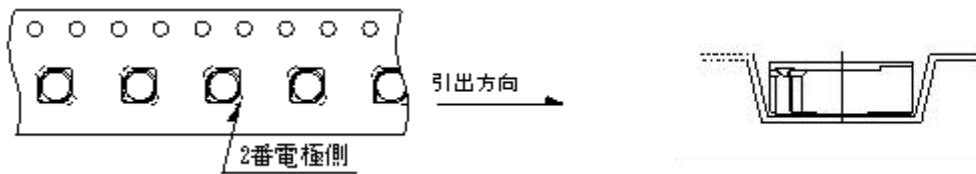

### 包装方式

LEADER部	SEAL TAPE 尺寸	10cm以上
	START CARRIER TAPE尺寸	20cm以上
	TRATLER部尺寸	10cm以上
	数量	1000pcs

纸卷

