


Poles	Dimensions (mm)		Poles	Dimensions (mm)	
	A	B		A	B
02	2.00	6.00	08	14.00	18.00
03	4.00	8.00	09	16.00	20.00
04	6.00	10.00	10	18.00	22.00
05	8.00	12.00	11	22.00	24.00
06	10.00	14.00	12	24.00	26.00
07	12.00	16.00	13	26.00	28.00

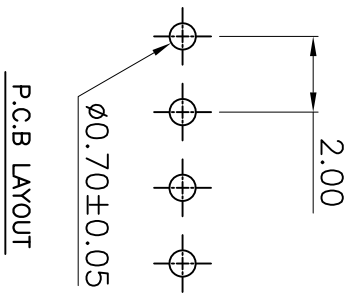

- 技术指标:
1. 塑体表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
  2. 温度范围: -25° C~85° C.
  3. 额定电压: 50V, AC,DC.
  4. 接触电阻: ≤0.02Ω.
  5. 绝缘电阻: ≥100MΩ

ECN NO.		REV.	DATE.	DESCRIPTION.	CHANGE.	CHECK.	APPRO.
		A		NEW			

APPROVALS		DATE
DRAWN	G.M.Chen	2015/7/17
CHECKED		
APPROVALS		

TOLERANCES ARE	30 <sup>±0.15</sup>	±0.30	ANGLE	PART NO.	PH-W-XXA
	10 <sup>±0.10</sup>	±0.20		UNIT: mm	SCALE: 1:1
	5 <sup>±0.10</sup>	±0.15	±2°	DRAWING NO.	SHEET 1 OF 1
					PROJ.

**DEALON** 德之隆®  
 ELECTRONICS CO.,LTD

TITLE: 2.0 Pitch 弯插