





TYPE B4F

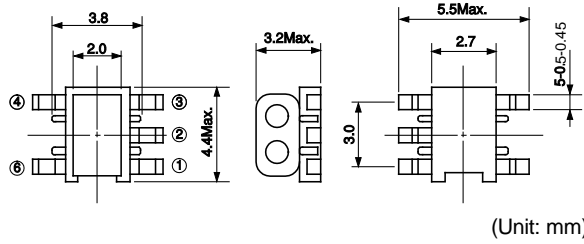

**Recommended patterns
推荐焊盘尺寸**

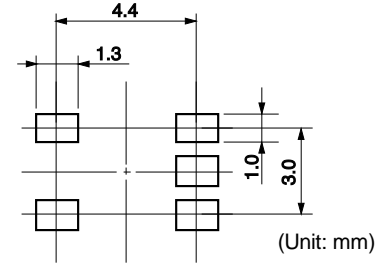


- Operating temperature (-40~+85°C)

- 使用温度范围：-40 ~ +85°C


Transformers for Frequency Mixer 混频器用变压器

Part No.	Winding Turns		Impedance Ratio
	1-2=2-3	4-6	
#617PT-2323=P3	3T	6T	75 : 75
#617PT-2291=P3	2T	6T	75 : 37.5
#617PT-2301=P3	1T	4T	75 : 18.75

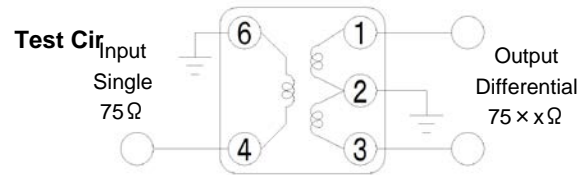


Typical Characteristics 典型特性


1) #617PT-2323 (Impedance Ratio=75Ω:75Ω)

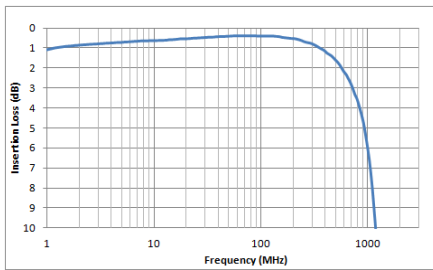

2) #617PT-2291 (Impedance Ratio=75Ω:37.5Ω)

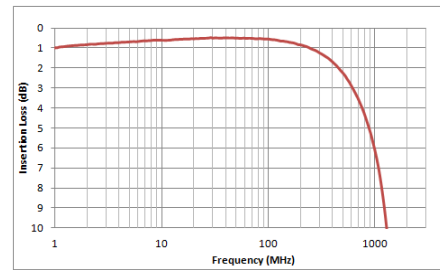

3) #617PT-2301 (Impedance Ratio=75Ω:18.75Ω)

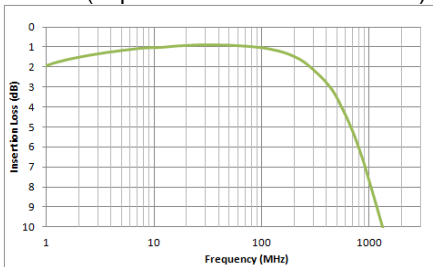

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Murata:](#)

[#617PT-2291=P3](#) [#617PT-2323=P3](#)