


Connectors for Automobiles

Connect with the Best

How to choose connectors Notes on usage User Guide Catalogue PDF

results

Product information

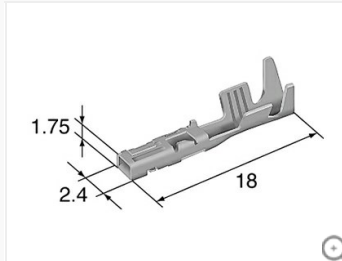

(Unit: mm)

Contact us for products

8240-0215

TS series

Terminal For AV Wire


1.5mm(060)

Sealed/Unsealed	unsealed
Male/Female	F
Tab Size	1.5mm(060)
Size	S
Mating parts	8230-4925 (TS series)


Applicable wire size	0.3-0.5mm ²
Cable overall diameter (mm)	1.1-1.7
Materials	Heat-resistant copper alloy
Surface treatment	Tin-plated
Contact resistance	Initial 3mΩ Max. after durability tests 10mΩ Max.
Leak current	3mA Max.
Insulation resistance	100MΩ Min.

TS series 1.5mm(060) related products


▶ Housing (11)

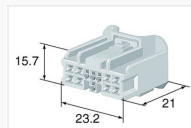


[0.64/1.5mm 6098-6083](#)

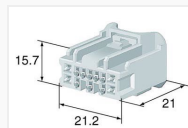

[0.64/1.5mm 6098-6097](#)

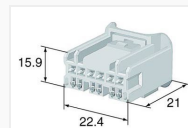

[0.64/1.5mm 6098-6111](#)

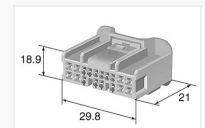

[0.64/1.5mm 6098-5604](#)

Show all results