
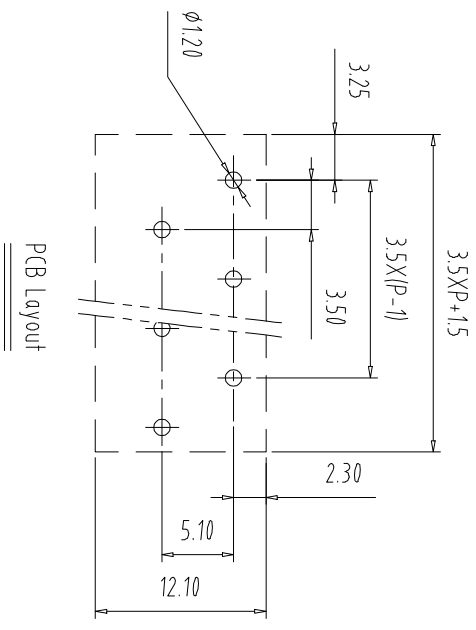


注：本板为禁止传输、复制、编辑文件，以及利用其内容建设网站

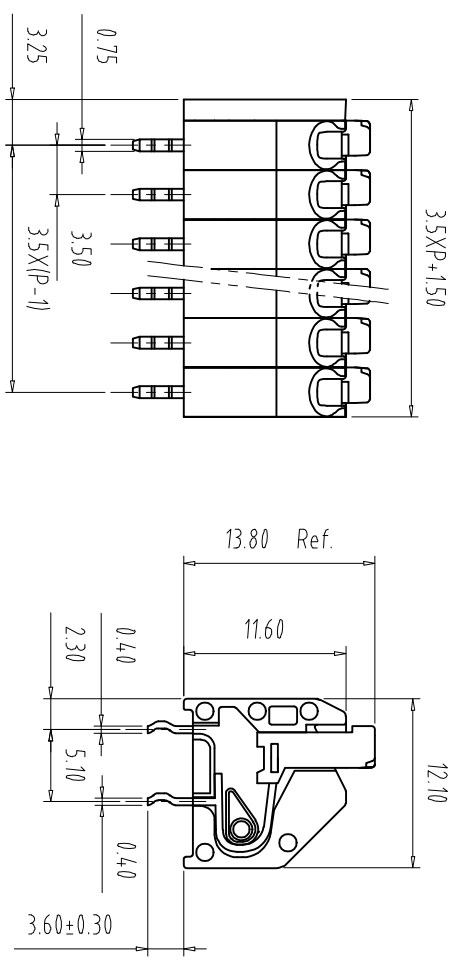

REV	ECN NO.	CONTENT	CHK	DATE

- NOTES1:
- UL Standard
 - 1.Rating voltage/current: 300V/8A
 - 2.withstanding voltage: AC2000V/1Min
 - 3.Wire range: 22~16AWG
- IEC Standard
- 1.Rating voltage/current: 400V/8A
 - 2.Wire range: 15mm²

- NOTES2:
- 1.Housing: PA66 (UL94V-0)
 - 2.Pin header: Hosphor bronzel(Tin plate)

- NOTES3:
- 1.Pitch: 3.5mm Poles: 01-XXX
 - 2.Stripping length: 9mm
 - 3.Operating temperature: -40℃~+105℃
 - 4.RoHS Compliance

How to order

MX250 - 35 - XXP - A - XXXX - XX - X

产品型号 间距 板数 出针顺序 颜色: 01-常规颜色

灰色:GY 橙色:OE
 蓝色:BU 红色:RD 定制颜色
 黑色:BK 透明色:TT
 绿色:GN 黄色:YW
 透明色:TT 白色:WE

— Cu铜
 — Fe铁
 A-其他定制

Pitch Range In mm	Nominal Dimension In mm	Over 6 TO	Over 10 TO	Over 24 TO	Over 30 TO	Over 60 TO	Over 100 TO	Over 150 TO	Over 150 TO	—	—
±0.15	±0.20	±0.30	±0.30	±0.30	±0.50	±0.70	±1.00	±1.30	±2°	—	—

ITEM	NAME OF PART	NO. OF PART	Q'TY	MATERIAL	NOTE
DWG	CHK	DATE	UNITS	MM	1/1
APP	DATE	SCALE	A4	1:1	1/1
NAME				MX250-35-XXP-A	

CIXI MAIXU ELECTRONICS CO.,LTD
 慈溪市迈旭电子有限公司