

注：本板为禁止传输、复制、编辑、修改、以及用其内容进行交流

REV	ECN NO.	CONTENT	CHK	DATE
-----	---------	---------	-----	------

NOTES1:  
UL Standard

1. Use group	B	C	D
Rated Current	15A	-	10A
Rated Voltage	300V	-	300V

3. Torque value: M2.5, 3.54Lb/in  
4. Wire range: 28~12AWG

IEC Standard

1. Pollution Degree	3	2	2
Overvoltage Category	III	III	II
Rate Impulse Voltage(KV)	/	4.0KV	/
Rate Voltage(V)	/	320V	/
Rate Current(A)	/	12A	/

2. Torque value: M2.5, 0.4Nm  
3. wire range: 1.0~2.5mm<sup>2</sup>

NOTES2:






- 1.Housing: PA66 (UL94V-0)
- 2.Cover: PA66 (UL94V-0)
- 3.Cage: Brass (Ni Plated)
- 4.Clamp: Copper alloy (Ni Plated)
- 5.Screw: Steel (M2.5,Zn Plated)

NOTES3:

- 1.Pitch: 5.08mm Poles: 02-24P
- 2.Stripping length: 7-8mm
- 3.Operating temperature: -40°C~+105°C
- 4.RoHS Compliance

How to order

MXZEDGKA - 508 - XXP - XXXX - XX - X - X

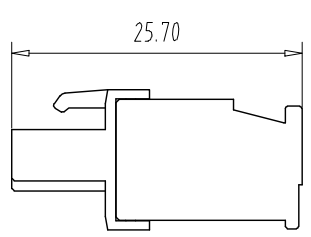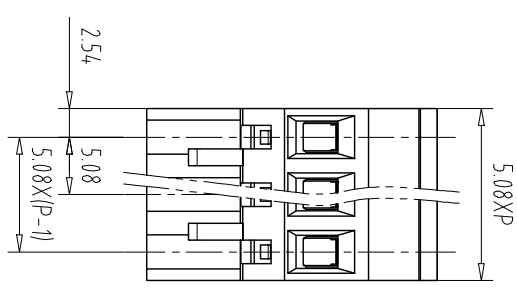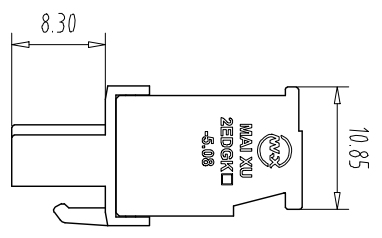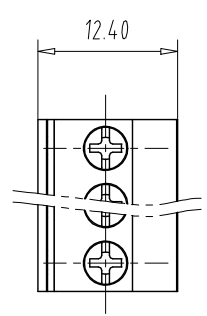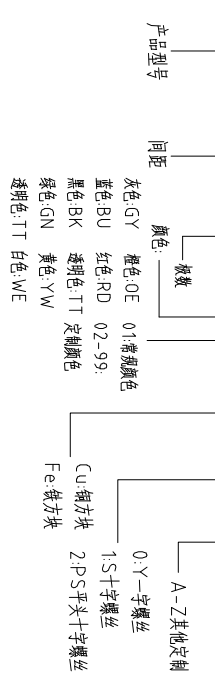

Pitch	Range	In	Nominal Dimension	Range	In	mm
Over	6	10	TO	30	60	100
TO	6	10	TO	30	60	100
Over	6	10	TO	30	60	100
TO	6	10	TO	30	60	100

ITEM	NAME OF PART	NO. OF PART	Q'TY	MATERIAL	NOTE
DWG	CHK	DATE	SCALE	SHEET/OF	1/1
APP	DATE	SCALE	NAME	MXZEDGKA-5.08-XXP	

CI XI MAIXU ELECTRONICS CO.,LTD  
慈溪市迈旭电子有限公司