
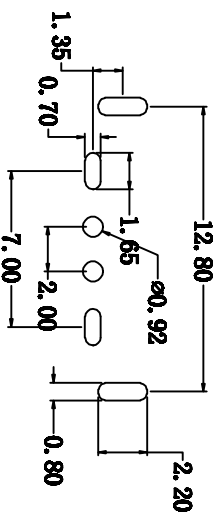
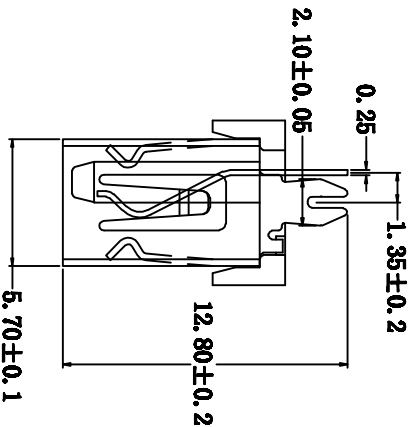
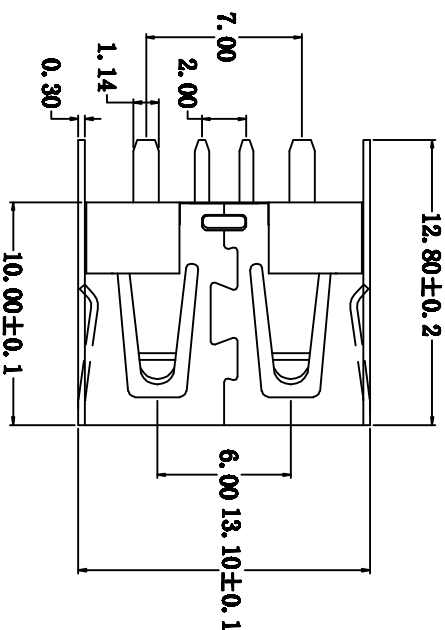


RoHS Compliant

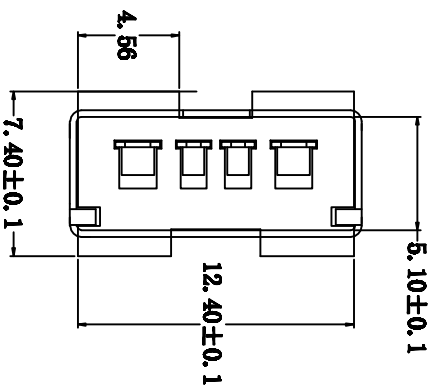

规格说明: Specifications:  
电气特性: Electrical:

1. 额定电流: Current Rating  
5A/contact terminal
2. 额定电压: Voltage Rating  
30V DC
3. 接触阻抗: Contact Resistance  
30 milliohms MAX
4. 耐电压: Dielectric Withstanding Voltage:  
500 V AC AT Sea Level
5. 绝缘阻抗: Insulation Resistance:  
1000MEGA ohms MIN

物理性能: Mechanical:

1. 插拔力: Connector Mate and Unmate Force  
Mate force: 3.57kgf (MAX)  
Unmate force: 1.02kgf (MIN)
2. 端子保持力: Terminal Retention  
1.2kgf (MIN)

原材料: Material:

1. 塑胶: Housing:  
Hing Temperature Thermoplastics,  
Ul 94V-0 PBT White/Black
2. 端子: Contact: Copper Alloy C2680
3. 外壳: Shell: Copper Alloy C2680/SPCC

电镀: Finish:

1. 端子: Contact: Plated Gold in Mating Area:  
Tin On Solder Tails
2. 外壳: Shell:  
Nickel Plating

## 深圳市连欣科技有限公司

品名 (ITEM NO)	USB A/F 180 度 10.0 大 电 流 无 边	图号 (DWG NO)		单位 (UNIT):	MM
料号 (PART NO)	XUDF-012-0107D	版本 (REV)	A/0	比例 (SCALE):	1:1
型号 (MODEL NO)	N/A	日期 (DATE)	2015.06.09	设计 (DESIGN)	
		审核 (CHECKED)	~	批准 (APPROVED)	
		未注公差 UNLESS OTHERWISE SPECIFIED			
					±0.30 ±0.20 ±0.10 ±0°