

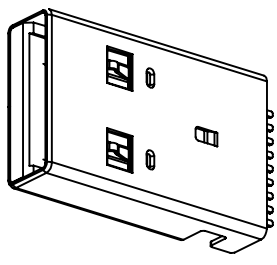
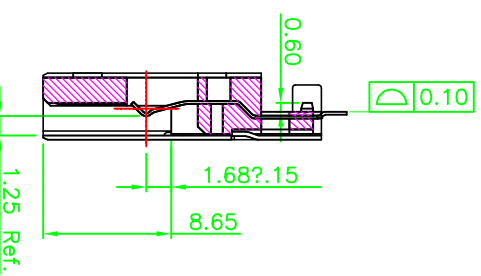
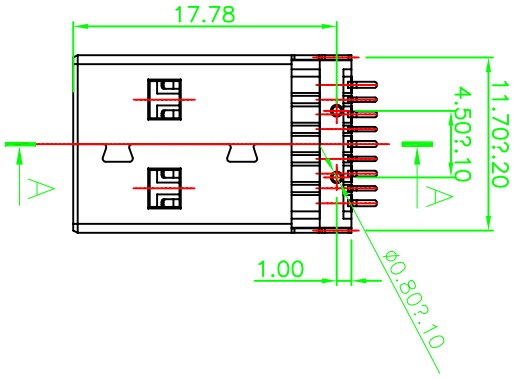
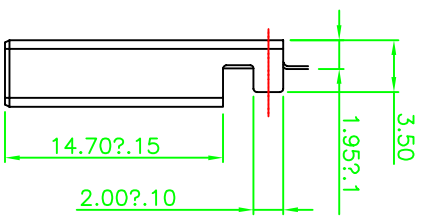
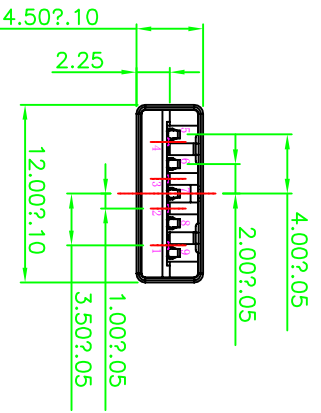


RoHS Compliant

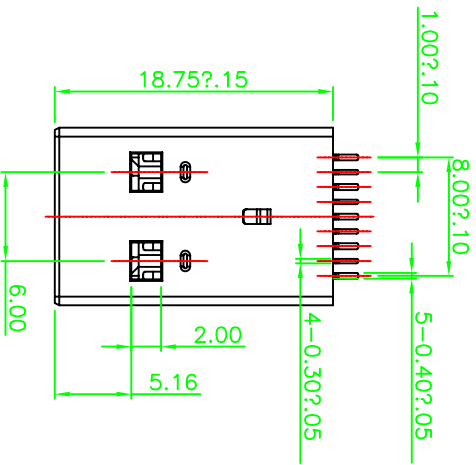

U3M-09SNA0501

- Notes:
- 1) Material:
Insulator : Thermoplastic G.F. UL94V-0,BULE
Contacts : Copper Alloy
Shell : SPCC
 - 2) Environmental :
-55°C to +105°C
 - 3) Electrical
Voltage : 30VAC(R.M.S)
Current Rating : 1.5 Ampere Min.
Contact resistance : 30 Milliohms Max.
Insulation resistance : 100 Megohms Min.
Dielectric withstanding voltage : 500 VAC
 - 4) Finish
Shell : 50u" min. Nickel
Contacts : 1~30u" min. Gold on mating area.
100u" min. Tin on the tails.

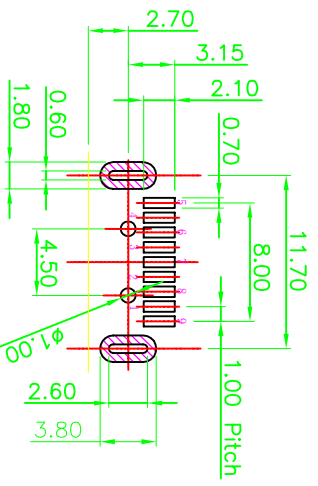

Pin NUMBER	SIGNAL NAME	VERIS
1	D-	
2	D+	
3	D+	
4	GND	
5	Seda_SSTR-	
6	Seda_SSTR+	
7	GND_DRAIN	
8	Seda_SSTR-	
9	Seda_SSTR+	
Shield		

深圳市连欣科技有限公司	
品名 (ITEM NO)	USB3.0 A/M SMT插座1.9外壳3.5有柱 L=18.7
料号 (PART NO)	XUSM-0930-2319
型号 (MODEL NO)	N/A

图号 (DWG NO)	版本 (REV)	日期 (DATE)	设计 (DESIGN)	审核 (CHECKED)	核准 (APPROVED)
A/0	2015.06.09	~			
单位 (UNIT) : MM	比例 (SCALE) 1:1	未注公差 TOLERANCE UNSPECIFIED X.X ±0.30 X.XX ±0.20 X.XXX ±0.10 X.X° ±5° X.X° ±2°			