

# KMK - Plastic cable markers

1005208

<https://www.phoenixcontact.com/us/products/1005208>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Plastic cable markers, transparent, unlabeled, mounting type: Assembly with cable ties, cable diameter range: 10 ... 25 mm, lettering field size: 29 x 8 mm

## Your advantages

- Labeling service: Phoenix Contact can custom-label all insert labels for plastic cable markers according to your requirements
- The marked insert label is protected from dirt by the sealing cap
- Plastic cable markers for marking and bundling conductors and cables indoors

## Commercial data

Item number	1005208
Packing unit	1 pc
Minimum order quantity	100 pc
Sales key	BG12
Product key	BG231A
Catalog page	Page 236 (C-3-2019)
GTIN	4017918012434
Weight per piece (including packing)	2.56 g
Weight per piece (excluding packing)	2.56 g
Customs tariff number	39269097
Country of origin	DE

1005208

<https://www.phoenixcontact.com/us/products/1005208>

## Technical data

### Product properties

Product type	Marker carrier cable
Type	Mounting set

### Dimensions

Width	8 mm
Height	8 mm
Length	29 mm

### External dimensions

Outside diameter	10 mm ... 25 mm
------------------	-----------------

### Material specifications

Color	transparent
Material	Polyethylene
Components	free from silicone and halogen

### Cable/line

External cable diameter	10 mm ... 25 mm
-------------------------	-----------------

### Environmental and real-life conditions

#### Test for substances that would hinder coating with paint or varnish

Result	Test passed
--------	-------------

#### UV resistance

Specification	ISO 4892-2:2013-03 (following)
Result	Test passed
Test duration	96 h
Specification	ISO 175:2010 (following)
Test duration	168 h

#### Testing in a condensation changing climate in the presence of sulfur dioxide

Specification	DIN 50018:2013-05
Result	Test passed
Climate level	AHT 1.0 S
Cycles	2

#### Salt spray test

Specification	DIN EN 60068-2-11:2000-02
Result	Test passed
Test duration	96 h

#### Ambient conditions

# KMK - Plastic cable markers



1005208

<https://www.phoenixcontact.com/us/products/1005208>

Ambient temperature (operation)	-40 °C ... 80 °C
Recommended ambient temperature (storage/transport)	23 °C
Recommended humidity (storage/transport)	50 %
Shelf life	2 years

## Mounting

Mounting type	Assembly with cable ties
---------------	--------------------------

# KMK - Plastic cable markers

1005208

<https://www.phoenixcontact.com/us/products/1005208>



## Classifications

### ECLASS

ECLASS-11.0	27281105
ECLASS-12.0	27281105
ECLASS-13.0	27281105

### ETIM

ETIM 8.0	EC001530
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# KMK - Plastic cable markers



1005208

<https://www.phoenixcontact.com/us/products/1005208>

## Accessories

### UCT-EMP (29X8) - Snap-in markers

1014118

<https://www.phoenixcontact.com/us/products/1014118>



Snap-in markers, Sheet, white, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: insert, lettering field size: 29 x 8 mm, Number of individual labels: 15

---

### ESL 29X8 - Insert strip

0808257

<https://www.phoenixcontact.com/us/products/0808257>



Insert strip, Sheet, white, unlabeled, can be labeled with: Office printing systems, CMS-P1-PLOTTER, perforated, mounting type: insert, lettering field size: 29 x 8 mm, Number of individual labels: 174

## KMK - Plastic cable markers

1005208

<https://www.phoenixcontact.com/us/products/1005208>



### ESL 29X8 YE - Insert strip

0811930

<https://www.phoenixcontact.com/us/products/0811930>

Insert strip, Sheet, yellow, unlabeled, can be labeled with: Office printing systems, CMS-P1-PLOTTER, mounting type: insert, lettering field size: 29 x 8 mm, Number of individual labels: 174



---

### US-EMP (29X8) - Snap-in markers

0829436

<https://www.phoenixcontact.com/us/products/0829436>

Snap-in markers, Card, white, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: insert, lettering field size: 29 x 8 mm, Number of individual labels: 48



# KMK - Plastic cable markers

1005208

<https://www.phoenixcontact.com/us/products/1005208>

## US-EMP (29X8) YE - Snap-in markers

0829440

<https://www.phoenixcontact.com/us/products/0829440>



Snap-in markers, Card, yellow, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: insert, lettering field size: 29 x 8 mm, Number of individual labels: 48

---

## EMT (29X8)R - Insert label

0817277

<https://www.phoenixcontact.com/us/products/0817277>



Insert label, Roll, white, unlabeled, can be labeled with: THERMOMARK E.300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMASTER 300/600, THERMOMARK X1.2, mounting type: insert, cable diameter range: 10 ... 25 mm, lettering field size: 29 x 8 mm, Number of individual labels: 5400

# KMK - Plastic cable markers




1005208

<https://www.phoenixcontact.com/us/products/1005208>

## EMT (29X8)R YE - Insert label

0817280

<https://www.phoenixcontact.com/us/products/0817280>

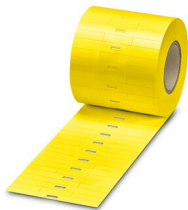

Insert label, Roll, yellow, unlabeled, can be labeled with: THERMOMARK E.300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMASTER 300/600, THERMOMARK X1.2, mounting type: insert, cable diameter range: 10 ... 25 mm, lettering field size: 29 x 8 mm, Number of individual labels: 5400

---

## MM-EMT (EX8)R C1 WH/BK - Insert label

0803965

<https://www.phoenixcontact.com/us/products/0803965>



Insert label, Roll, white/black, unlabeled, can be labeled with: THERMOFOX, THERMOMARK GO, THERMOMARK GO.K, mounting type: snapped, lettering field size: continuous x 6 mm

---

Phoenix Contact 2023 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)