

1

2

3

4

5


CHARACTERISTICS:

MATERIAL:
COLOR: BLACK
OPERATING TEMPERATURE: -20°C UP TO 80°C
COMPLIANCE: LEAD FREE AND ROHS

PACKAGING:
10PCS/BAG

WIRE DIMENSION:
AWG: 16

Terminal A

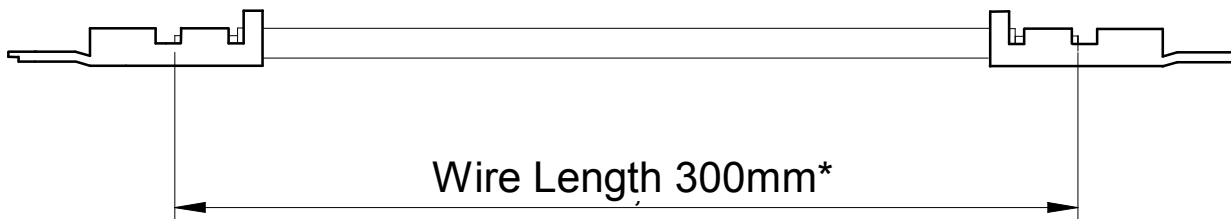

Terminal B

Wire Length 300mm*

Terminal A	649 008 137 22
Terminal B	649 008 137 22

* Note: Wire UL 1007

RoHS Compliant				PROJECTION:	GENERAL TOLERANCE		DESCRIPTION: WR-MPC4 MALE PRE-CRIMPED CONTACT WERI PART NO: 649 849 816 030	SIZE A4
G					.X = +/- 0.2 .XX = +/- 0.15			
F				APPROVAL: RJ	UNIT: MM			
E					SCALE:			
D					SHEET: 1/2			
C					DRAW: QL			
B								
A	18-OCT-11	PDF	GG					
REV	DATE	FILE	BY					

1

2

3

4

5


A

B

C


D

Note:
 1.Dimension
 Carton Size:40*30*20(CM)
 2.Quantity: 5000 Pcs/Carton

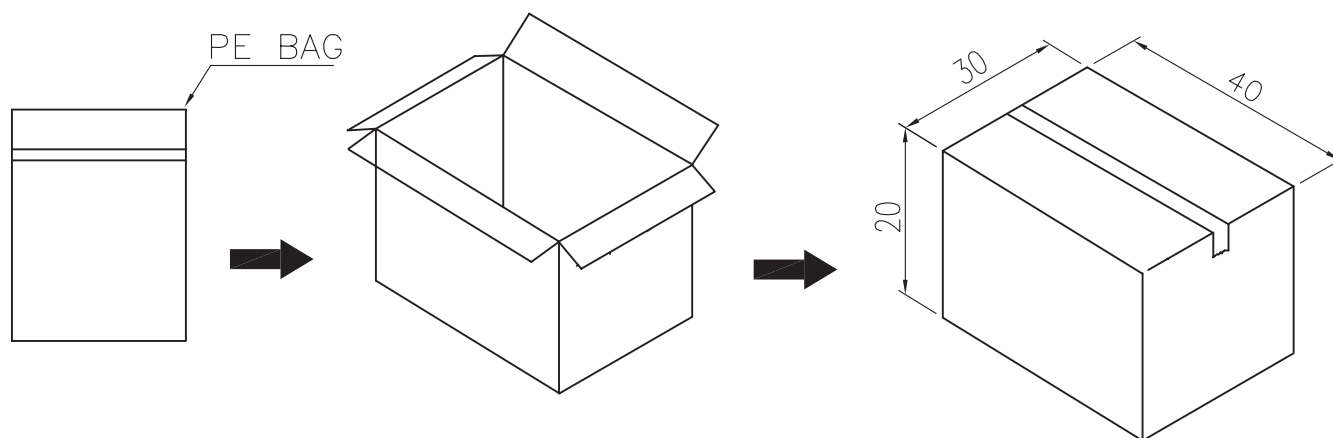

RoHS Compliant

 PROJECTION:



GENERAL TOLERANCE

.X = ± 0.2 .XX = ± 0.15 

APPROVAL: RJ

UNIT: MM

DESCRIPTION: WR-MPC4 MALE PRE-CRIMPED CONTACT

SIZE

 

SCALE:

A4

SHEET: 2/2

WERI PART NO: 649 849 816 030

DRAW: QL

G				PROJECTION: 	GENERAL TOLERANCE .X = ± 0.2 .XX = ± 0.15		DESCRIPTION: WR-MPC4 MALE PRE-CRIMPED CONTACT	SIZE A4
F								
E								
D								
C				APPROVAL: RJ	UNIT: MM	WERI PART NO: 649 849 816 030		
B					SCALE:			
A					SHEET: 2/2			
REV	DATE	FILE	BY		DRAW: QL			