
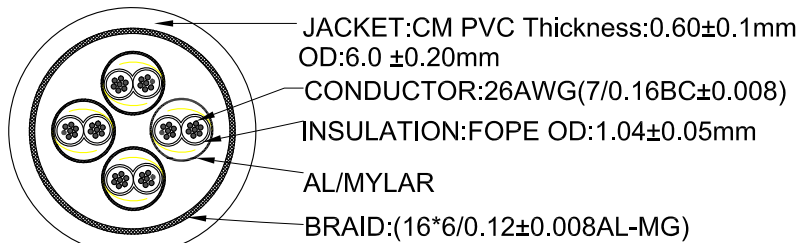


NOTE: ALL MATERIAL COMPLIANT ROHS STANDARD

REVISION INFORMATION			
Rec.	Rec. Date	Modified By	Brief Description

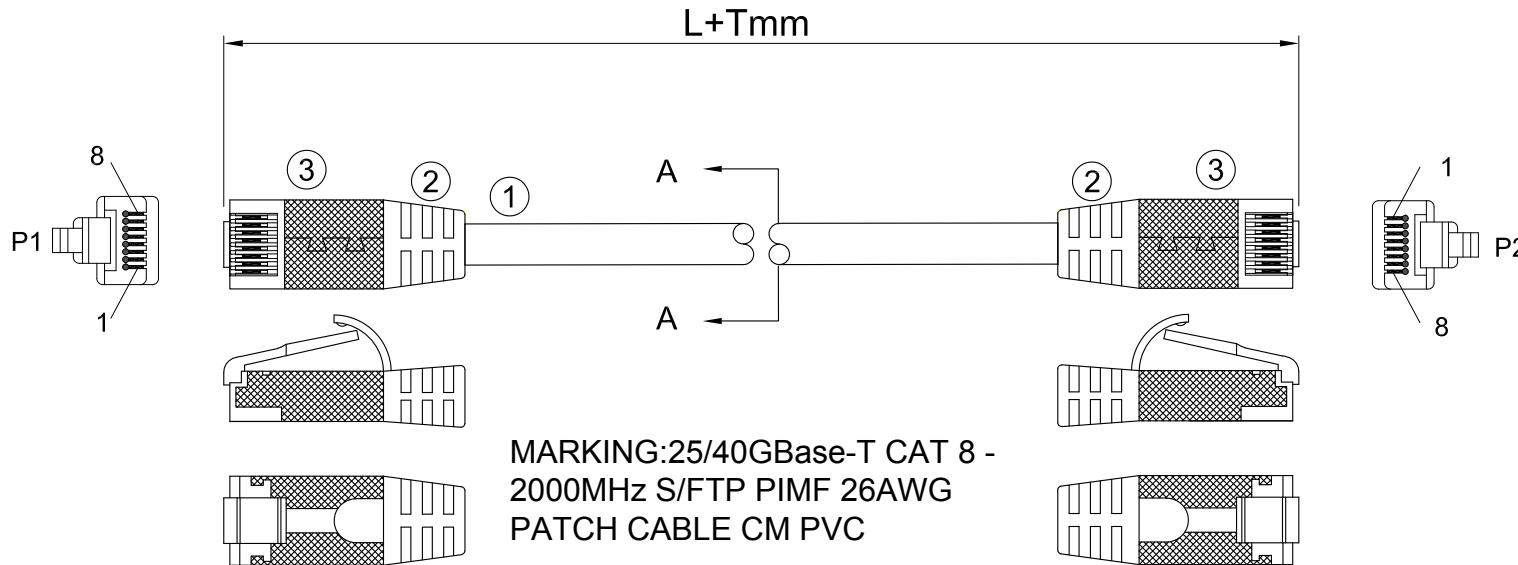

SEC:A-A

orange 1	green 2
white/orange	white/orange
blue 3	brown 4
white/blue	white/brown

Cable Part No. Length Guide

0.5ft.	CM-100370XXBSTK	7ft.	CM-100375XXBSTK
1ft.	CM-100371XXBSTK	8ft.	CM-100377XXBSTK
2ft.	CM-100372XXBSTK	10ft.	CM-100378XXBSTK
3ft.	CM-100373XXBSTK		
5ft.	CM-100374XXBSTK		

Cable Part No. Color Guide *Replace "XX" in the Part No. to the respective color code (e.x. CM-100370GNBSTK for a Green cable)

White = WT	Gray = GY	Black = BK	Blue = BL	Green = GN
Purple = PU	Yellow = YW	Orange = OR	Red = RD	

L(ft)	T(inch)	T(%)	L(ft)	T(inch)	T(%)
0.5	±1.2	20%			
1	±1.2	10%			
2	±1.2	5%			
3	±1.2	3.33%			
4	±1.2	2.5%			
5	±1.2	2%			
7	±2	2.38%			
10	±2	1.67%			

PINOUT		
P1	WIRE	P2
1	WHITE/ORANGE	1
2	ORANGE	2
3	WHITE/GREEN	3
6	GREEN	6
5	WHITE/BLUE	5
4	BLUE	4
7	WHITE/BROWN	7
8	BROWN	8



③	RJ45 PLUG	8P8C 50U" GOLD PLATED TWO-PIECE PLUG.		
②	MOLDED	PVC MOLDED BOOT		
①	CABLE	CAT8 S/FTP 4P/26AWG(7/0.16±0.008MM BC) OD=6.0±0.20mm		
NO.	PART NAME	SPECIFICATION DESCRIPTION	QT'Y	UNIT

Drawn By:	Date: 10 / 31 / 2022	Description: Cat.8 Shielded Cables 26AWG
Checked By:	Sheet 1 of 1	Model No. CM-1003XXXXBSTK
Approved By:	Scale 1:1	Rev. 01 Unit: mm