


Note for plug:

- Material:**
 Housing-Polycarbonate, clear.
 Terminal-0.36[.014] thick phosphor bronze.
 Thick gold in localized gold plate.
 Area, Gold flash over the remainder.
 Over 2.54mm[.000100] thick nickel underplate.
- ① Conductor: [26AWG(0.12x12) BARE COPPER]x8C.
 - ① Insulation: (PP6331 ID:0.95-1.0)x8C.
 - ① Jacket: PVC NOUL 80P.
 - ① Package: Individual PE Bag.

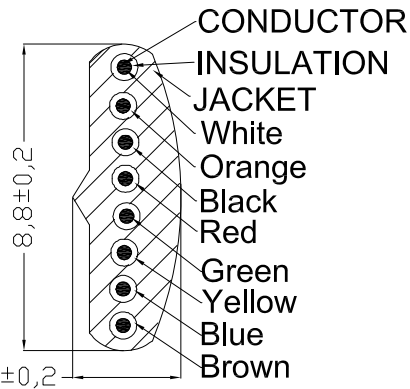

SEC: A-A

P1	P2	
1	White	8
2	Orange	7
3	Black	6
4	Red	5
5	Green	4
6	Yellow	3
7	Blue	2
8	Brown	1

Order code: AT-C-26-8/8/x-xx

Order color:
 B: Black
 W: White
 S: Silver

Length Code	Retracted Length(L3)	Extended Length(L2)	Cut Length(L1)
5	700±50	5.0FT-5.75FT	2900-3000
7	1000±50	7.0FT-8.05FT	4000-4200
10	1500±50	10.0FT-11.5FT	5900-6100
12	1650±50	12.0FT-13.8FT	7000-7200
14	1900±50	14.0FT-16.1FT	7600-7800
25	3200±50	25.0FT-28.75FT	14300-14500

RoHS compliant
 Unit: mm

Scale	Free					Date	Name	Customer-No.
TOLERANCE						Drawn	18.12.2017	Amy
.x	±0.50					Approved	08.05.2019	Amy
.xx	±0.20	②	Update the code	08.05.2019	Segal			ASSMANN WSW-No. AT-C-26-8/8/x-xx
DIM	TOL	①	Update the dimension, notes, and add the cut length	22.02.2019	Segal			
		③	Drawn	18.12.2017	Amy			
Angle	±2°	Id.	Modification	Date	Name	Replace		ASS 8164 CA rev02

RoHS compliant
 Unit: mm