

# 规格书

## Specification

品 名  
Model name

**HYD-4216W**

**PROPRIETARY**  
**Huayu Electronic co.,Ltd.**

**CONFIDENTIAL**  
**Huayu Electronic co.,Ltd.**

Version #	<b>Spec V1.1</b>
制作日期 Date	<b>2022/03/01</b>
准备 Prepared	<b>Yi Shen</b> Acoustic specialist,R&D Dept.
承认 Approved	<b>Qian Wanjin</b> Executive Manager,R&D Dept.



**兴化市华宇电子有限公司**

地址：江苏省兴化市陈堡工业区人民路 1 号

电话：13625199874 传真：0523-83723118

邮箱：[391245375@qq.com](mailto:391245375@qq.com) 网址：[www.js-huayu.com](http://www.js-huayu.com)

*Components Operating Div.  
Huayu Electronic co.,Ltd.*

1. 适用范围: 本规范适用于 HYD-4216W 蜂鸣器。

This specifications apply the HYD-4216W buzzer.

2. 基本规格/General specification

项目/Item		规格/Spec	条件/Condition
1	额定电压 Rated voltage	36VDC	
2	工作电压 Operation voltage	30~38VDC	
3	声压 Sound Pressure Level=SPL	Min 90dB	测试环境: 标准状态, 标准驱动电路, 额定电压 测试距离: 0.1m Standard State, Standard Drive Circuit. Rated voltage, Distance at 0.1m
4	平均消费电流 Average consumption current	Max 39mA	
5	振荡频率 Oscillation frequency	2700±500Hz	
6	工作温度范围 Range of operation temperature	-20~+70°C	
7	保存温度范围 Range of preservation temperature	-30~+80°C	
8	外部尺寸 Externals size	Φ41.8*16	参阅附图 Refer to the attached drawing
9	重量 Mass	12g	

☆标准状态: 常温 (15~35°C), 湿度 (25~85%相对湿度), 空气压力 (860~1060hpa)

在假设的情况判断, 测试是一基本状态下进行。

Standard State: Ordinary Temp(15~35°C), Humidity(25~85%RH), Air pressure(860~1060hPa)



In case of doubtful judgment, the test is re—performed under Basic State.

☆基本情况: 温度。(20±2°C), 湿度 (60~70%相对湿度), 空气压力 (860~1060hpa)



Basic State: Temp.(20±2°C), Humidity(60~70%RH), Air pressure(860~1060hPa)

<标准驱动电路>/<Standard Drive Circuit>

<标标测试治具>/<Standard Test Fixture>

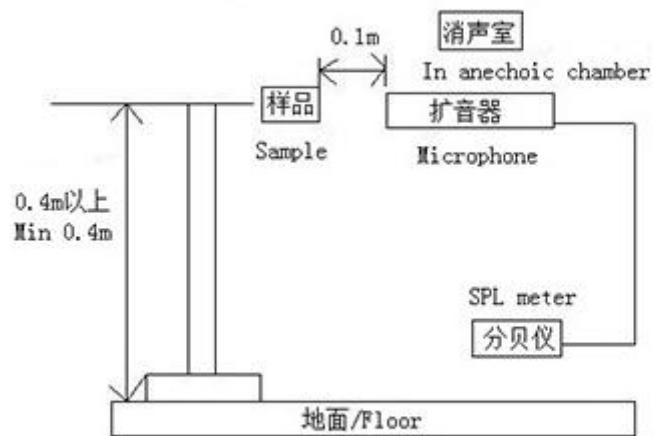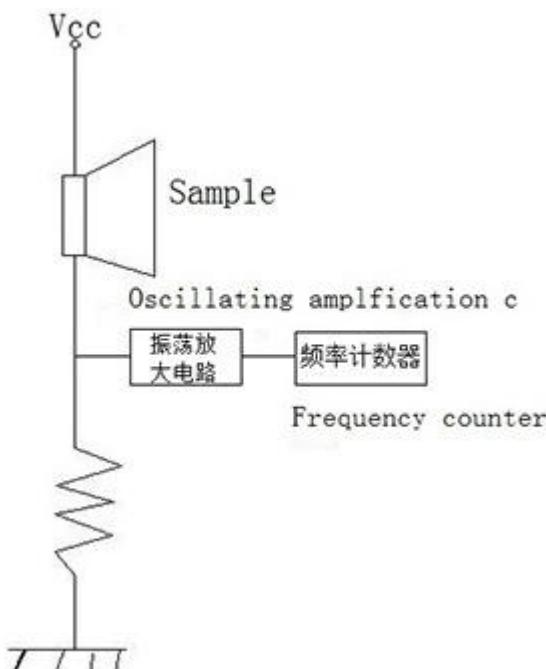


### 3. 可靠性规范/Reliability specification

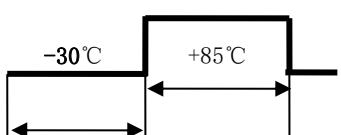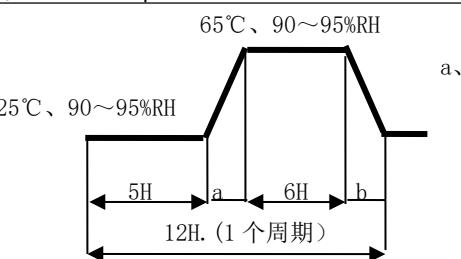项目/Item	试验条件/Test condition	判断标准/Criteria	引用规格/Reference Specification
高温保存试验 High temperature Preservation	+85°C 环境下放置 96 小时 Exposure to +85°C for 96 hrs.	经过测试，符合规格，没有任何不合格的外观和性能，除了是 80 分贝或以上 (2700±500 Hz) After the test the part shall meet specifications without any degradation in appearance And performance except SPL. SPL shall be 80 dB More. (at 2700±500 Hz)	GB/T 2423.2
低温保存试验 Low temperature preservation	-30°C 环境下放置 96 小时 Exposure to -30°C for 96 hrs.	After the test the part shall meet specifications without any degradation in appearance And performance except SPL. SPL shall be 80 dB More. (at 2700±500 Hz)	GB/T 2423.1
耐温试验 Thermal Shock	 10 次周期 10 cycles	10 次周期 10 cycles	GB/T 2423.4
温湿度试验 Thermal, Humidity Shock	 10 cycles	10 cycles	
常温寿命试验 Ordinary Temp. Life	常温 (25°C ±10°C) 电压 36VDC 连续测试 1000 小时 Driving the sounder at 36VDC for 1000hrs in the room temperature (25°C ±10°C)		
高温寿命试验 High Temp. Life	高温 (+80°C) 电压 36VDC 连续测试 500 小时 Driving the sounder at 36VDC for 500hrs in the low temperature (+80°C)		
低温寿命试验 Low Temp. Life	低温 (-20°C) 电压 36VDC 连续测试 500 小时 Driving the sounder at 36VDC for 500hrs in the low temperature (-20°C)		

### 4. 尺寸图/Dimension


(UNIT: mm)

Tolerance: ±0.5mm Except Specified

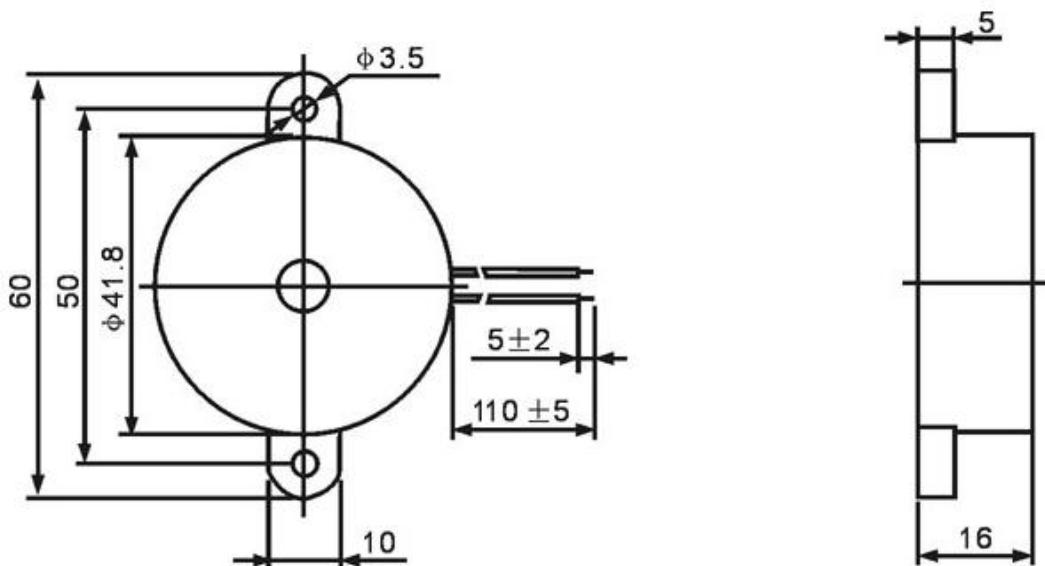

## 5.频率图/Frequency Response:

FREQUENCY RESPONSE

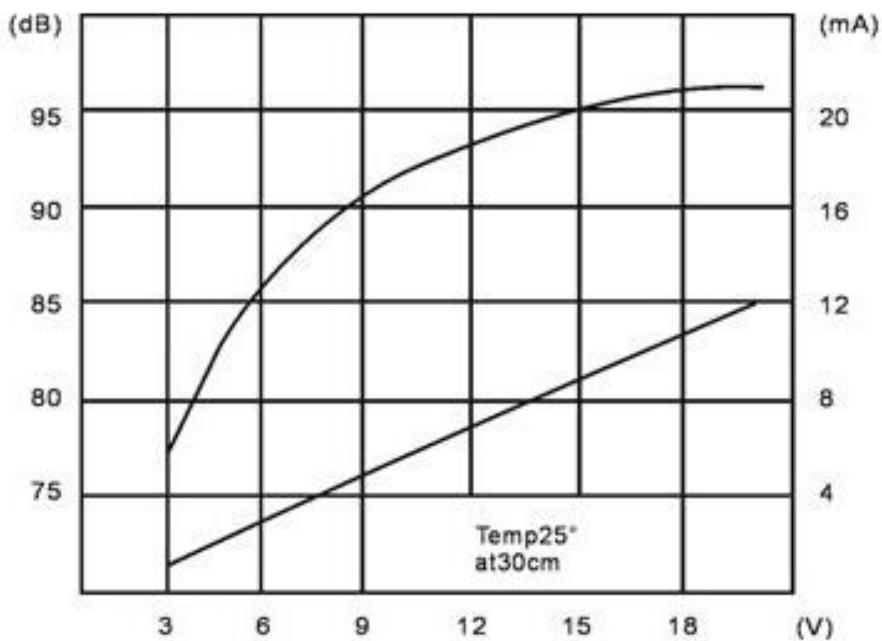

兴化市华宇电子有限公司

地址：江苏省兴化市陈堡工业区人民路 1 号

电话：13625199874 传真：0523-83723118

邮箱：[391245375@qq.com](mailto:391245375@qq.com) 网址：[www.js-huayu.com](http://www.js-huayu.com)

Components Operating Div.  
Huayu Electronic co.,Ltd