

SAC-5P-22AWG-OE-OE-544-300,0SH - Cable reel



1318414

<https://www.phoenixcontact.com/us/products/1318414>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



By the meter, Cable reel, shielded, PVC, gray, 5-wire, color single wire: brown, white, blue, black, gray, cable length: 300 m

Commercial data

Item number	1318414
Packing unit	1 pc
Sales key	BF16
Product key	BF1IIB
GTIN	4063151601614
Weight per piece (including packing)	22.22 g
Weight per piece (excluding packing)	22.22 g
Country of origin	US

SAC-5P-22AWG-OE-OE-544-300,0SH - Cable reel



1318414

<https://www.phoenixcontact.com/us/products/1318414>

Technical data

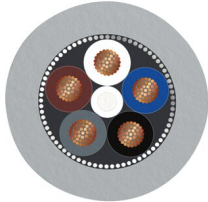
Product properties

Product type	Cable by the meter
Number of positions	5
Application	Connector

Cable/line

Cable length	300 m
--------------	-------

PVC gray 105 °C [544]

Dimensional drawing	
Cable weight	40 kg/km
UL AWM Style	2517 (105 °C / 300 V)
Number of positions	5
Shielded	yes
Cable type	PVC gray 105 °C [544]
Conductor structure signal line	30x 1.30 mm
AWG signal line	22
Wire diameter incl. insulation	1.27 mm ±0.03 mm
External cable diameter	5.9 mm ±0.2 mm
Outer sheath, material	PVC
External sheath, color	gray
Conductor material	Tin-plated Cu litz wires
Material wire insulation	PVC
Single wire, color	brown, white, blue, black, gray
Overall twist	5 wires, twisted
Optical shield covering	85 %
Max. conductor resistance	max. 50.5 Ω/km (20 °C)
Insulation resistance	≥ (550 M Ohms/m @ 500V)
Nominal voltage, cable	300 V
Minimum bending radius, flexible installation	12 x D
Flame resistance	FT4
Other resistance	UV resistant
Special properties	UL standards PLTC and ITC
Ambient temperature (operation)	-30 °C ... 105 °C (cable, fixed installation)

SAC-5P-22AWG-OE-OE-544-300,0SH - Cable reel



1318414

<https://www.phoenixcontact.com/us/products/1318414>

-5 °C ... 105 °C (Cable, flexible installation)

SAC-5P-22AWG-OE-OE-544-300,0SH - Cable reel



1318414

<https://www.phoenixcontact.com/us/products/1318414>

Classifications

ECLASS

ECLASS-11.0	27061801
ECLASS-12.0	27061801
ECLASS-13.0	27061801

SAC-5P-22AWG-OE-OE-544-300,0SH - Cable reel



1318414

<https://www.phoenixcontact.com/us/products/1318414>

Environmental product compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

SAC-5P-22AWG-OE-OE-544-300,0SH - Cable reel



1318414

<https://www.phoenixcontact.com/us/products/1318414>

Accessories

WIREFOX SAC - Stripping tool

1212623

<https://www.phoenixcontact.com/us/products/1212623>



Stripping pliers, for halogen-free sensor/actuator cables (SAC cables), with PUR and PVC insulation, from Ø of 4.4 to 7 mm, any stripping length

Phoenix Contact 2023 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com