
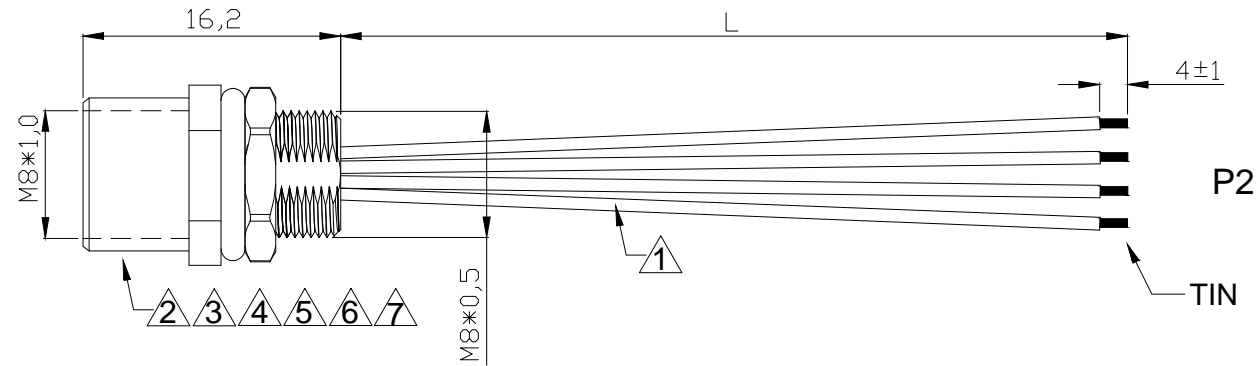


RECOMMEND
PANEL CUT-OUT

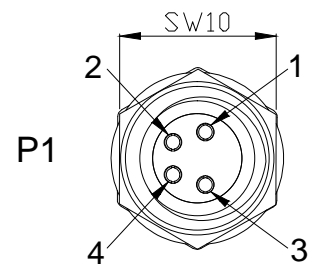

② Order Code:
A-M08A04FSTxxx16BK00

L:
050: 500mm ±15mm
100: 1000mm ±15mm
200: 2000mm ±20mm
300: 3000mm ±30mm
500: 5000mm ±50mm

WIRE LIST

P1	COLOR	P2
1	BROWN	S/T
2	WHITE	
3	BLUE	
4	BLACK	

- Notes:
Detailed Product Description:
1. Waterproof connector rating is IP67/IP68
2. Protected from dust and water during immersion, resistant to many oils and chemical etc.
3. Outer Jacket material : PVC

- Other Specification:
4. Rating voltage: 60V AC/DC
5. Rating current: 3A
6. Insulation resistance: >100MΩ.
7. Contact resistance of connector: ≤10mΩ.
8. Operating Temperature: -25°C ~ +85°C.

⑦	O-RING BLACK FKM Ø4.0*1.0mm	1	PCS
⑥	M8*0.5 BRASS PLATED NI NUT L*W=2.0*1.0mm	1	PCS
⑤	BLACK EPOXY RESIN	1	G
④	O-RING BLACK FKM Ø7.00*1.5mm	1	PCS
③	M8 BRASS PLATED NI FEMALE REAR MOUNT M8*0.5 L=16.2mm	1	PCS
②	M8 A CODING 4 PIN FEMALE CONNECTOR	1	SET
①	UL1007 24AWG HOOK UP WIRE	1	SET
ITEM	SPECIFICATION	Q'TY	UNIT

RoHS compliant
Unit: mm

Scale	Free					Date	Name	Customer-No.
TOLERANCE						Drawn	21.11.2018	Segal
.X	±0.5					Approved	31.05.2023	Winnie
.XX	±0.20							
		②	Add the order code	31.05.2023	Winnie			
DIM	TOL	①	Update the P/N	26.01.2019	Segal			
X.	±2.0°							
.X	±1.0°	①	Drawn	21.11.2018	Segal			
Angle	TOL	Id.	Modification	Date	Name			



ASSMANN WSW-No. ① A-M08A04FSTxxx16BK00	
Drawing-No. ASS 8413 CA	rev02
Replace	Sheet