
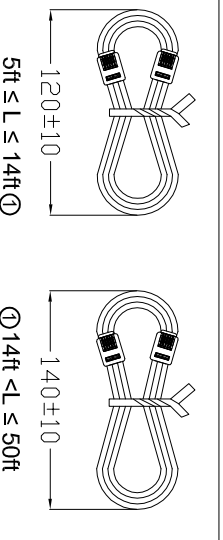


Conductor: {26AWG(0.16x7)BC}x8C
 Insulation: (PP6331 TD:0.95±0.03)x8C
 Jacket: PVC NOUL 65P

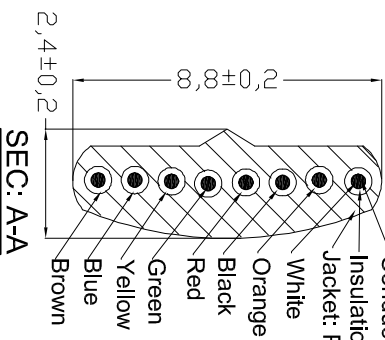

P1	P2
1 — White	1
2 — Orange	2
3 — Black	3
4 — Red	4
5 — Green	5
6 — Yellow	6
7 — Blue	7
8 — Brown	8

Note for plug:

Material:
 Housing-Polycarbonate, clear.
 Terminal-0.36[.014] thick phosphor bronze.
 Thick gold in localized gold plate.
 Area, Gold flash over the remainder.
 Over 2.54mm[.000100] thick nickel underplate

Order code: AT-S-26-8/8-X-XX/R

Order color: _____
 B: Black
 W: White
 S: Silver

Length Code	Length (mm)
5	1525±20(5FT)
7	2135±30(7FT)
10	3050±60(10FT)
12	3660±60(12FT)
14	4270±60(14FT)
25	7625±100(25FT)
50	15250±150(50FT)

RoHS compliant

Unit: mm

Scale	Free	Date	Name
TOLERANCE			
.X	±0.50	18.12.2017	Any
.XX	±0.20	11.10.2018	Any
DIM TOL			
Update the package bending length			
Drawn			
Angle	±2°	Date	Name

ASSMANN
 wsw components

Customer-No. _____
 ASSMANN WSW-No.
AT-S-26-8/8-X-XX/R
 Drawing-No.
ASS 8171 CA
 Replace

rev01

1 2 3 4 5 6 7

A B C D E F G H