


USB 2.0 Panel Mount Cable, 5-Pin Motherboard IDC to USB-A (F/F), 1 ft. (0.31 m)

MODEL NUMBER: **U024-001-5P-PM**

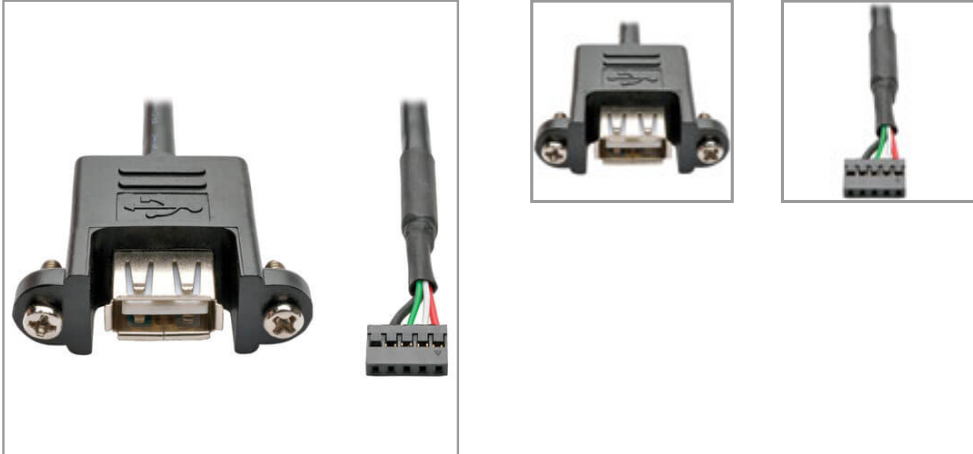

Connects your computer's motherboard to a panel-mounted USB-A port that can be installed in a computer, booth, kiosk or podium.

Features

Adds a Panel-Mounted USB-A Port Allows convenient USB access from a trade show booth, retail kiosk or lecturer's podium
 5-pin PCB header terminates on computer's motherboard
 Supports data transfer speeds up to 480 Mbps
 Backward compatible with previous USB generations

Premium Construction for Premium Performance Corrosion-resistant gold-plated contacts for optimal signal transfer
 Fully molded construction with strain relief for durability and long life
 Flexible PVC jacket easy to install in tight spaces
 Double shielding with aluminum braid, aluminum Mylar foil and twisted 28/24 AWG data/power lines
 Mounting screws included

Specifications

OVERVIEW	
UPC Code	037332191106
Technology	USB 2.0 (High Speed)
USB Cable Type	Passive
PHYSICAL	
Cable Jacket Color	Black
Cable Length (ft.)	1
Cable Length (m)	0.30
Shipping Dimensions (hwd / in.)	7.00 x 9.00 x 0.50
Shipping Dimensions (hwd / cm)	17.78 x 22.86 x 1.27

Highlights

- Supports data transfer speeds up to 480 Mbps
- 5-pin PCB header connects to computer's motherboard
- USB-A port attaches with included screws
- Corrosion-resistant gold-plated contacts
- Backward compatible with previous USB generations

System Requirements

- Computer with 5-pin motherboard connector

Package Includes

- U024-001-5P-PM USB 2.0 Hi-Speed Panel Mount Cable, 1 ft.
- (2) Mounting screws



Shipping Weight (lbs.)	0.08
Shipping Weight (kg)	0.04
ENVIRONMENTAL	
Operating Temperature Range	14 to 122 F (-10 to 50 C)
Storage Temperature Range	5 to 140 F (-15 to 60 C)
Operating Humidity Range	0% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 81% RH, Non-Condensing
CONNECTIONS	
Side A - Connector 1	5 PIN IDC (FEMALE)
Side B - Connector 1	USB A (FEMALE)
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2022 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>