


Specification Sheet

Part Number: FC2.2H4

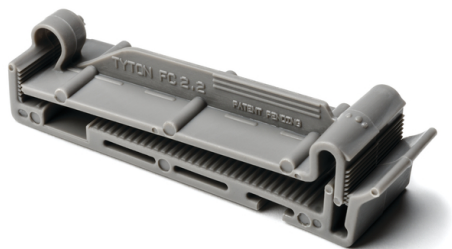

Adjustable-height feature allows the clamp to close to the exact height of the ribbon cable.

Releasable for easy access to cables when necessary.

Flat Ribbon Clamp, 2.2" Max Cable Width, 0.156" Hole Dia, PA66, Gray, 500/pkg

Article Number 154-00014

Type FC2.2

Color Gray (GY)

Quantity Per bag

Product Description HellermannTyton's flat ribbon clamps route, protect and secure flat ribbon cables without damage to sensitive wires and cables. The unique, adjustable height feature allows the clamp to close to the exact height of the ribbon cable, using only as much force as needed to secure the cable. The releasable feature allows simple opening when access to the cable is necessary.

Short Description Flat Ribbon Clamp, 2.2" Max Cable Width, 0.156" Hole Dia, PA66, Gray, 500/pkg

Global Part Name FC2.2-PA66-GY

Length L (Imperial) 1.5

Length L (Metric) 38.1

Width W (Imperial) 2.5

Width W (Metric) 63.5

Height H (Imperial) 0.51

Height H (Metric) 12.95

Mounting Hole Diameter D (Imperial) 0.156

Mounting Hole Diameter D (Metric) 4.0 mm

Mounting Hole Diameter D Min (Imperial) 0.156

Mounting Hole Diameter D Max (Imperial) 0.156

Mounting Hole Diameter D Max (Metric) 4.0

Material Polyamide 6.6 (PA66)

Material Shortcut PA66

Flammability UL 94 V-2

UV Resistant (Yes/No)	No
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	No
ROHS Compliant	Yes
Package Quantity (Imperial)	500
Package Quantity (Metric)	500
Customs Number	3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 39 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

© 2023 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)