



ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	COMPONENT NOTES
1	30-00928	Wire, 6C BC, 24 AWG, UL20280, 300V, 80C, 5.4 mm, braided shield, FT2, TPU	1	

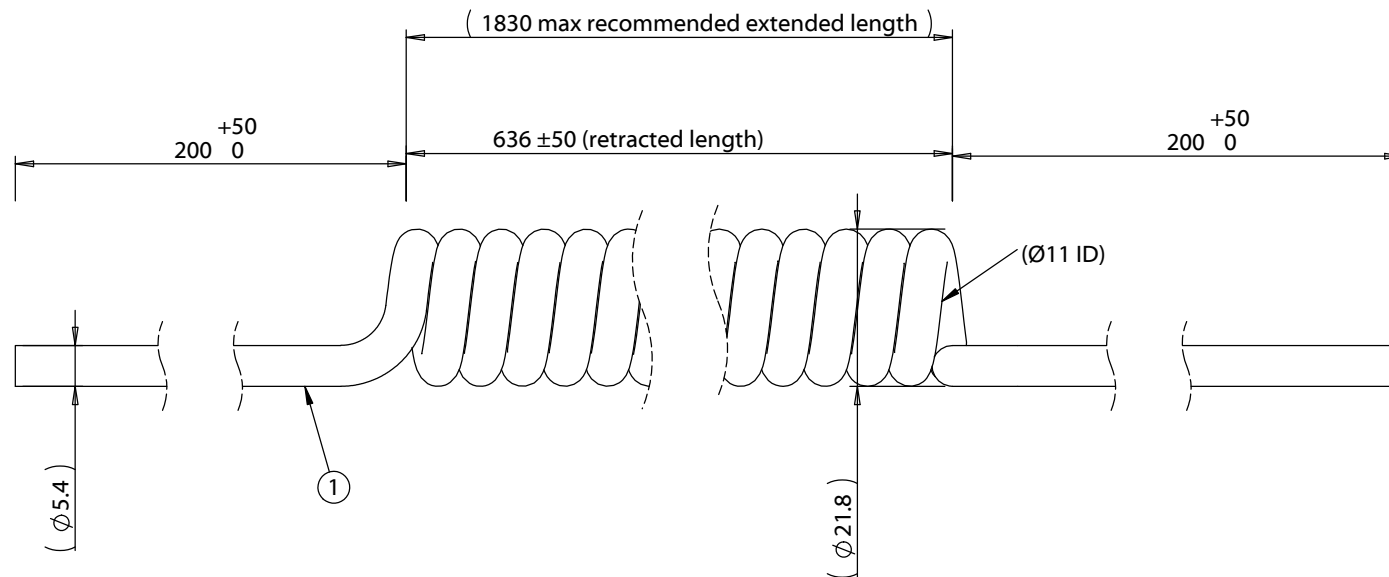

**Notes:**  
Total wire length for resistance calculation: 6500 mm

Revision:	Date:	Description:	Prepared:	Notes: RoHS and REACH compliant Phthalate and halogen free Function test: no open, no short circuit, no intermittent	<h1>TENSILITY</h1> <p>tel 1.541.323.3228 800 877.670.7118 fax 1.541.323.4202 web tensility.com</p>	
A	10/17/2018	Initial release	Verified:			
			Dimensions are in millimeters. Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Description:	Size: Part number:	
				Coiled cable, 2230 mm, 6C blunt cut to same, 24 AWG, 5.4 mm, TPU, shielded, 30-00928 wire	A 31-00082	
				Scale: 1:1		Sheet 1 of 1

5

4

3

2

1