

Molex's range of pre-crimped leads offers a simple, cost-effective solution for prototyping, pre-production and mass production requirements. These leads are offered in female-to-female and male-to-male configurations in lengths of 75.00 to 600.00mm

### Features and Advantages


Pre-crimped and fully tested cables	Decrease time to market
Available in 75.00 to 600.00mm lengths	Works well for all prototype and pre-production requirements
Leads crimped on both ends	Allows for wire-to-wire applications and when cut in half, wire-to-board applications
UL listed cables	Helps ensure high-quality approved materials
Available for most popular Molex families	Helps customers choose the right connector before investing in application tooling



C-Grid III      CLIK-Mate      DuraClik




KK      L1NK 396      Mega-Fit

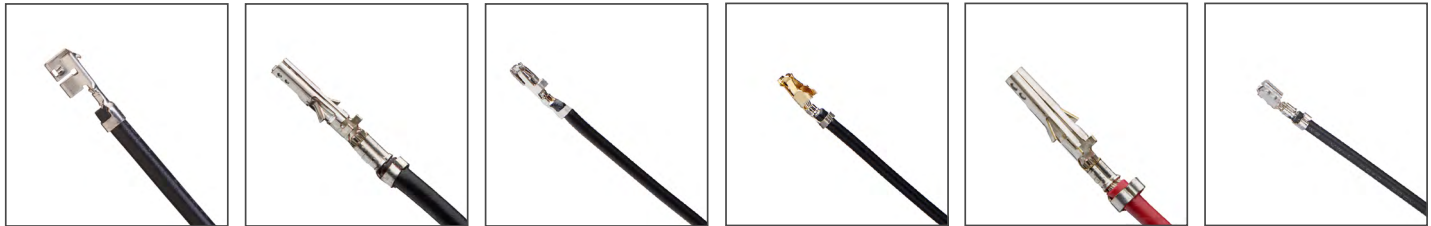


MicroClasp      Micro-Fit 3.0      Micro-Lock Plus      Milli-Grid      Mini-Fit      Mini-Lock



Mizu-P25      MLX      MultiCat      MX150      Nano-Fit      PicoBlade

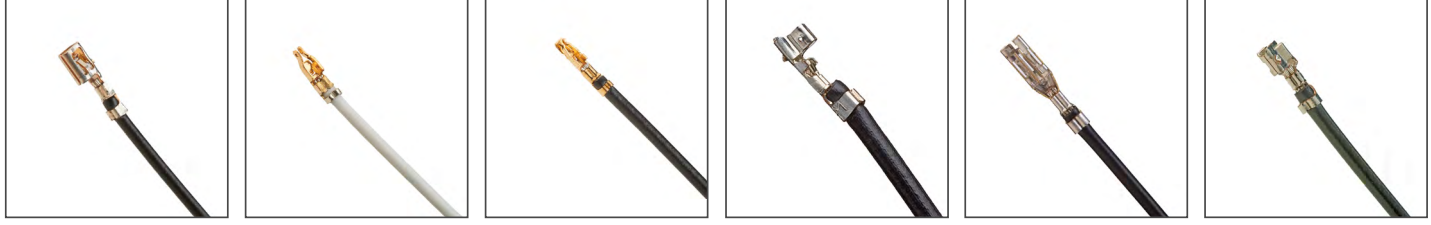

Pico-Clasp      Pico-EZmate      Pico-Lock      Pico-SPOX      Sabre      Sherlock

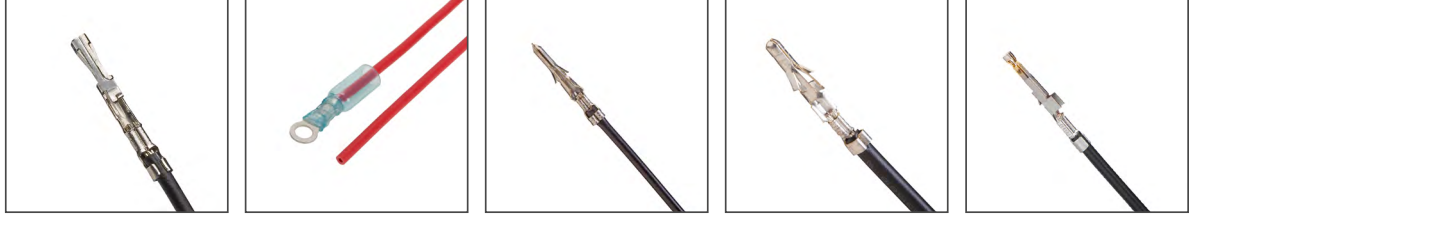

SL      Solderless Ring      Standard .062"      Standard .093"      Ultra-Fit

Product Family	Series Number	Length (mm)	Connector A	Connector B	Wire Size (AWG)	Wire/Cable Type
C-Grid	79758	150, 300	Female	Female	22	UL 1061
CLIK-Mate	79758, 215710, 215711	75, 150, 225, 300, 450	Female, Male	Female, Male, -	24, 26, 28	UL 1061, UL 10002
DuraClik	79758	150, 300	Female	Female	26	UL 1061
KK	79758	150, 300	Female, Male	Female, Male	22, 24	UL 1061, UL 1007
L1NK 396	79758	150	Female	Female	18	UL 1051
Mega-Fit	79758	150, 300	Female	Female	16, 12	UL 1015
Micro-Clasp	79758	150, 300	Female	Female	24	UL 1007
Micro-Fit 3.0	79758, 214760, 214761, 214762, 214763	150, 300, 600	Female, Male	Female, Male, -	18, 20	UL 1061, UL10002
Micro-Lock Plus	79758	150, 300	Female	Female	26	UL 1061
Milli-Grid	79758	150, 300	Female	Female	24	UL 1061
Mini-Fit	79758, 215340, 215341, 215342, 215343	75, 150, 225, 300, 450	Female, Male	Female, Male	16, 18, 20	UL 1015, UL 1061
Mini-Lock	79758	150, 300	Female	Female	22	UL 1061
Mizu-P25	217840, 217841, 217842, 217843, 217520, 217521, 217522, 217523	75, 150, 225, 300, 450,	Female, Male	Female, Male	20, 22	UL10002, FLYR-B
MLX	79758	150, 300	Female, Male	Female, Male	18	UL 1015
Multicat	79758	150, 300	Female, Male	Female, Male	8, 9, 12, 16	UL 1199
MX150	216300, 216301, 216302, 216303	150, 225, 300, 450, 600	Female, Male	Female, Male	14, 16, 18	TXL
Nano-Fit	79758	150, 300	Female	Female	20	UL 1061
PicoBlade	79758, 214920, 214921, 214922, 214923	75, 150, 225, 300, 450	Female, Male	Female, Male, -	26, 28, 26 and 28	UL1061
Pico-Clasp	79758	150, 300	Female	Female	28	UL 1571

### Ordering Information

Product Family	Series Number	Length (mm)	Connector A	Connector B	Wire Size (AWG)	Wire/Cable Type
Pico-EZmate	79758	300	Female	Female	28	UL 1516
Pico-Lock	79758	150, 300	Female	Female	24, 30	UL 1061, UL 1571
Pico-SPOX	79758	150, 300	Female	Female	24	UL 1061
Sabre	79758	150, 300	Female, Male	Female, Male	16	UL 1015
Sherlock	79758	150, 300	Female	Female	26	UL 1061
SL	79758	150	Female	Female	22	UL 1061
Standard .062"	79758	150, 300	Female, Male	Female, Male	22	UL 1015
Standard .093"	79758	150, 300	Female, Male	Female, Male	18	UL 1015
Ultra-Fit	79758, 217470, 217471	75, 150, 225, 300, 450	Female	Female	16, 18, 20	UL 1061, UL 11028

Product Family	Series Number	Length (mm)	Stud Size	Wire Termination	Wire Size (AWG)	Wire/Cable Type
Solderless Ring Terminal	217851	150	10 (M5)	Blunt cut	16 AWG	UL 1015
		300				
		600				