

# P1AD-18FF-65G

1.85mm Female to 1.85mm Female Straight Adapter. Frequency DC to 65 GHz, maximum VSWR of 1.25.

## Product Features

Precision 50 Ohm RF adapter, 1.85mm female to 1.85mm female.

Frequency DC to 65 GHz with a max VSWR 1.25.

Passivated stainless steel body



Electrical Specification:  $T_{\text{Ambient}} = 25^{\circ}\text{C}$

Parameter	Frequency Range	Units	Min	Typical	Max	Notes
Frequency Range		GHz	DC		65.0	
Impedance				50.0		


Mechanical And Environmental Specifications:

Parameter	Description	Notes
Connector 1	1.85mm Female	
Connector 2	1.85mm Female	
RoHS Compliance	Yes	

Drawing

# P1AD-18FF-65G

1.85mm Female to 1.85mm Female Straight Adapter. Frequency DC to 65 GHz, maximum VSWR of 1.25.

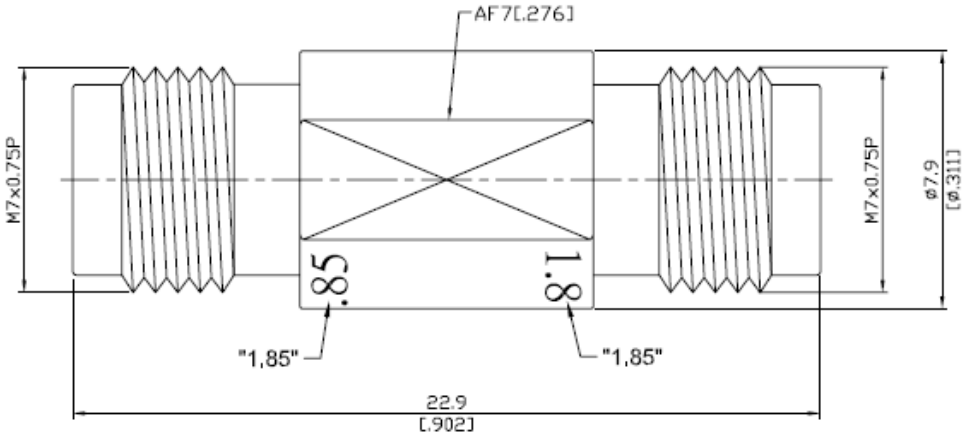

## Product Notes