


# M83723/59-2 BAYONET PLUG DUST CAP

MIL-DTL-26500 Series III

M83723/59-2	SHELL SIZE	FINISH	STYLE
Designated Receptacle Cover	8	W - Cadmium	P - w/ Chain Length 8in + .25in
	10		C - w/ Chain Length 5in + .25in
	12		
	14	R - Electroless Nickel	R - w/ Rope Length 5in + .25in
	16		
	18	A - Anodized Black	T - w/ Rope Length 8in + .25in
	20		
	22	Z - Black Zinc Nickel	N - w/o Chain
24			

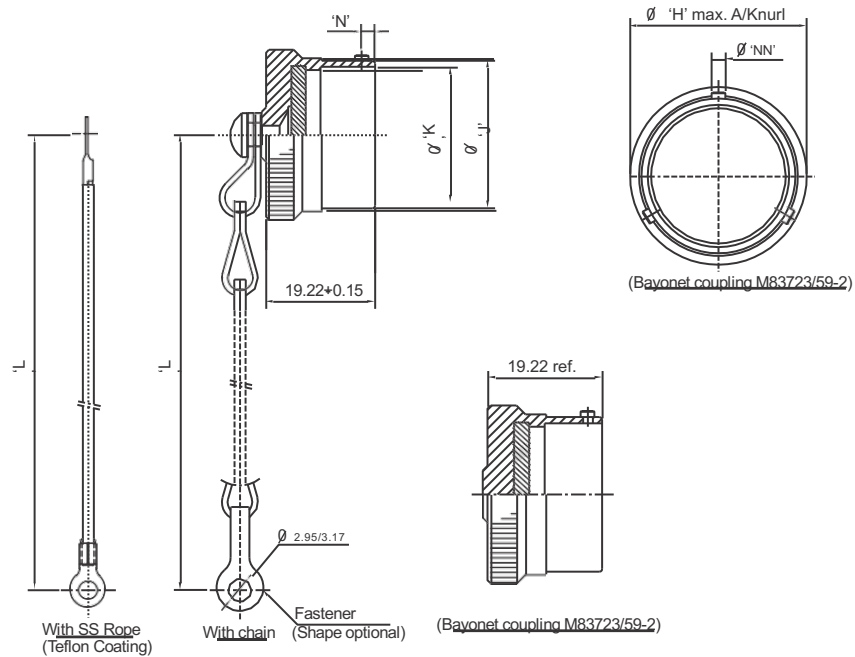

Shell Size	H Max		Ø J		Ø K		Ø N		Ø NN		Chain S/Assembly L		SS Rope S/Assembly L	
			+0.0 - 0.13		+0.13 - 0.0		+0.0 - 0.10		+0.0 - 0.08		+6.35 - 0.0		+6.35 - 0.0	
	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in
8	19.46	0.76	13.61	0.534	12.07	0.48	2.57	0.10	1.98	0.08	127.0	5	203.20	8
10	23.01	0.91	16.74	0.656	14.63	0.58	2.39	0.04	2.36	0.09				
12	27.38	1.08	21.06	0.83	18.95	0.75								
14	28.98	1.14	22.81	0.90	20.70	0.81								
16	32.16	1.27	26.04	1.03	23.93	0.94								
18	34.93	1.38	28.73	1.13	26.62	1.05								
20	38.35	1.51	31.90	1.26	29.74	1.17								
22	41.28	1.62	35.08	1.38	32.94	1.30								
24	44.70	1.76	38.25	1.51	36.07	1.42								