



Quality Products. Service Excellence.

Audio Sound Distribution Line Matching 119 Series


Features



- Suitable for driving from solid state amplifiers where isolated windings are not required or can be used with our "Classic" 1600 tube output transformers to provide a 25V or 70V line output.
- 8 or 16 ohm input, 25V or 70V line output.
- Frequency response 50 Hz. to 10 KHz. at full ratings
- Leads 6" long minimum
- Can be reversed for operation at high power speaker locations.
- For speaker matching from older "Classic" 600 Ohm equipment - check out our **119DA** matching transformer.



Gallery

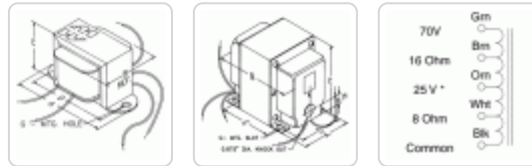

| Part No. | Max Output (Watts) | Line Output | Mounting Type | Mounting Centers | Mounting Hole Slot G | Wt. (lbs.) | Drawing Figure | Overall Dimensions | | | | |
|----------|--------------------|-------------|---------------|------------------|----------------------|-------------|----------------|--------------------|------|------|------|------|
| | | | | | | | | A | B | C | D | E |
| 119Y30 | 30 | 70 & 25v | Bracket | 3.56 | 0.19 | 2.40 | 1.00 | 4.03 | 2.25 | 2.63 | 3.56 | - |
| 119Y60 | 60 | 70 & 25v | X Mtg. | 2.00 x 2.19 | 0.20 x 0.38 | 3.30 | 2.00 | 2.50 | 3.25 | 3.06 | 2.00 | 2.19 |
| 119Y100 | 100 | 70v only | X Mtg. | 2.50 x 2.19 | 0.20 x 0.38 | 4.70 | 2.00 | 3.13 | 3.50 | 3.81 | 2.50 | 2.19 |
| 119Y250 | 250 | 70v only | X Mtg. | 2.50 x 2.94 | 0.20 x 0.38 | 6.70 | 2.00 | 3.13 | 4.25 | 3.81 | 2.50 | 2.94 |

Tags: audio transformer, speaker, solid state, amplifier, output

Data subject to change without notice

© 2023. Hammond Manufacturing Ltd. All rights reserved.