


MIL-DTL-83723/60-2 BAYONET RECEPTACLE DUST CAP

MIL-DTL-26500 Series III

M83723/60-2	24	Z	T
	SHELL SIZE	FINISH	STYLE
Designated Receptacle Cover	8	W - Cadmium	P - w/ Chain Length 8in + .25in
	10		C - w/ Chain Length 5in + .25in
	12	R - Electroless Nickel	R - w/ Rope Length 5in + .25in
	14		T - w/ Rope Length 8in + .25in
	16	A - Anodized Black	N - w/o Chain
	18	Z - Black Zinc Nickel	
	20		
	22		
24			

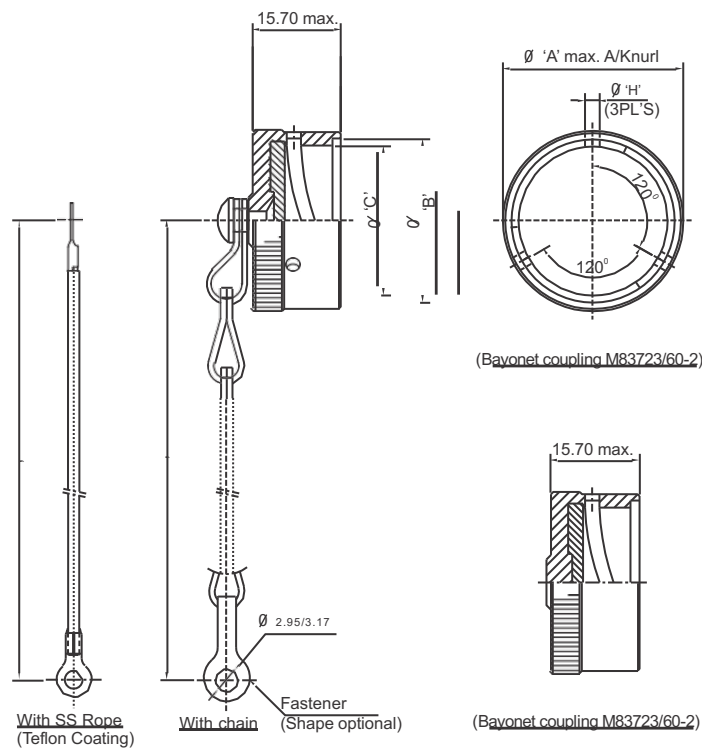

Shell Size	A MAX		Ø B MAX		Ø C MAX		H MIN	
					+0.13 - 0.0			
	mm	in	mm	in	mm	in	mm	in
8	19.71	0.78	16.20	0.64	13.72	0.54	2.01	0.08
10	23.01	0.91	19.40	0.76	16.81	0.66	2.39	0.09
12	27.38	1.08	23.80	0.94	21.13	0.83		
14	28.98	1.14	25.50	1.00	22.89	0.90		
16	32.16	1.27	28.70	1.123	26.11	1.027		
18	34.93	1.38	31.50	1.24	28.80	1.13		
20	38.35	1.51	34.60	1.36	32.03	1.26		
22	41.28	1.63	37.80	1.49	35.15	1.38		
24	44.70	1.76	40.90	1.61	38.38	1.51		