


Assorted Wire Ferrules

Provide **high quality termination** and years of trouble free service

All ferrules are made with **tin plated copper**. Insulated ferrules plastic material is polypropylene, **heat resistant to 105°C** (UL/CSA* and RoHS)

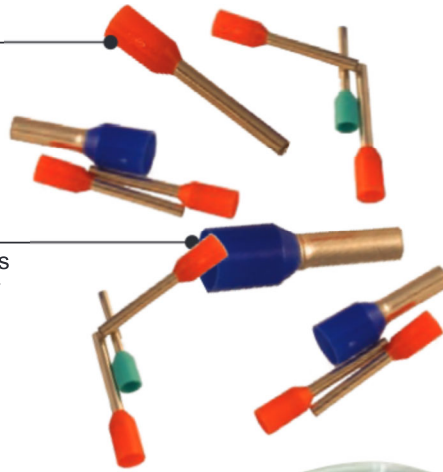

701-998

Wire Ferrule Assortment Pack

Contents

50 pcs 701-028(Insulated wire ferrule, AWG 20, orange)
100 pcs 701-011(Insulated wire ferrule, AWG 18, white)
100 pcs 701-014(Insulated wire ferrule, AWG 18, yellow)
100 pcs 701-016(Insulated wire ferrule, AWG 16, red)
50 pcs 701-022(Insulated wire ferrule, AWG 14, blue)

Individual packing

Plastic compartment wheel




Uninsulated Wire Ferrules


Model No.	AWG	mm ²	L1	d1	d2	Bag Q'ty
701-001	24	0.25	5	0.8	1.7	1000
701-129	22	0.34	5	0.85	1.8	1000
701-047	20	0.50	6	1.0	2.1	1000
701-048	20	0.50	10	1.0	2.1	1000
701-002	18	0.75	6	1.2	2.3	1000
701-136	18	0.75	8	1.2	2.3	1000
701-049	18	0.75	10	1.2	2.3	1000
701-050	18	1.00	6	1.4	2.5	1000
701-003	18	1.00	10	1.4	2.5	1000
701-051	16	1.50	7	1.7	2.8	1000
701-004	16	1.50	10	1.7	2.8	1000
701-052	16	1.50	12	1.7	2.8	1000
701-053	16	1.50	18	1.7	2.8	1000
701-054	14	2.50	7	2.2	3.4	1000
701-005	14	2.50	10	2.2	3.4	1000
701-055	14	2.50	12	2.2	3.4	1000
701-056	14	2.50	18	2.2	3.4	1000
701-057	12	4.00	9	2.8	4.0	500
701-006	12	4.00	12	2.8	4.0	1000
701-058	12	4.00	15	2.8	4.0	500
701-059	12	4.00	18	2.8	4.0	500
701-060	10	6.00	10	3.5	4.7	500
701-061	10	6.00	12	3.5	4.7	500
701-062	10	6.00	15	3.5	4.7	500
701-063	10	6.00	18	3.5	4.7	500
701-064	8	10.00	12	4.5	5.8	250

Model No.	AWG	mm ²	L1	d1	d2	Bag Q'ty
701-065	8	10.00	15	4.5	5.8	250
701-066	8	10.00	18	4.5	5.8	250
701-147	8	10.00	25	4.5	5.8	500
701-067	6	16.00	12	5.8	7.5	200
701-068	6	16.00	15	5.8	7.5	200
701-069	6	16.00	18	5.8	7.5	200
701-070	6	16.00	25	5.8	7.5	200
701-071	6	16.00	32	5.8	7.5	200
701-115	4	25.00	12	7.3	9.5	100
701-072	4	25.00	15	7.3	9.5	200
701-073	4	25.00	18	7.3	9.5	200
701-074	4	25.00	25	7.3	9.5	200
701-075	4	25.00	32	7.3	9.5	200
701-076	2	35.00	18	8.3	11.0	100
701-077	2	35.00	25	8.3	11.0	100
701-078	2	35.00	30	8.3	11.0	100
701-079	2	35.00	32	8.3	11.0	100
701-080	1/0	50.00	18	10.3	13.0	100
701-081	1/0	50.00	25	10.3	13.0	100
701-082	1/0	50.00	32	10.3	13.0	100
701-142	2/0	70.00	25	12.5	15.0	100
701-125	2/0	70.00	32	12.5	15.0	100
701-126	3/0	95.00	32	14.5	17.0	100
701-127	4/0	120.00	32	17.2	19.0	100
701-128	300 MCM	150.00	32	19.5	21.0	100
701-146	350 MCM	185.00	32	20.0	23.5	100
701-148	500 MCM	240.00	40	23.0	25.0	25

 
Insulated Wire Ferrules



Uninsulated Wire Ferrules

 

Twin Wire Ferrules

 

Individual packing
Poly Bag or Blister card

Insulated Wire Ferrules

Model No.	AWG	mm ²	color	L1	L2	d1	d2	Pkg Qty
701-088	26-28	0.14	Gray	10	6	0.60	1.5	500
701-088-100	26-28	0.14	Gray	10	6	0.60	1.5	100
701-025	24	0.25	Lt.Blue	10	6	0.85	1.8	500
701-025-100	24	0.25	Lt.Blue	10	6	0.85	1.8	100
701-104	24	0.25	Yellow	10	6	0.85	1.8	500
701-104-100	24	0.25	Yellow	10	6	0.85	1.8	100
701-007	24	0.25	Lt.Blue	12	8	0.85	1.8	500
701-007-100	24	0.25	Lt.Blue	12	8	0.85	1.8	100
701-026	22	0.34	Turquoise	10	6	0.85	2.0	500
701-026-100	22	0.34	Turquoise	10	6	0.85	2.0	100
701-027	22	0.34	Turquoise	12	8	0.85	2.0	500
701-027-100	22	0.34	Turquoise	12	8	0.85	2.0	100
701-008	20	0.50	Orange	12	6	1.00	2.6	500
701-008-100	20	0.50	Orange	12	6	1.00	2.6	100
701-030	20	0.50	White	18	12	1.00	2.6	500
701-030-100	20	0.50	White	18	12	1.00	2.6	100
701-013	20	0.50	White	16	10	1.00	2.6	500
701-013-100	20	0.50	White	16	10	1.00	2.6	100
701-097	20	0.50	White	14	8	1.00	2.6	500
701-097-100	20	0.50	White	14	8	1.00	2.6	100
701-098	20	0.50	Blue	14	8	1.30	2.6	500
701-098-100	20	0.50	Blue	14	8	1.30	2.6	100
701-028	20	0.50	Orange	14	8	1.00	2.6	500
701-028-100	20	0.50	Orange	14	8	1.00	2.6	100
701-131	20	0.50	Gray	16	10	1.00	2.6	500
701-131-100	20	0.50	Gray	16	10	1.00	2.6	100
701-010	20	0.50	Orange	16	10	1.00	2.6	500
701-010-100	20	0.50	Orange	16	10	1.00	2.6	100
701-029	20	0.50	White	12	6	1.20	2.8	500
701-029-100	20	0.50	White	12	6	1.20	2.8	100
701-111	20	0.75	Gray	14	8	1.20	2.8	500
701-111-100	20	0.75	Gray	14	8	1.20	2.8	100
701-011	18	0.75	White	14	8	1.20	2.8	500
701-011-100	18	0.75	White	14	8	1.20	2.8	100
701-031	18	1.00	Yellow	12	6	1.40	3.0	100
701-031-100	18	1.00	Yellow	12	6	1.40	3.0	500
701-132	18	1.00	Red	12	6	1.40	3.0	500
701-132-100	18	1.00	Red	12	6	1.40	3.0	100
701-014	18	1.00	Yellow	14	8	1.40	3.0	500
701-014-100	18	1.00	Yellow	14	8	1.40	3.0	100
701-099	18	1.00	Red	14	8	1.40	3.0	500
701-099-100	18	1.00	Red	14	8	1.40	3.0	100
701-023	18	1.00	Yellow	16	10	1.40	3.0	500
701-023-100	18	1.00	Yellow	16	10	1.40	3.0	100
701-130	18	1.00	Red	16	10	1.40	3.0	500
701-130-100	18	1.00	Red	16	10	1.40	3.0	100
701-032	18	1.00	Yellow	18	12	1.40	3.0	500
701-032-100	18	1.00	Yellow	18	12	1.40	3.0	100
701-117	18	1.00	Red	18	12	1.40	3.0	500
701-117-100	18	1.00	Red	18	12	1.40	3.0	100
701-016	16	1.50	Red	14	8	1.70	3.5	500
701-016-100	16	1.50	Red	14	8	1.70	3.5	100
701-100	16	1.50	Black	14	8	1.70	3.5	500
701-100-100	16	1.50	Black	14	8	1.70	3.5	100

All Ferrules are copper with tin plating (UL and RoHS)

Model No.	AWG	mm ²	color	L1	L2	d1	d2	Pkg Qty
701-024	16	1.50	Red	18	12	1.70	3.5	500
701-024-100	16	1.50	Red	18	12	1.70	3.5	100
701-138	16	1.50	Black	18	12	1.70	3.5	500
701-138-100	16	1.50	Black	18	12	1.70	3.5	100
701-122	16	1.50	Black	16	10	1.70	3.5	500
701-122-100	16	1.50	Black	16	10	1.70	3.5	100
701-033	16	1.50	Red	24	18	1.70	3.5	200
701-033-100	16	1.50	Red	24	18	1.70	3.5	100
701-101	16	1.50	Black	24	18	1.70	3.5	500
701-101-100	16	1.50	Black	24	18	1.70	3.5	100
701-022	14	2.50	Blue	15	8	2.20	4.2	500
701-022-100	14	2.50	Blue	15	8	2.20	4.2	100
701-102	14	2.50	Gray	15	8	2.20	4.2	500
701-102-100	14	2.50	Gray	15	8	2.20	4.2	100
701-034	14	2.50	Blue	19	12	2.20	4.2	500
701-034-100	14	2.50	Blue	19	12	2.20	4.2	100
701-113	14	2.50	Gray	19	12	2.20	4.2	500
701-113-100	14	2.50	Gray	19	12	2.20	4.2	100
701-019	14	2.50	Blue	25	18	2.20	4.2	200
701-019-100	14	2.50	Blue	25	18	2.20	4.2	100
701-035	12	4.00	Gray	16	8	2.80	4.8	200
701-035-100	12	4.00	Gray	16	8	2.80	4.8	100
701-036	12	4.00	Gray	18	10	2.80	4.8	200
701-036-100	12	4.00	Gray	18	10	2.80	4.8	100
701-145	12	4.00	Orange	18	12	2.80	4.8	200
701-145-100	12	4.00	Orange	18	12	2.80	4.8	100
701-103	12	4.00	Orange	18	10	2.80	4.8	200
701-103-100	12	4.00	Orange	18	10	2.80	4.8	100
701-037	12	4.00	Gray	26	18	2.80	4.8	100
701-038	10	6.00	Black	20	12	3.50	6.3	100
701-085	10	6.00	Yellow	20	12	3.50	6.3	100
701-020	10	6.00	Black	26	18	3.50	6.3	100
701-086	8	10.00	Red	22	12	4.50	7.6	100
701-039	8	10.00	Ivory	22	12	4.50	7.6	100
701-040	8	10.00	Ivory	28	18	4.50	7.6	100
701-087	6	16.00	Blue	22	12	5.80	8.8	100
701-121	6	16.00	White	22	12	5.80	8.8	100
701-041	6	16.00	Green	22	12	5.80	8.8	100
701-021	6	16.00	Green	28	18	5.80	8.8	100
701-042	4	25.00	Brown	30	16	7.30	11.2	50
701-140	4	25.00	Yellow	30	16	7.30	11.2	50
701-133	4	25.00	Black	32	18	7.30	11.2	50
701-043	4	25.00	Brow	36	22	7.30	11.2	50
701-137	2	35.00	Red	22	16	8.30	12.7	25
701-044	2	35.00	Beige	30	16	8.30	12.7	25
701-045	2	35.00	Beige	39	25	8.30	12.7	25
701-046	1/0	50.00	Olive	36	20	10.30	15.0	25

Twin Wire Ferrules

Model No.	AWG	mm ²	color	L1	L2	d1	A/B	Pkg Qty
701-009	2X20	0.5	Orange	15	8	1.4	5.0/3.0	500
701-116	2X20	0.5	White	15	8	1.4	5.0/3.0	500
701-089	2X18	0.75	Gray	15	8	1.7	5.5/3.0	500
701-012	2X18	0.75	White	15	8	1.7	5.5/3.0	500
701-015	2X18	1.0	Yellow	16	8	2.0	5.8/3.2	500
701-090	2X18	1.0	Red	16	8	2.0	5.8/3.2	500
701-139	2X18	1.0	Red	20	12	2.0	5.8/3.2	500
701-017	2X16	1.5	Red	16	8	2.2	6.5/3.6	500
701-143	2X16	1.5	Red	20	12	2.2	6.5/3.6	500
701-091	2X16	1.5	Black	16	8	2.2	6.5/3.6	500
701-120	2X16	1.5	Black	20	12	2.2	6.5/3.6	500
701-018	2X14	2.5	Blue	18	9	2.8	8.0/4.5	500
701-083	2X14	2.5	Blue	21	12	2.8	8.0/4.5	200
701-084	2X12	4.0	Gray	23	12	3.5	9.0/5.2	200
701-112	2X10	6.0	Yellow	26	14	4.5	11.4/6.2	100
701-135	2X8	10.0	Red	24	12	5.8	13.4/7.6	100
701-114	2X6	16.0	Blue	29	16	8.3	17.2/9.5	50