


N=Number of contacts

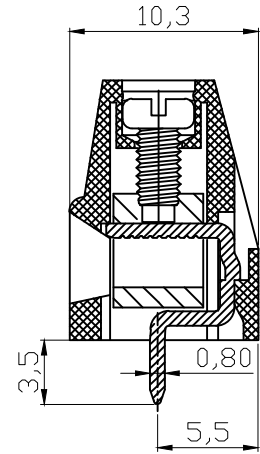

Material
 Terminal body (metal housing): Brass(CuZn)
 Terminal screw: Steel Zinc plating "-" slot type
 Contacts: Brass
 Surface of solder tail: Tin plated
 Insulator (housing): Thermoplastic (UL94V-0), Green

Electrical UL
 Voltage rating: 300VAC
 Current rating: 10A
 Wire range:
 Solid wire(AWG): 12-22
 Stranded wire(AWG): 12-22
 Torque(Lb-In): 3.5
 Screw: M2.5
 Wire strip length: 6-7mm
 Withstanding Voltage: 1.6KV
 Operating temperature: -40°C to +115°C
 Soldering temperature: 250°C ± 10°C / 5 Sec
 Safety Approval:

RoHS compliant
 Unit: mm



File No.: E349947

Scale	1:1				Date	Name	Customer-No.
TOLERANCE					Drawn	29.07.2009	Dean
X.	±0.50				Approved	18.04.2016	Joanna
X.X	±0.30						
X.XX	±0.10						
DIM	TOL	②	Add UL	18.04.2016	Joanna	ASSMANN WSW-No. A-TB500-TIxx	
X.°	±1°	①	Drawn	29.07.2009	Dean		
X.X°	±X°						
Angle	TOL	Id.	Modification	Date	Name	Replace	Sheet



Customer-No.
 ASSMANN WSW-No.
A-TB500-TIxx

Drawing-No.
ASS 3594 CO rev02
 Sheet