

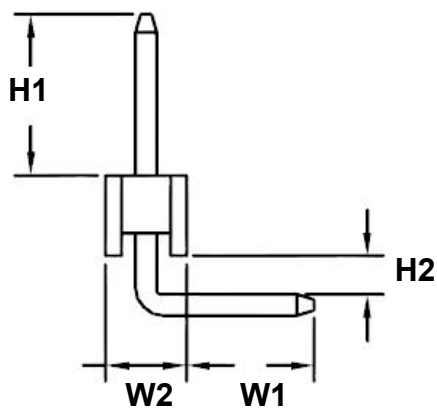


1.27 mm 40 pin Right Angle Male Header Through Hole Gold

REF.	DIMENSIONS					
	mm			inches		
	MIN.	TYP.	MAX.	MIN.	TYP.	MAX.
C		0.65				
C1		0.40				
E		1.27			0.050	
H		1.60				
H1		3.00				
H2		0.40				
L1		49.53			1.950	
L2		50.80			2.000	
W1		1.80				
W2		2.12				

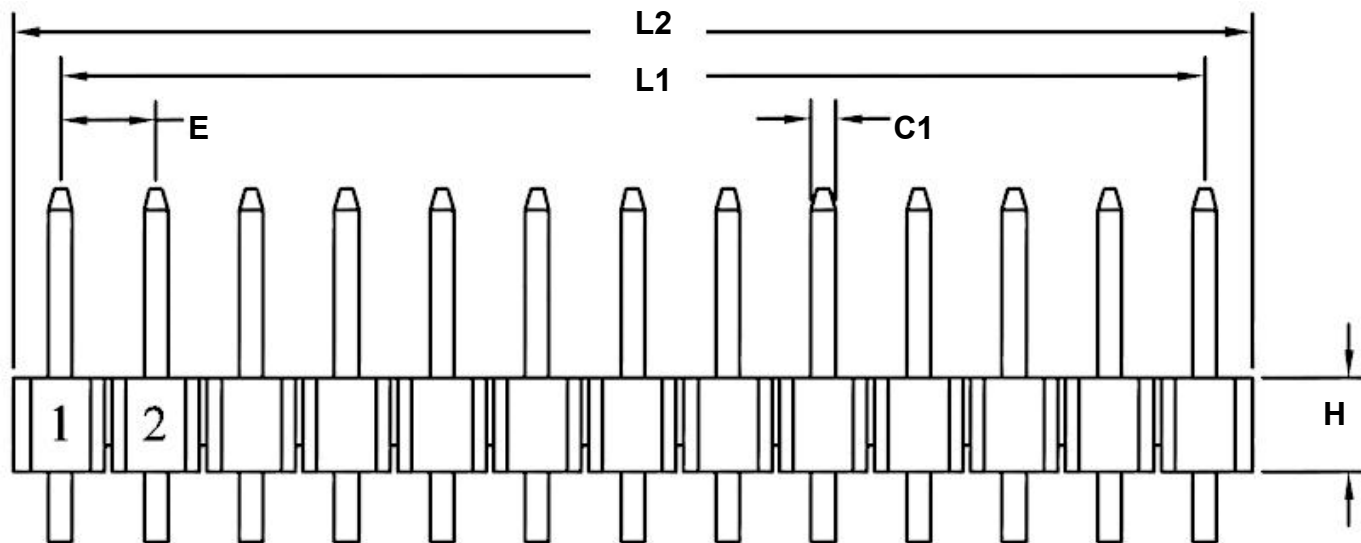

Recommended PCB Hole Layout

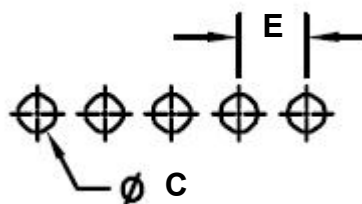

SPECIFICATIONS

Plastic body construction: PA6T plastic (320°C melting point)

Pin construction: Gold plated (brass pin, with 1um gold over 50um nickel)

Operating temperature range: -40°C to +130°C

Reflow maximum temperature: +260°C