


COMBO MIMO MOBILE ROOF SMA ANTENNA

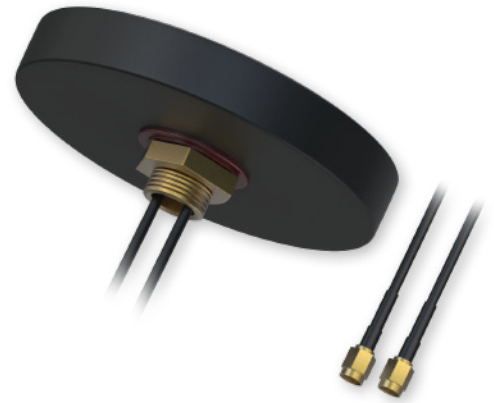

TECHNICAL DATA

PARAMETER

Mounting method	Screw
Radome ingress protection rating	IP65
Radome material	UV resistant plastic and cable
Weight	215 g
Housing dimensions	Ø 81.3 x 15.2 mm
Cable	2x RG174, 3000 mm
Operating temperature	-40 ~ +85 °C
UV resistance	✓
RoHS Compliant	✓

