



Plug-in miniature solid-state relay, power solid-state relay, 1 NO contact, Input: 24 VDC, Output: 24 VDC/2 A

### Business data

Article number	<u>15505.2</u>
Article name	PSC 1/24V DC-24V/2A/DC
GTIN (EAN)	4044211118198
Packaging unit	10
Quantity unit	PC
Weight per piece (not including packaging)	3.6 g
Weight per piece (including packaging)	4.97 g
Unit of weight	G
Customs number	85364900
Country of origin	IT
Product description	Solid-state module

### Technical data

#### Dimensions

Length	28 mm
Width	5 mm
Height	15 mm

#### Input data

Input voltage	24 VDC
Drop-out voltage	10 VDC
Control current	7,2 mA
Number of channels	1
Operating range	16-30 VDC
Power consumption	0,17 W

#### Output data

Output voltage range	1,5-33 VDC V
Voltage drop at 20 °C and rated current, max.	0,4 V
Switching current, min.	0,001 A
Continuous current max. / Inrush current max.	6 / 50 A
Residual current at 55 °C, max.	0,001 mA

#### Materials

Working temperature, min.	-20 °C
Working temperature, max.	55 °C


#### Further technical data

Response/release time	0,1 / 0,6 ms
Remarks	1 NO contact
Test voltage	2.5 kV

#### Environmental Product Compliance

REACH Conform	yes
REACH Reference date	2023-06-14
REACH Candidate Substance Note	No
RoHS Conform	yes

### Media

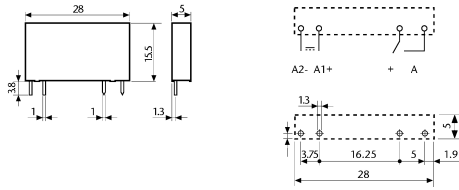

---

### Accessories

---