

Product Specification



Patch Antenna JLT868S25P4C

Feature

High gain , Compact


Pin type

Customization available

Electrical Specification

Center Frequency	868± 3.0 MHz
Return Loss @ F0	≥ 15dB
Polarization	RHCP
Ground plane	70x70 mm
Impedance	50 Ω
Operation Temperature Range	-40 ~ +85°C

Mechanical Drawing

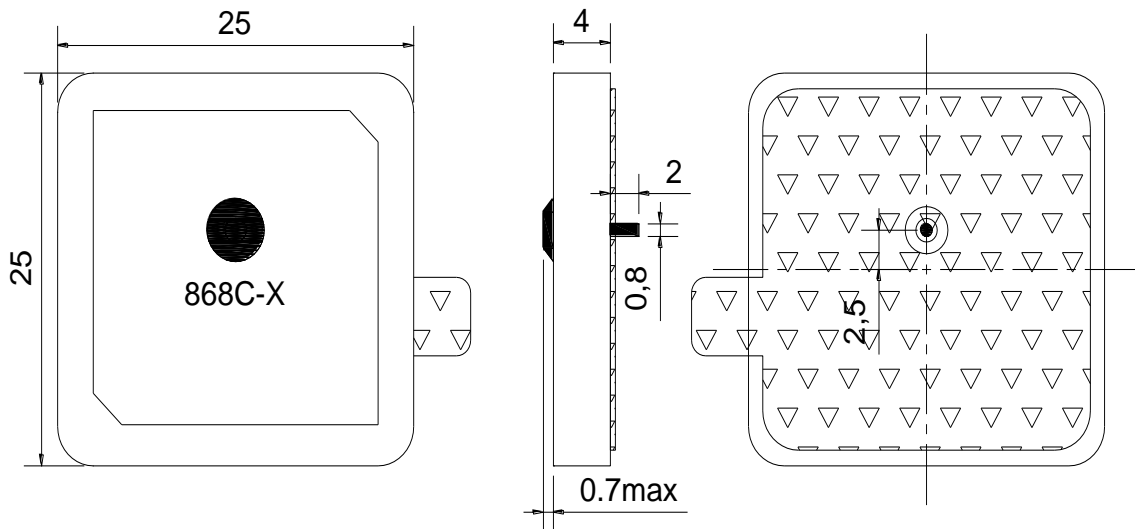

The last "X" is the serial number of month

Tolerance Unless Otherwise Specified:±0.30
Unit: mm

Product Specification




Patch Antenna



JLT868S25P4C

Test Fixture

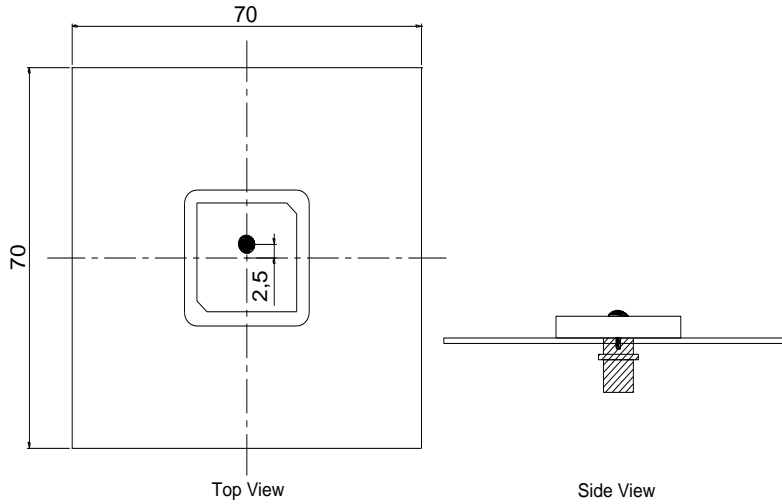

Characteristics

